



Basic information

Part number	493.097.613.644.001
Category	housing
Size	4

Mechanical and environmental data


IP class	IP40
Max. operating temperature	125 °C
Min. operating temperature	-40 °C
Weight	121.7 g

Material and surface treatments


Material	aluminum_die_casting_body
----------	---------------------------

Graphics and technical drawings

B METAL PROTECTIVE COVER
for cable hood and cable hood XXL
for spindle locking

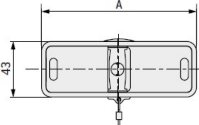

B VIEW WITHOUT LANYARD

 

Size	Dim. A
	mm
1	60
2	73
3	93.5
4 / XXL	120

Further technical information and downloads

- [3D-File \[STP File\]](#)
- [Assembly Instruction](#)