


Insulation-body 3-pos.

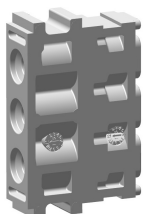

Basic information

Part number	611.127.103.923.000
Category	Insulation-body
Number of units	3

Contact insert description

Number of contacts	3
Contact type	Sockets

Mechanical and environmental data



Mating cycles	minimum 100.000
Upper temperature limit	125 °C
Max. operating temperature	125 °C
Min. operating temperature	-40 °C
Weight	3.64 g

In the ODU-MAC Silver-/ White-Line product portfolio we explicitly recommend that the modules are purchased assembled with the frames in order to prevent possible errors in the assembly process. Only in exceptional cases we can supply individual parts. However we cannot take any liability therefore. We would like to emphasize the usage of our ODU tools, as well as our current assembly instructions in the download area: <https://odu-connectors.com/silver-white-line-instructions>

Material and surface treatments

Material	PBT Polybutyleneterephthalat
Insulator material	PBT
Color option (Front or back nut)	Gray

ODU reserves the right to make changes based on the current state of knowledge without prior notice without being obliged to provide replacement deliveries or refinements of older designs.

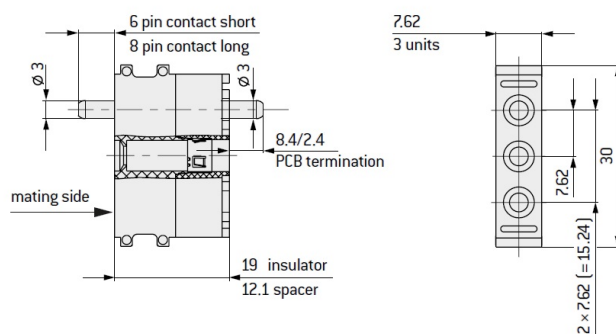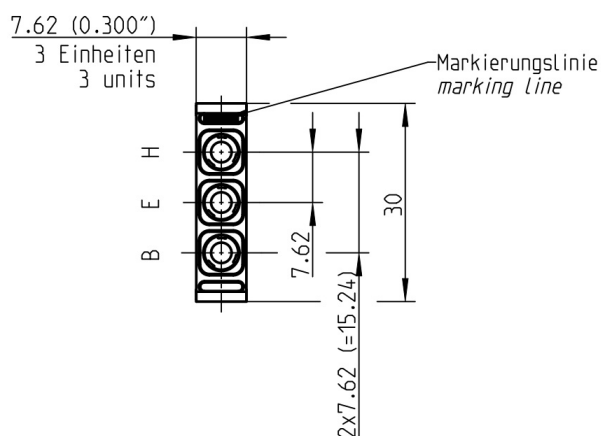

Further technical information and downloads

[3D-File \(STP File\)](#)

[Assembly Instruction](#)