

612.093.010.644.000

ODU-MAC®



Bulkhead mounted housing for spindle locking, metal, size 4, gray

For mounting on your device. Housing colors available in grey or white.



Basic information

Part number	612.093.010.644.000
Category	Housing
Number of units	34
Size	4




Mechanical and environmental data

Locking principle	Spindle-locking
IP class	IP65
Max. operating temperature	85 °C
Min. operating temperature	-40 °C
Weight	97.78 g

Material and surface treatments

Material	Aluminum
----------	----------

ODU reserves the right to make changes based on the current state of knowledge without prior notice without being obliged to provide replacement deliveries or refinements of older designs.

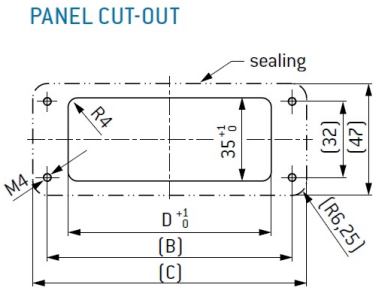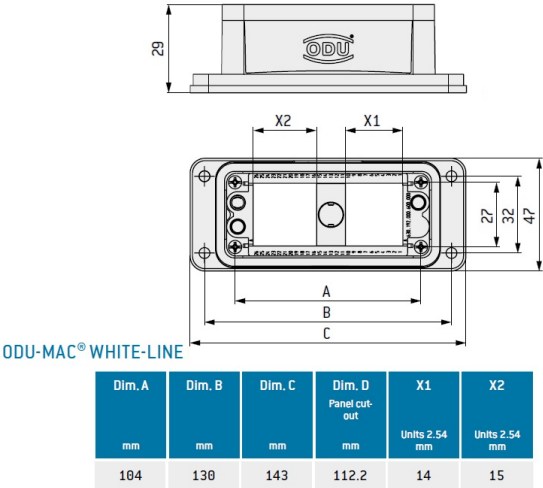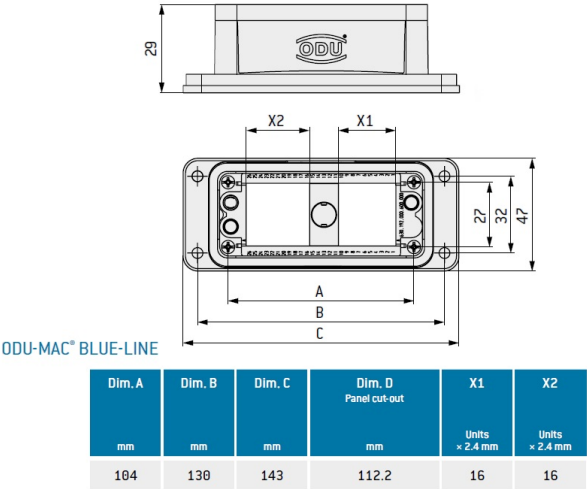

Further technical information and downloads

[3D-File \(STP File\)](#)

[Assembly Instruction](#)