


Socket insulation body 3-pos.

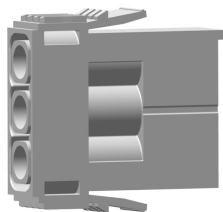

Basic information

Part number	630.113.103.923.000
Category	Insulation-body
Number of units	4

Contact insert description

Number of contacts	3
Contact type	Sockets

Mechanical and environmental data



Mating cycles	10000
Max. operating temperature	125 °C
Min. operating temperature	-40 °C
Weight	5.55 g

Material and surface treatments

Material	Thermoplastic
----------	---------------

ODU reserves the right to make changes based on the current state of knowledge without prior notice without being obliged to provide replacement deliveries or refinements of older designs.

Graphics and technical drawings

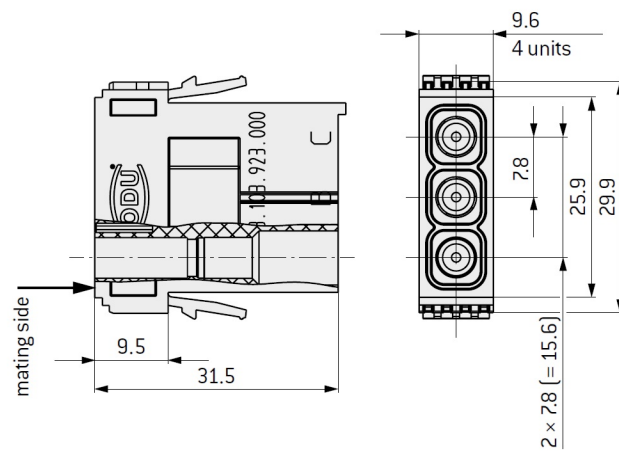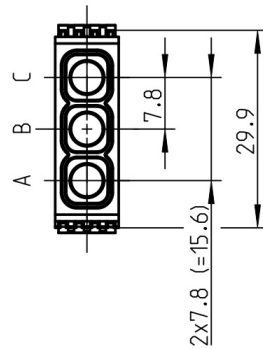

Further technical information and downloads

[3D-File \(STP File\)](#)

[Assembly Instruction](#)