


631.112.105.923.000

ODU-MAC® Blue-Line

Insulation-body 5-pos.

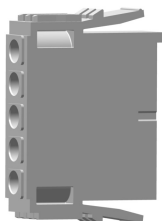

Basic information

Part number	631.112.105.923.000
Category	Insulation-body
Number of units	3

Contact insert description

Number of contacts	5
--------------------	---



Mechanical and environmental data

Mating cycles	10000
Max. operating temperature	125 °C
Min. operating temperature	-40 °C
Weight	3.93 g

Material and surface treatments

Material	Thermoplastic
----------	---------------

ODU reserves the right to make changes based on the current state of knowledge without prior notice without being obliged to provide replacement deliveries or refinements of older designs.

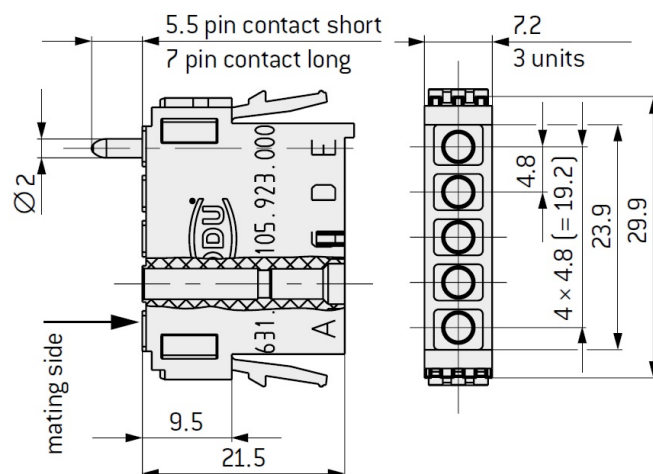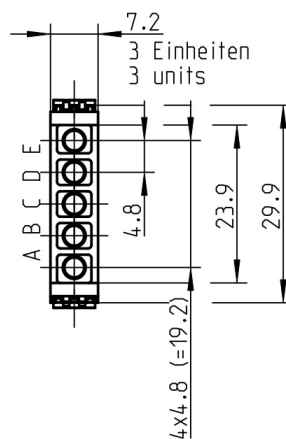

Further technical information and downloads

[3D-File \(STP File\)](#)

[Assembly Instruction](#)