

GC1WCM-P27WBC0-000L

odu_amc®_hd



receptacle_with_screw_lock_for_rear_panel_mounting

size_1_ip6k8_ip6k9k_coding_c_blue_27_contacts_sockets_solder_cup_data_transmission_hdmi®_1.3_8.13_gbits



Basic information

Part number	GC1WCM-P27WBC0-000L
Category	connector
Type of connector	receptacle
Assembly situation	rear_panel_mounting
Size	1

Contact insert description

Special features	data_transmission
Transmission type	HDMI® 1.4 [10.2 Gbit/s]
Number of contacts	27
Contact type	sockets
Contact diameter	0.3 mm
Termination type	solder_cup
Termination diameter	0.45 mm
Wire cross section AWG	AWG 28

Technical information

Max. current single contact	1 A	IEC 60512-5-2:2002 (DIN EN 60512-5-2:2003)
Max. current insert	0.4 A	VDE 0298-4:2013
Test voltage	0.75 kV DC	EIA-364-20F:2019-02




Mechanical and environmental data

Locking principle	screw_lock
Keying	c
Mating cycles	5.000
IP class	IP68 / IP6K9K
Max. operating temperature	125 °C
Min. operating temperature	-51 °C
Tightening torque	1 Nm
Weight	7.4 g

ip_protection_class_refers_to_mated_condition

Material and surface treatments

Material	cu_alloy_with_ruthenium_finish
Contact material	gold

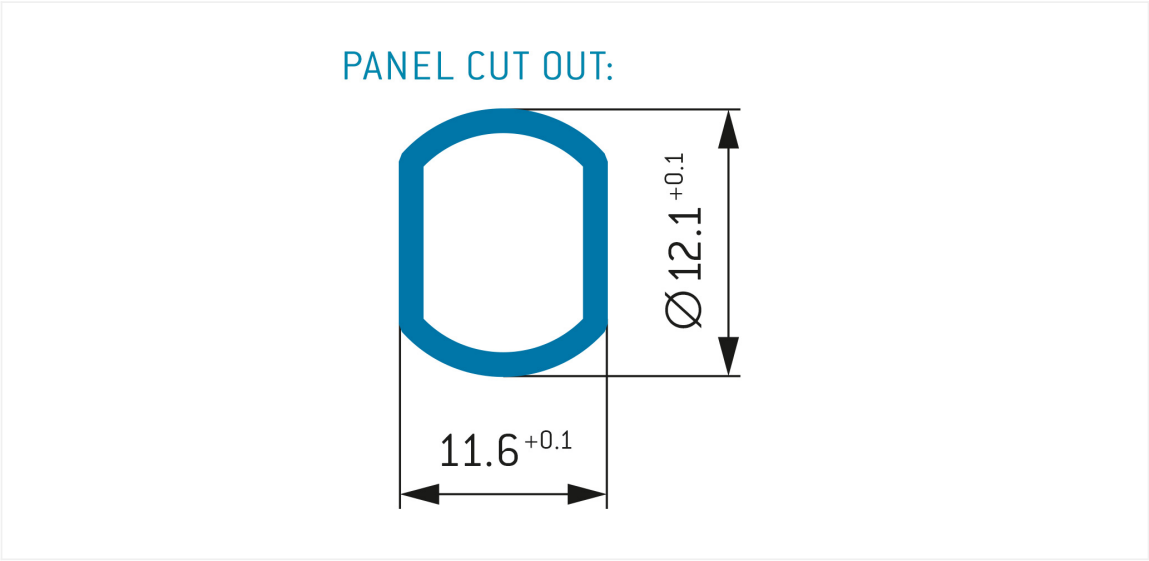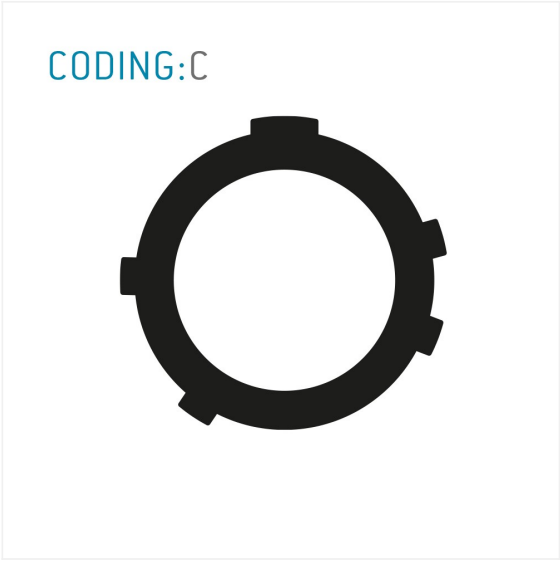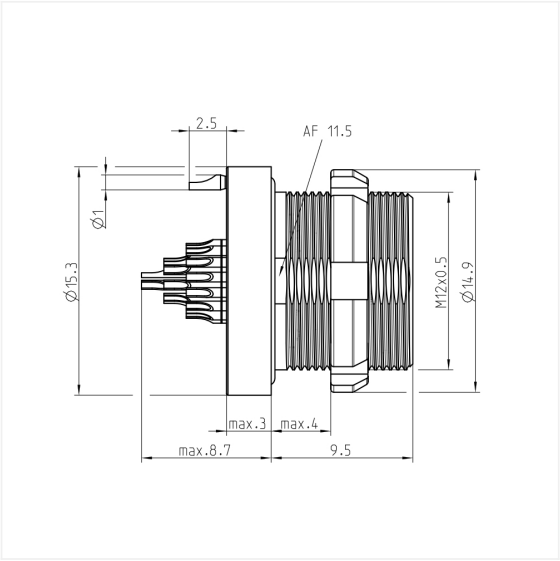

Further technical information and downloads

Connection diagram	connection_diagram_27_pin_hdmi_1_4_typ_a
--------------------	--

[3D-File \(STP File\)](#)

Technical specifications
--