

receptacle_with_screw_lock_for_rear_panel_mounting

size_1_ip6k8_ip6k9k_coding_d_green_27_contacts_sockets_pcb_data_transmission_hdmi®_1.3_8.13_gbits

**Basic information**

Part number	GC1WDM-P27UB00-000L
Category	connector
Type of connector	receptacle
Assembly situation	rear_panel_mounting
Size	1

Contact insert description

Special features	data_transmission
Transmission type	HDMI® 1.3 (8.13 Gbit/s)
Number of contacts	27
Contact type	sockets
Contact diameter	0.3 mm
Termination type	pcb
Termination diameter	0.3 mm

Technical information

Max. current single contact	1 A	IEC 60512-5-2:2002 (DIN EN 60512-5-2:2003)
Max. current insert	0.4 A	VDE 0298-4:2013
Test voltage	0.75 kV DC	EIA-364-20F:2019-02

Mechanical and environmental data


Locking principle	screw_lock
Keying	d
Mating cycles	5.000
IP class	IP68 / IP6K9K
Max. operating temperature	125 °C
Min. operating temperature	-51 °C
Tightening torque	1 Nm
Weight	7.22 g

ip_protection_class_refers_to_mated_condition


Material and surface treatments

Material	cu_alloy_with_ruthenium_finish
Contact material	gold


DIMENSIONS:

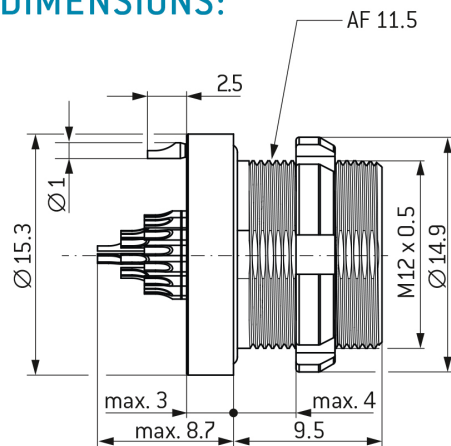


CODING:C

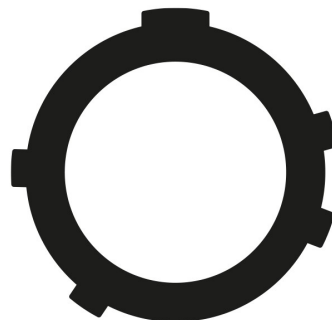


POSITIONS: 27 positions

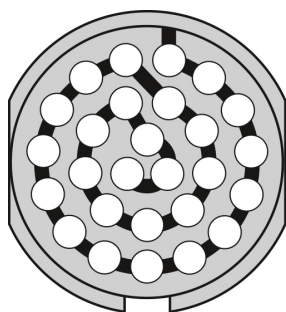

PCB-LAYOUT:

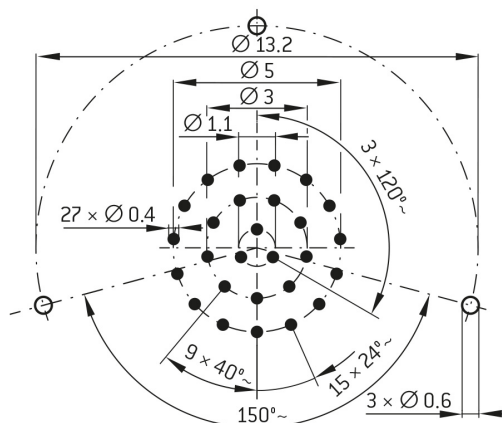

PANEL CUT OUT:

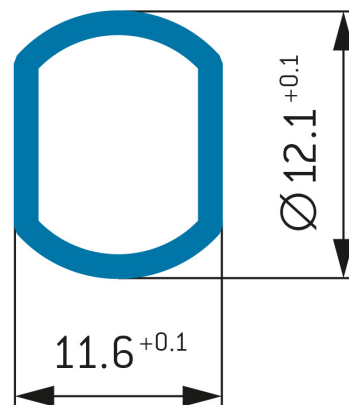

Further technical information and downloads

Connection diagram	connection_diagram_amc_hd_27_pin_hdmi
--------------------	---------------------------------------

[3D-File \(STP File\)](#)

Technical specifications
--