

GS1WAM-P17WMM0-0000

odu_amc®_hd



receptacle_with_screw_lock_for_rear_panel_mounting_with_cable_outlet

size_1_ip6k8_ip6k9k_coding_a_light_brown_17_contacts_sockets_solder_cup_data_transmission



Basic information

Part number	GS1WAM-P17WMM0-0000
Category	connector
Type of connector	receptacle
Assembly situation	rear_panel_mounting
Size	1

Contact insert description

Special features	data_transmission
Transmission type	HDMI® 1.4 (10.2 Gbit/s)
Number of contacts	17
Contact type	sockets
Contact diameter	0.3 mm; 0.7 mm
Termination type	solder_cup
Termination diameter	0.45 mm
Wire cross section AWG	AWG 28; AWG 22

Technical information

Max. current single contact	1 A	IEC 60512-5-2:2002 (DIN EN 60512-5-2:2003)
Test voltage	0.75 kV DC	EIA-364-20F:2019-02

Cable description

Cable outlet	overmolding
Min. cable diameter	3.2
Max. cable diameter	8.5

Mechanical and environmental data


Locking principle	screw_lock
Keying	a
Mating cycles	5.000
IP class	IP68 / IP6K9K
Max. operating temperature	125 °C
Min. operating temperature	-51 °C
Tightening torque	1 Nm
Weight	13.09 g

ip_protection_class_refers_to_mated_condition



Material and surface treatments

Material	cu_alloy_with_ruthenium_finish
Contact material	gold


DIMENSIONS:

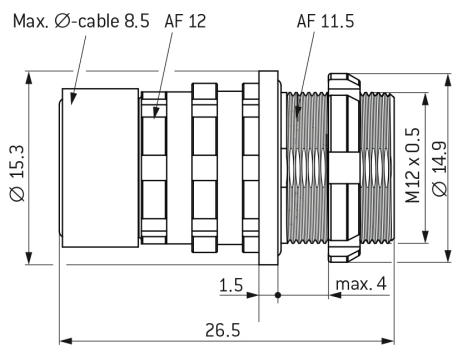

CODING:A

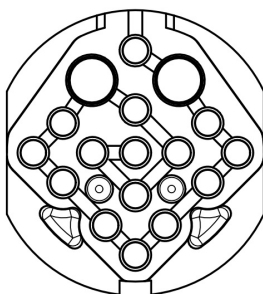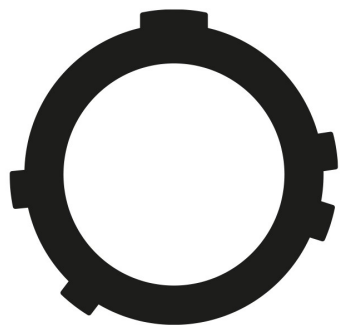

PANEL CUT OUT:

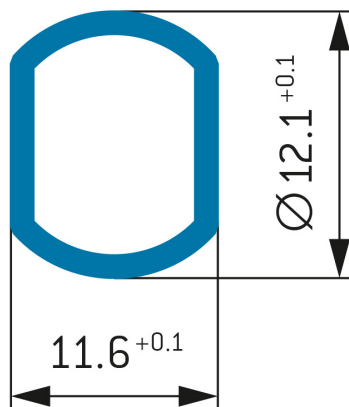

Further technical information and downloads

Connection diagram	connection_diagram_17_pin_hdmi_1_4_typ_a
--------------------	--

[3D-File \(STP File\)](#)

Assembly Instruction

[Technical specifications](#)