

ODU LAMTAC socket 2.0mm Ag 2.5mm² crimp termination



Basic information

Part number	178.607.100.201.000
Category	Contact

Contact insert description

Contact type	Sockets
Termination type	Crimp
Wire cross section mm²	2.5 mm²

Technical information

Nominal current single contact	36 A
Max. current	62 A
Impulse current	2.5 kA
Contact resistance	350 µΩ


Mechanical and environmental data

Total mating force (average) in N/module	6 N
Extraction force	5 N
Weight	1.487 g

Material and surface treatments

Material	Cu-alloy
Contact material	Silver

Graphics and technical drawings

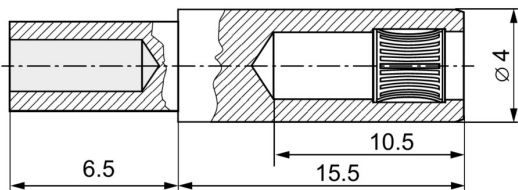

Further technical information and downloads

[3D-File \(STP File\)](#)