 


Socket insulation-body 20-pos.**Basic information**

Part number	610.178.120.922.000
Category	Insulation-body
Number of units	2

Contact insert description

Number of contacts	20
Contact type	Sockets

Technical information

Max. creepage distance (contact to contact)	1.5 mm
Max. clearance distance (contact to contact)	0.9 mm

Mechanical and environmental data





Mating cycles	minimum 100.000
Max. operating temperature	125 °C
Min. operating temperature	-40 °C
Weight	2.3 g

In the ODU-MAC Silver-/ White-Line product portfolio we explicitly recommend that the modules are purchased assembled with the frames in order to prevent possible errors in the assembly process. Only in exceptional cases we can supply individual parts. However we cannot take any liability therefore. We would like to emphasize the usage of our ODU tools, as well as our current assembly instructions in the download area: <https://odu-connectors.com/silver-white-line-instructions>

Material and surface treatments

Material	Polyamide 4T GF30 FR
----------	----------------------

ODU reserves the right to make changes based on the current state of knowledge without prior notice without being obliged to provide replacement deliveries or refinements of older designs.

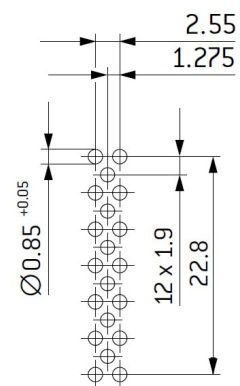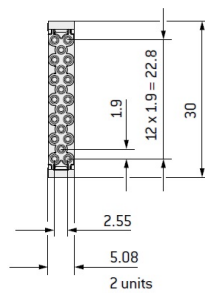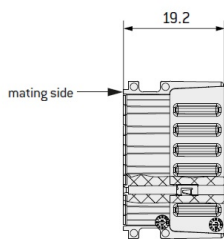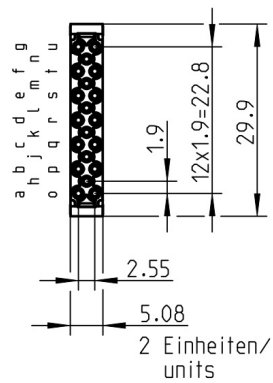

Further technical information and downloads

[3D-File \[STP File\]](#)

[Assembly Instruction](#)