


Pin insulation body 3-pos.

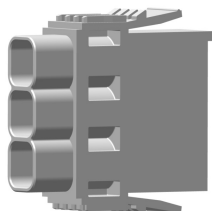

Basic information

Part number	631.113.103.923.000
Category	Insulation-body
Number of units	4

Contact insert description

Number of contacts	3
Contact type	Pins

Technical information

Max. creepage distance (contact to contact)	16.3 mm
Max. clearance distance (contact to contact)	16.3 mm

The current load information is valid for single contacts or fully equipped modules. For use in connector systems, the load should be reduced according to VDE 0298-4:2013-06



Mechanical and environmental data

Mating cycles	10000
Max. operating temperature	125 °C
Min. operating temperature	-40 °C
Weight	5.39 g

Material and surface treatments

Material	Thermoplastic
----------	---------------

ODU reserves the right to make changes based on the current state of knowledge without prior notice without being obliged to provide replacement deliveries or refinements of older designs.

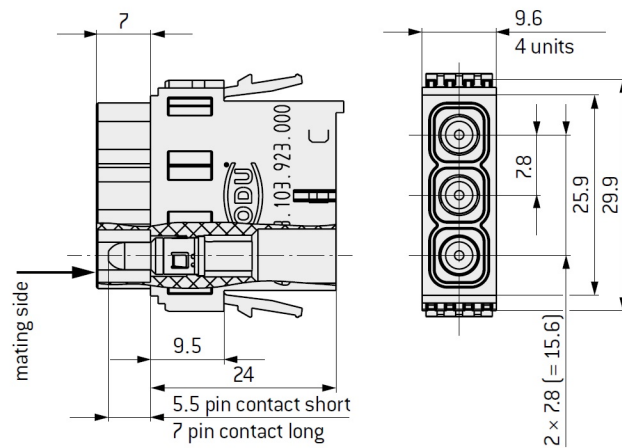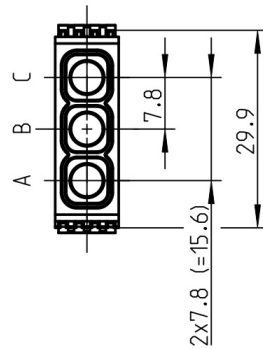

Further technical information and downloads

[3D-File \(STP File\)](#)

[Assembly Instruction](#)