

PUSH-LOCK housing, black, without contacts

The ODU-MAC® PUSH-LOCK housing with the proven push-pull locking principle.

**Basic information**

Part number	656.564.012.000.000
Category	Housing
Number of units	7

Cable description

Cable outlet position	Top
-----------------------	-----

Mechanical and environmental data


Locking principle	Push-Pull
Mating cycles	5000
IP class	IP67
Max. operating temperature	125 °C
Min. operating temperature	-40 °C
Total sliding force (average) in N/module	25 N +/- 15 N
Total mating force (average) in N/module	25 N +/- 15 N
Weight	178.05 g

Material and surface treatments

Material	Lexan PC
----------	----------

ODU reserves the right to make changes based on the current state of knowledge without prior notice without being obliged to provide replacement deliveries or refinements of older designs.

Graphics and technical drawings

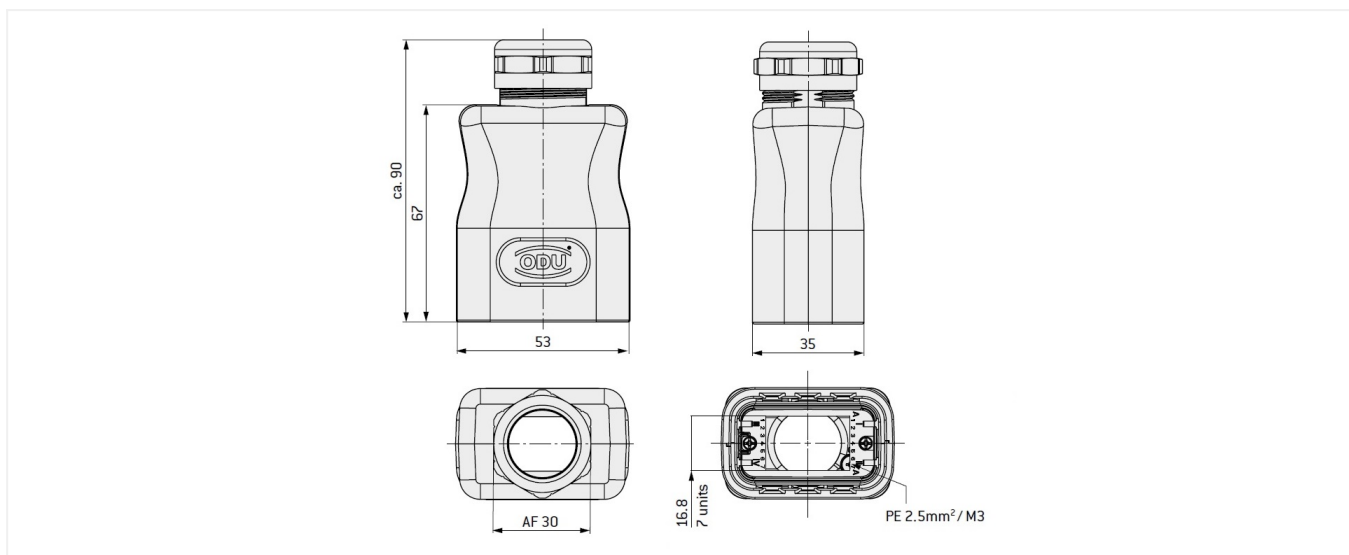

Further technical information and downloads

[3D-File \[STP File\]](#)

[Assembly Instruction](#)