

receptacle_with_screw_lock_for_rear_panel_mounting

size: 0, IP68 / IP6K9K, keying: d, number_of_contacts: 12, pcb, contact_type: sockets, USB® 3.2 Gen 1x1 [5 Gbit/s]



Basic information

Part number	GCOWDM-PD1UM00-000L
Category	connector
Type of connector	receptacle
Assembly situation	rear_panel_mounting

Contact insert description

Special features	data_transmission
Transmission type	USB® 3.2 Gen 1x1 [5 Gbit/s]
Number of contacts	12
Contact type	sockets
Contact diameter	0.3 mm; 0.7 mm
Termination type	pcb
Termination diameter	0.8 mm

Technical information

Nominal current single contact	1 A	IEC 60512-5-2:2002 (DIN EN 60512-5-2:2003)
Test voltage	0.75 kV DC	EIA-364-20F:2019-02

Mechanical and environmental data


Locking principle	screw_lock
Keying	d
Mating cycles	5.000
IP class	IP68 / IP6K9K
Max. operating temperature	125 °C
Min. operating temperature	-51 °C
Tightening torque	1 Nm
Weight	4.92 g

ip_protection_class_refers_to_mated_condition


Material and surface treatments

Material	cu_alloy_with_ruthenium_finish
Contact material	cu_alloy_with_gold_finish



DIMENSIONS:

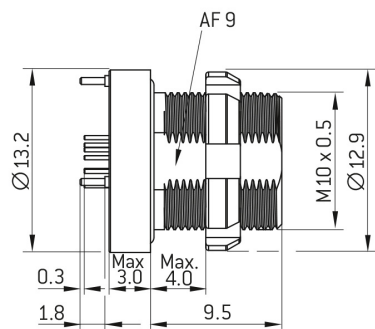


CODING:C

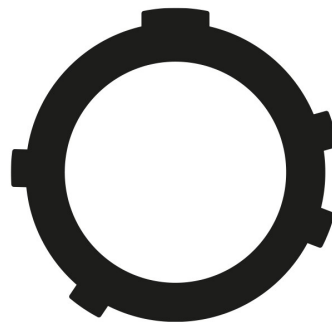

12 Positions

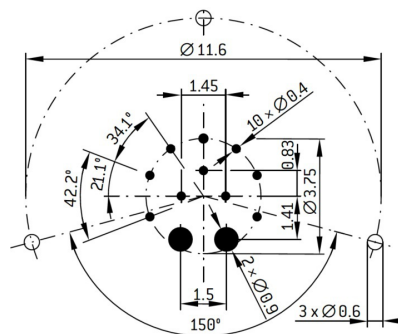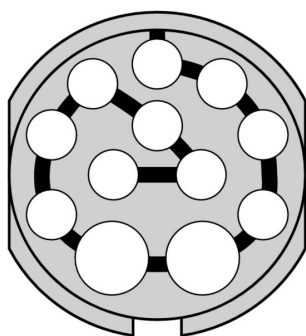

PANEL CUT OUT:

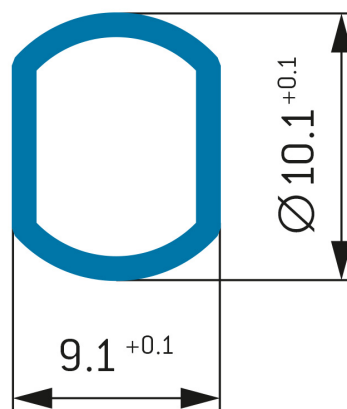

Further technical information and downloads

Connection diagram	connection_diagram_D1_pin_usb_3_2_gen1x1_socket_typ_a
--------------------	---

[3D-File \(STP File\)](#)

Technical specifications
--