


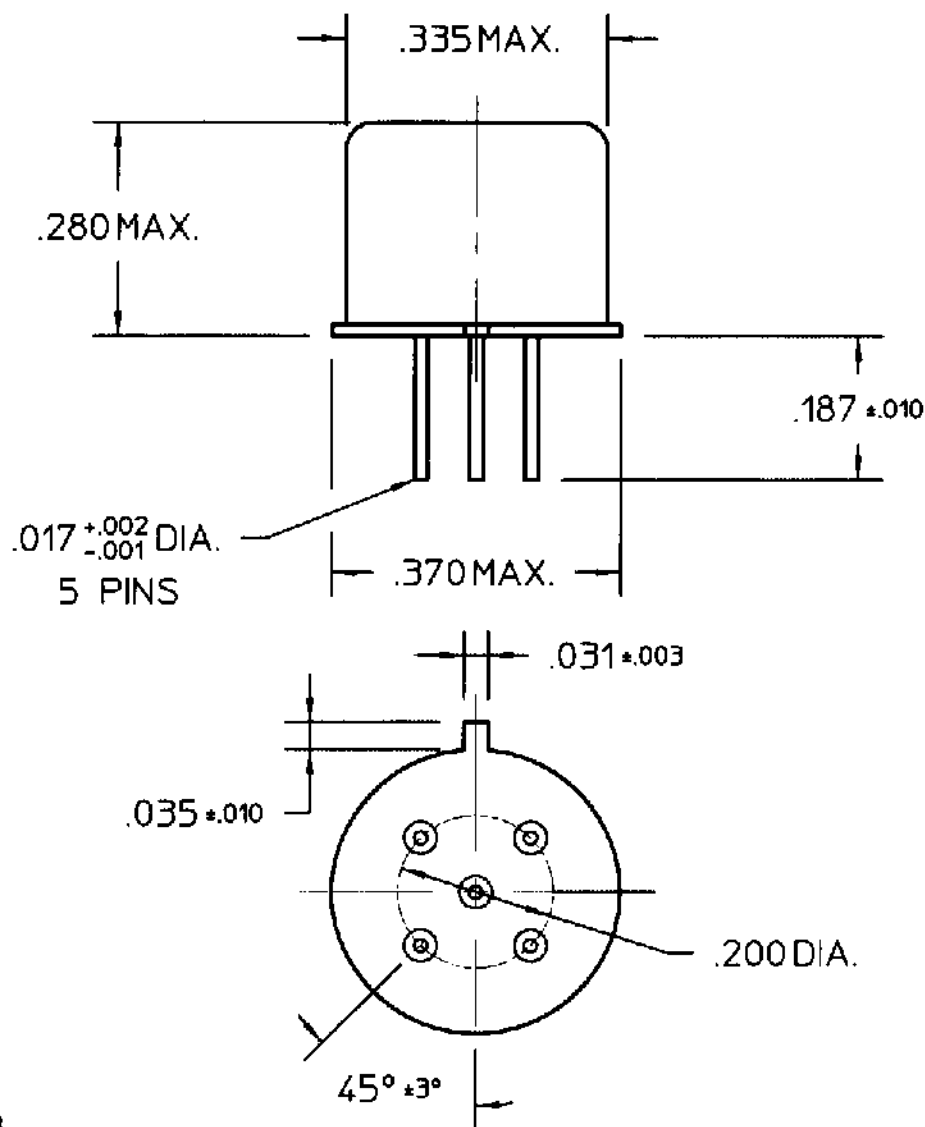

REV. 0

DCO 141423


COIL: @ 25°C	
RESISTANCE	2000 OHMS $\pm$ 10%
NOMINAL VOLTAGE	26.5 VDC
MUST OPERATE	14.2 VDC
MUST RELEASE	8.0 VDC MAX, 1.37 VDC MIN.

ENVIRONMENT:

VIBRATION 10 CPS TO 3000 CPS @ 30 g's
 SHOCK 75 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 2.0 MS MAX.
 RELEASE TIME 2.0 MS MAX.
 CONTACT BOUNCE 1.5 MS MAX.

CUSTOMER DATA SHEET

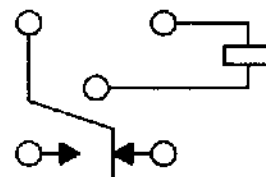

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1A
 28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 10/6/99

CK/ERD 10/6/99

COMMUNICATIONS
 INSTRUMENTS, INC.

CUST. QPL

CUST. NO. M39016/7-024L REV.

"J1MA" RELAY

J1MAP-26XL