


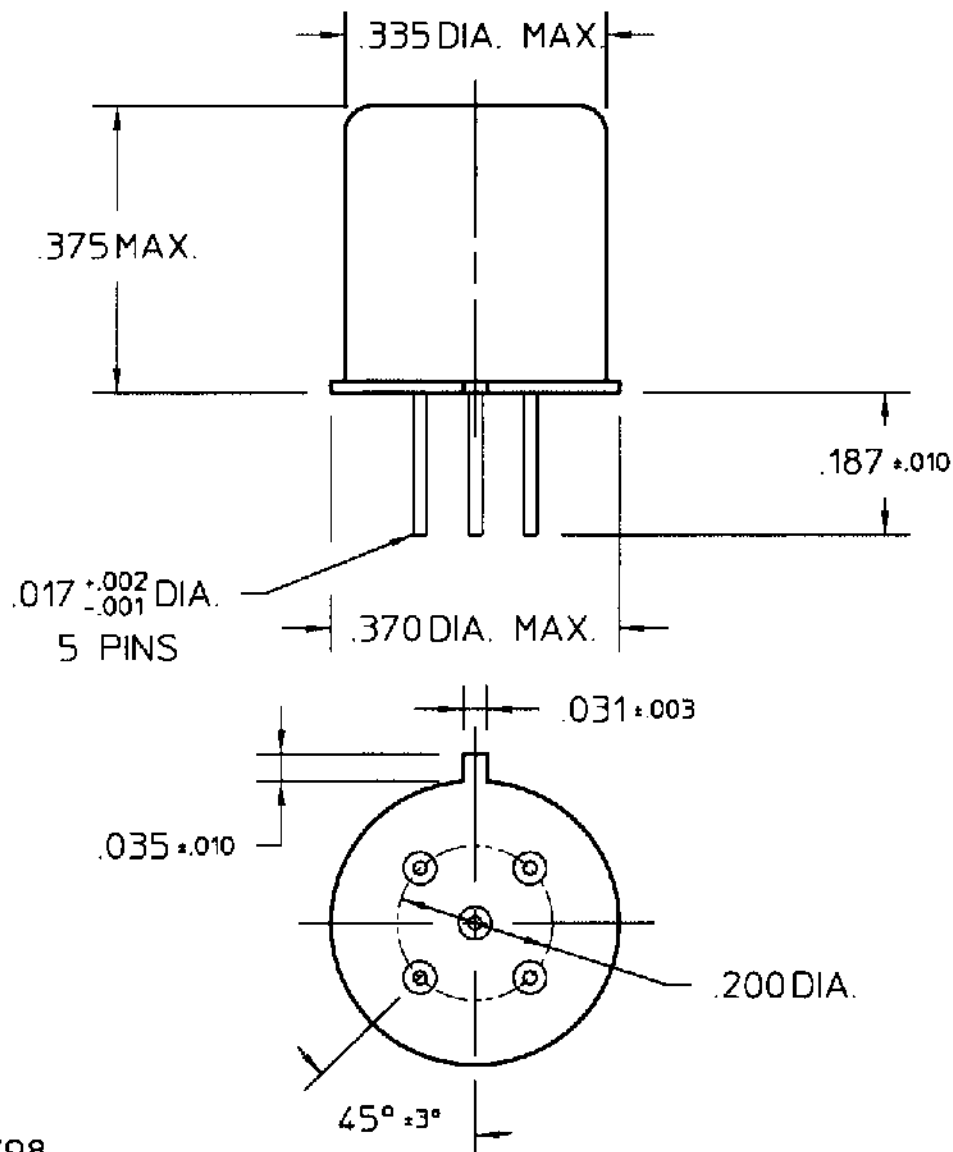

REV. 2 4/6/98


COIL: @ 25°C
 RESISTANCE 125 OHMS ± 10%
 NOMINAL VOLTAGE 5.0 VDC
 MUST OPERATE 2.8 VDC
 MUST RELEASE 1.7 VDC MAX, 0.23 VDC MIN.

ENVIRONMENT:

VIBRATION 10 CPS TO 3000 CPS @ 30 g's
 SHOCK 75 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 4.0 MS MAX.
 RELEASE TIME 7.5 MS MAX.
 CONTACT BOUNCE 1.5 MS MAX.

CUSTOMER DATA SHEET

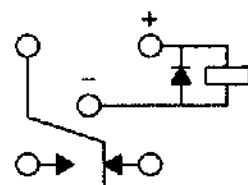

CONTACT RATING: LOW LEVEL TO 1A
 28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 5/15/97 CK JERRY 4/6/98

COMMUNICATIONS
 INSTRUMENTS, INC.

CUST. QPL
 CUST. NO. M39016/25-025L

TYPE J1MSD RELAY

J1MSPD-5XL