




Terminals & Splices > Quick Disconnects

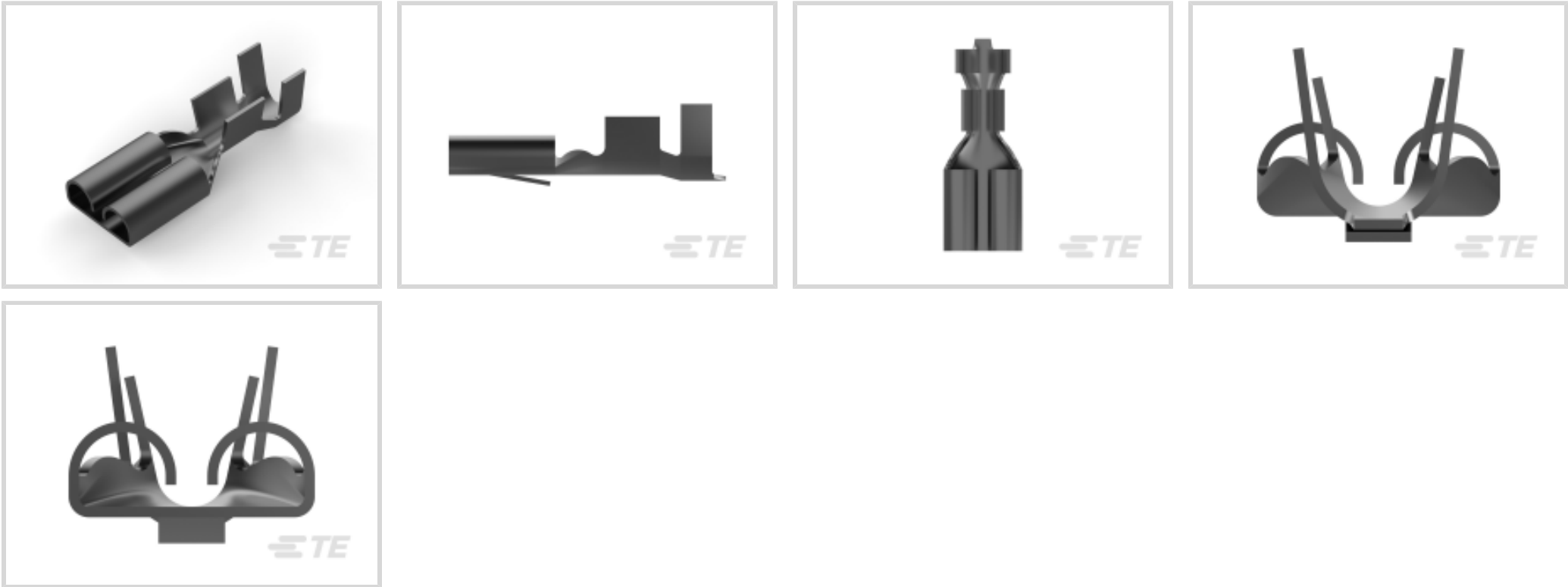

Quick Disconnect Terminal Type: **Receptacle**

Wire Size: **2.1 – 3.31 mm²**

Mating Tab Width: **6.35 mm [.25 in]**

Mating Tab Thickness: **.81 mm [.032 in]**

Features

Product Type Features

Insertion Force	Normal
-----------------	--------

Configuration Features

Compatible With Wire & Cable Type	Discrete Wire
Connection Capacity	Single

Contact Features

Quick Disconnect Terminal Type	Receptacle
Mating Tab Width	6.35 mm[.25 in]
Mating Tab Thickness	.81 mm[.032 in]
Terminal Orientation	Straight
Contact Base Material	Brass
Terminal Plating Material	Tin
Crimp Type	F-Crimp
Barrel Type	Open

Termination Features

--	--



Product Terminates To	Wire & Cable
-----------------------	--------------

Mechanical Attachment

Locking Lance Height	.8 mm
Wire Insulation Support	With
Mating Retention Type	Locking Lance

Dimensions

Product Length	21.5 mm[.846 in]
Compatible Insulation Diameter Range	2.9 – 3.8 mm[.114 – .15 in]
Terminal Material Thickness	.33 mm[.013 in]
Wire Size	2.1 – 3.31 mm ²

Usage Conditions

Insulation Option	Uninsulated
Operating Temperature Range	-40 – 110 °C[-40 – 230 °F]

Packaging Features

Packaging Quantity	4000
Packaging Method	Strip/Reel

Compatible Parts

TE Part # 2819183-1
.250 SERIES FASTIN FASTON REC.

TE Part # 2150533-1
OCEAN_2.0_Applicator-E-130F180F-REM

TE Part # 2150533-2
OCEAN_2.0_Applicator-E-130F180F-REA

TE Part # 7-2150533-7
OCEAN_2.0_SPARE_PART_KIT-130F180F

TE Part # 170303-1
FF 250 REC 22-18AWG BR WITH LATCH

Also in the Series | FASTIN-FASTON 250



Crimp Terminal Housings(195)




Insertion & Extraction Tools(2)



Quick Disconnects(218)

Customers Also Bought

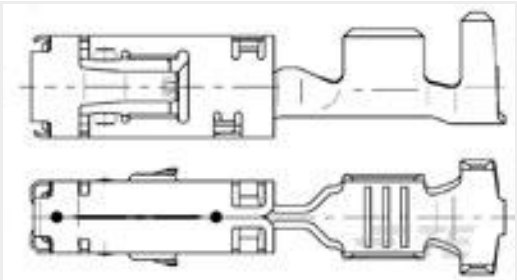

TE Part #967543-1
SENSOR FLA-KONT 2,8



TE Part #CAT-T319-CH8172
TH/.025 CONNECTOR SYSTEM, HOUSING



TE Part #CAT-T3437-C8906
CSL Self Laminating Polyester Labels



TE Part #3-2112780-1
18POS, MIXED,REC HSG,ASSY, SEALED



 
TE Part #2134557-2
8POS MQS REC



TE Part #2236793-3
SMARTSEAL TERMINAL



TE Part #1-2291193-3
SMARTSEAL TERMINAL



TE Part #2112758-1
COVER

Documents

Product Drawings

FF 250 REC 14-12AWG TPBR

Japanese

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_170089-2_P_c-170089-2-p.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_170089-2_P_c-170089-2-p.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_170089-2_P_c-170089-2-p.3d_stp.zip

English

By downloading the CAD file I accept and agree to the Terms and Conditions of use.



Product Specifications

Application Specification

Japanese

Crimping of 250 Series Tab and Receptacle Contacts

Japanese

Crimping of 250 Series Tab and Receptacle Contacts

Japanese

Application Specification

Japanese

Agency Approvals

UL Report

English