



Application Tooling > Hand Crimping Tools



Tool Grade: **Premium Crimp Tooling**
Ratchet Configuration: **Not Releasable, Not Adjustable**
Die Sets Type: **Fixed In Tool**
Specification Type: **MIL Spec, TE Product Specification (114-)**
TE Certification: **Yes – Certificate Included**

Features

Other

Crimp Form-Wire Barrel Type	Closed Barrel - Confined Crescent
Tool Grade	Premium Crimp Tooling
Ratchet Configuration	Not Releasable, Not Adjustable
Die Sets Type	Fixed In Tool
Specification Type	MIL Spec, TE Product Specification (114-)
TE Certification	Yes – Certificate Included
Power Technology Type	Battery, Electric, Manual
Tooling Type	CERTI-CRIMP II, Straight Action Hand Tool

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Out of Scope
EU ELV Directive 2000/53/EC	Out of Scope
China RoHS 2 Directive MIIT Order No 32, 2016	Not reviewed for China RoHS compliance
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JAN 2025 (247) Does not contain REACH SVHC






Halogen Content	Low Halogen - Br, Cl, F < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

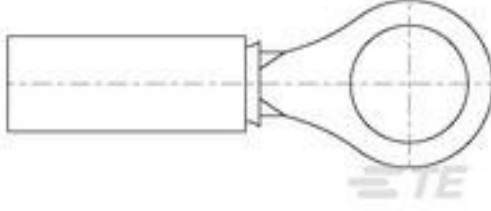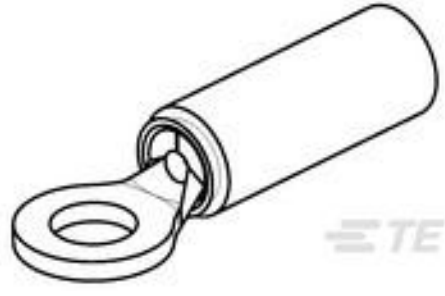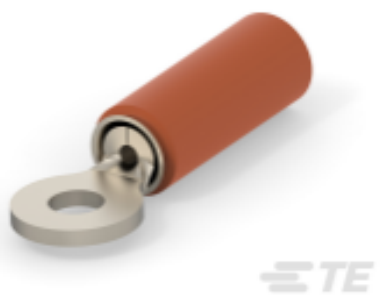 TE Part # 1577621-1 TERMINAL RT PIDG PEEK STRATO 24-22 AWG	 TE Part # 1577619-1 TERMINAL RT PIDG PEEK STRATO 24-22 AWG	 TE Part # 1577622-1 TERMINAL, PEEK PIDG STRATO, 20AWG	 TE Part # 1577624-1 TERMINAL RT PIDG PEEK STRATO 20 AWG
 TE Part # 1577625-1 TERMINAL RT PIDG PEEK STRATO 20 AWG	 TE Part # 1577618-1 TERMINAL RT PIDG PEEK STRATO 24-22 AWG	 TE Part # 1577620-1 TERMINAL RT PIDG PEEK STRATO 24-22 AWG	 TE Part # 1577623-1 TERMINAL, PEEK PIDG STRATO, 20AWG
 TE Part # 1577626-1 TERMINAL RT PIDG PEEK STRATO 20 AWG	 TE Part # 1577628-1 TERMINAL RT PIDG PEEK STRATO 20 AWG	 TE Part # 1577961-1 TERMINAL, PEEK PIDG STRATO, 24-22 AWG	 TE Part # 1577629-1 TERMINAL RT PIDG PEEK STRATO 20 AWG



TE Part # 1577617-1
TERMINAL RT PIDG PEEK STRATO 24-22 AWG




TE Part # 1577616-1
TERMINAL, PEEK PIDG STRATO, 24-22AWG



TE Part # 1577627-1
TERMINAL RT PIDG PEEK STRATO 20 AWG



TE Part # 1577962-1
TERMINAL, PEEK PIDG STRATO, 20 AWG

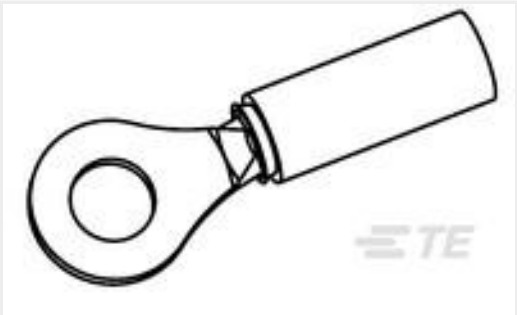

TE Part # 2067639-1
TERMINAL RT PIDG PEEK STRATO 20 AWG



TE Part # 1577960-1
TERMINAL, PEEK PIDG STRATO, 24-22 AWG




TE Part # 1577963-1
TERMINAL, PEEK PIDG STRATO, 20 AWG


Customers Also Bought



TE Part #6176350001
TMS-SCE-3/4-2.0-S1-4

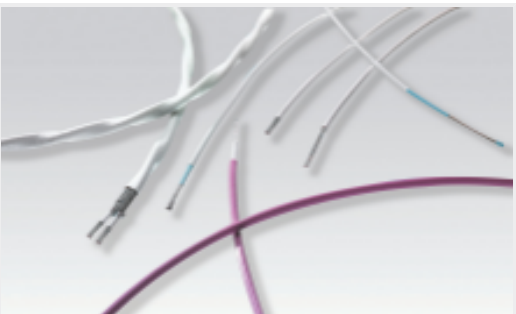

TE Part #110931-000
55PC0211-18-9

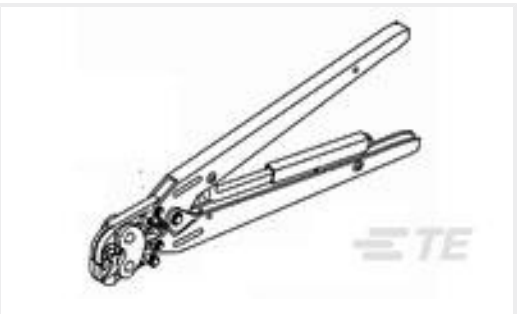


TE Part #47387
DAHT PG PIDG 20-14 ASSY




TE Part #150453
TERM, RT, STRAT, SOLIS, HR, 2, M8(5/16)




TE Part #1-525442-8
PLUG GAUGE, HANDTOOL

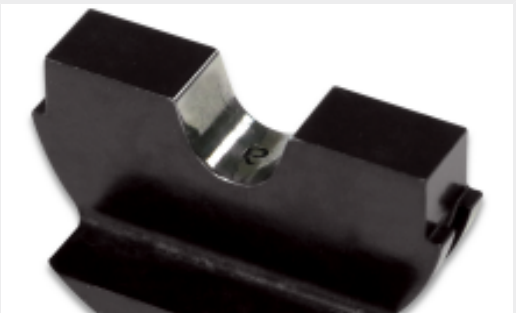

 TE Part #1490413-2
HYP10 SOLIS HD 8AWG NEST




TE Part #395241-000
AT-1319-22

 

TE Part #4956770001
TMS-SCE-3/8-2.0-6



TE Part #ZPF000000000202363
182-4042-23

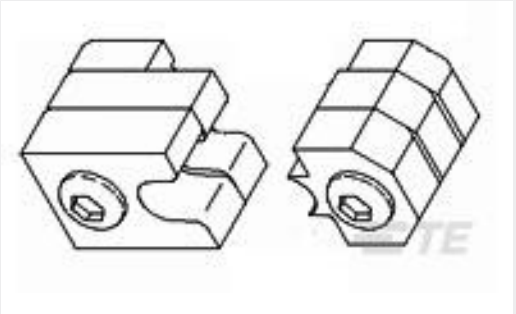

TE Part #576714
SAHT PIDG PEEK STRATO 16 DIE SET

Documents



Datasheets & Catalog Pages

Bottoming Dies

English

Instruction Sheets

Instruction Sheet (U.S.)

English