


VCF4-1002

✓ ACTIVE

TE Internal #: 4-1419106-0

TE Internal Description: VCF4-1002=CONNECTOR,HOUSING-

[View on TE.com >](#)

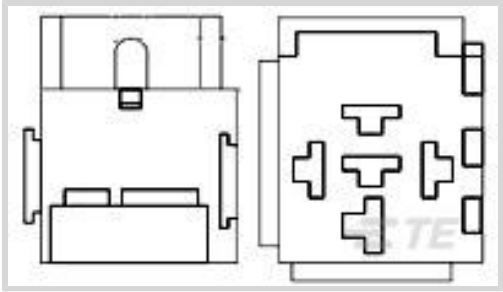

Compatible Parts

TE Part # 2-1393310-0
26A1348C=TERMINAL,CRMP,QC.250,

TE Part # 1-1393310-9
26A1348B=TERMINAL,CRMP,QC.250,

TE Part # 1-1393310-8
26A1348A=TERMINAL,CRMP,QC.250,

Customers Also Bought

TE Part #CB5346-000
SST-48-11/226

TE Part #66563-6
III+ SKT,24-20,TIN-LEAD,STRIP

TE Part #1-1393212-4
T92S7D22-12

TE Part #4-1393249-0
W58-XC4C12A-10=W58

TE Part #1-1414686-0
V23136A0004X058-EV-CBOX

TE Part #1-1423675-0
W57-XB7A4A10-20=CKTBKR,THERM,P

TE Part #304Z-05639
Speed sen DSE 0603.02 T1HV

TE Part #1-1393310-8
26A1348A=TERMINAL,CRMP,QC.250,

TE Part #1-1393310-9
26A1348B=TERMINAL,CRMP,QC.250,

TE Part #2-1393310-0
26A1348C=TERMINAL,CRMP,QC.250,

Documents

CAD Files



Customer View Model

[ENG_CVM_CVM_4-1419106-0_C.2d_dxf.zip](#)

English

[3D PDF](#)

3D

Customer View Model

[ENG_CVM_CVM_4-1419106-0_C.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_4-1419106-0_C.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

[Automotive Relay Application Notes](#)

English

[Connectors for Mini ISO, Connectors Production Production North America, Accessories](#)

English

Product Specifications

[Definitions General Purpose Relays](#)

English