



Application Tooling > Hand Crimping Tools



Tool Grade: **Premium Crimp Tooling**
Die Sets Type: **Removable/Interchangeable**
Specification Type: **MIL Spec, TE Product Specification (114-)**
TE Certification: **Yes – Certificate Included**
Power Technology Type: **Battery, Electric, Manual**

Features

Other

Crimp Form-Wire Barrel Type	Closed Barrel - Confined Crescent
Tool Grade	Premium Crimp Tooling
Die Sets Type	Removable/Interchangeable
Specification Type	MIL Spec, TE Product Specification (114-)
TE Certification	Yes – Certificate Included
Power Technology Type	Battery, Electric, Manual
Tooling Type	Die Assembly

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Out of Scope
EU ELV Directive 2000/53/EC	Out of Scope
China RoHS 2 Directive MIIT Order No 32, 2016	Not reviewed for China RoHS compliance
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JAN 2021 (211) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F < 900 ppm per homogenous material. Also BFR/CFR/PVC



Free

Solder Process Capability

Not applicable for solder process capability


Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # 1-696422-0
PIDG PVF2 22-16COM22-18MIL 1/2

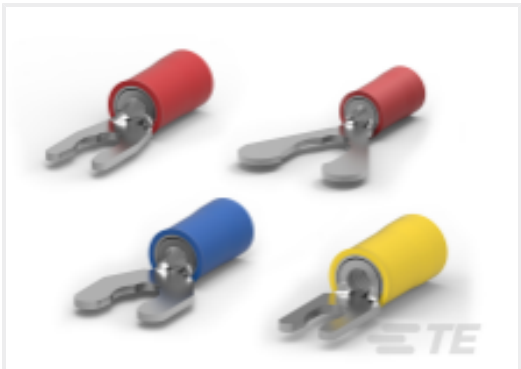

TE Part # CAT-P592-SH816
PIDG Short Spring Spade Tongue Terminals



TE Part # CAT-P592-R472A
PIDG Ring Tongue Terminals



TE Part # 696422-9
PIDG PVF2 22-16COM22-18MIL 3/8



TE Part # 151467
22-16 PIDG LIPPED BLADE EXP.1



TE Part # 8-52950-1
PG SPR SPD 22-16COMM 22-18MIL8



TE Part # 8-34148-1
PG R 22-16 COMM 22-18 MIL 8



TE Part # 8-322249-1
PG SPD FLG 22-16COMM22-18MIL 6



TE Part # 130861
PIDG WIRE TIP



TE Part # 171508-2
PIDG WIRE TERM, #8, 22-16 AWG



TE Part # 171507-1
PIDG RING UL.CSA(22-18)



TE Part # 171505-2
PIDG RING UL.CSA(22-18)



TE Part # 342105-1
TERM, RT, PLASTI-GRIP, 22-16, M6[1/4]

TE Part # 52949
PG SPR SPD 22-16COMM 22-18MIL6

TE Part # 54774-1
PG R 22-16COM22-18MIL 6-8-10

TE Part # 54774-2
PG R 22-16COM 22-18MIL 6-8-10

TE Part # 53241-1
PG SPR SPD 22-16COMM 22-18MIL8

TE Part # 53242-2
PG SPR SPD 22-16COM22-18MIL 10

TE Part # 53242-5
PG SPR SPADE SHORT 22-16 10

TE Part # 34146
PG R 22-16 COMM 22-18 MIL 10

Customers Also Bought

TE Part #CAT-D48-ST273
DEUTSCH Solid Contacts

TE Part #CAT-D487-W416
Wedgelocks: DEUTSCH DT

TE Part #DT06-2S
PLG, 2P, GRY, N

TE Part #DT04-2P
REC, 2P, GRY, N

TE Part #206070-8
CABLE CLAMP KIT #17

TE Part #281934-2
SINGLE WIRE SEAL

TE Part #CAT-AM71-CH8172
AMP SUPERSEAL 1.5MM, CONNECTOR HOUSING

Documents

Datasheets & Catalog Pages

Bottoming Dies

English

Instruction Sheets

C-Head Adapter Battery Powered Crimp Tool Kit, PN 2844990-[]

C-Head Adapter Battery Powered Crimp Tool Kit, PN 2844990-[]

C-Head Adapter Battery Powered Crimp Tool Kit, PN 2844990-[]



German

[C-Head Adapter Battery Powered Crimp Tool Kit, PN 2844990-\[\]](#)

French

[C-Head Adapter Battery Powered Crimp Tool Kit, PN 2844990-\[\]](#)

[C-Head Adapter Battery Powered Crimp Tool Kit, PN 2844990-\[\]](#)

English