

6-1579008-9  ACTIVE

MQS

TE Internal #: 6-1579008-9

Secondary Housing Lock, Insertion & Extraction Tools

[View on TE.com >](#)



Application Tooling > Insertion & Extraction Tools



Insertion & Extraction Tool Type: **Secondary Housing Lock**

Features

Product Type Features

Insertion & Extraction Tool Type

Secondary Housing Lock

Product Compliance

[For compliance documentation, visit the product page on TE.com >](#)

EU RoHS Directive 2011/65/EU

Compliant

EU ELV Directive 2000/53/EC

Out of Scope

China RoHS 2 Directive MIIT Order No 32, 2016

No Restricted Materials Above Threshold

EU REACH Regulation (EC) No. 1907/2006

Current ECHA Candidate List: JAN 2025

(247)

Candidate List Declared Against: JAN 2023
(233)

SVHC > Threshold:

Pb (.21% in Component Part)

Article Safe Usage Statements:

Do not eat, drink or smoke when using this product. Wash thoroughly after handling. Recycle if possible and dispose of the article by following all applicable governmental regulations relevant to your geographic location.

Halogen Content

Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free

Solder Process Capability

Not applicable for solder process capability

Product Compliance Disclaimer

 
This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides

on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # 6-962885-6
MQS BUCHS-KONT EDS



TE Part # 2479013-1
MQS 2P 0.63, TERMINAL, SWS, LL 0.25-0.35



TE Part # CAT-M8793-T273
MQS, RECEPTACLE AND TAB



TE Part # 5-962886-3
MQS0,63 Ag tab LL EDS 0,2-0,5



TE Part # 5-963727-6
MQS SOCKET CONTACT SWS



TE Part # 5-965908-3
MQS0,63 Ag tab LL EDS 0,5-0,75



TE Part # 2479013-6
MQS 2P 0.63, TERMINAL, SWS, AG, LL 0.25-0.35

Customers Also Bought



TE Part #CAT-R21-731072
Bulbous Heat Shrink Boots: Lipped, Straight



TE Part #K1152919
Limit switch G12-421-M-18



TE Part #K1152921
Limit switch G13-01-1819



TE Part #K1160758
Plunger Switch 44-01-069




TE Part #K1160973
Power Relay 29-251-11-907



TE Part #K1154427
Battery Disconnector 35-524-241-R-900



TE Part #610643-000
222K174-100/86-0

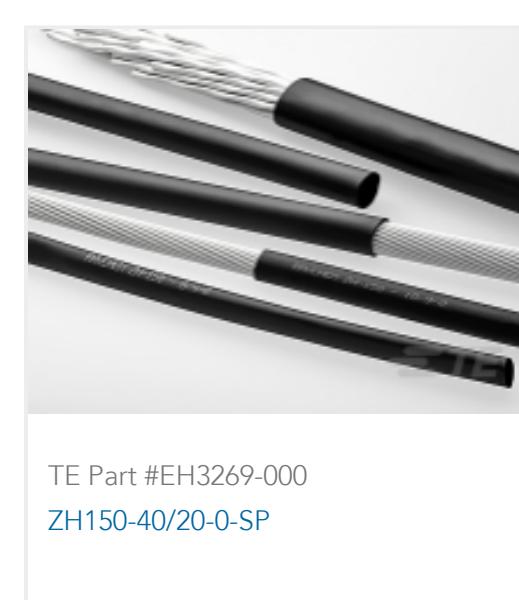

TE Part #EH3269-000
ZH150-40/20-0-SP

Documents

Product Drawings

LOCKING TOOL

English

Datasheets & Catalog Pages

CRIMPING TERMINALS

English

CRIMPING WHERE FORM MEETS FUNCTION

English