

MR1000 SERIES DETECTOR SWITCH

ANTI-VANDAL
SWITCHES

DETECTOR
SWITCHES

DIP
SWITCHES

KEYLOCK
SWITCHES

NAVIGATION
SWITCHES

PUSHBUTTON
SWITCHES

ROCKER
SWITCHES

ROTARY
SWITCHES

SLIDE
SWITCHES

SNAP ACTION
SWITCHES

TACTILE
SWITCHES

TOGGLE
SWITCHES

CAP
OPTIONS




APPLICATIONS / MARKETS



Commercial Appliances



Security Devices

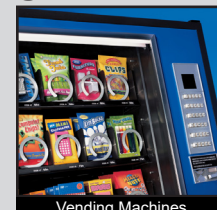

Vending Machines



HVAC



Industrial Controls



Medical Equipment

RoHS

SPECIFICATIONS

Contact Rating: 0.5A, 10VAC or 10VDC
Contact Resistance: 150 mΩ
Contact Arrangement: SPST N.O.

FEATURES & BENEFITS

- Recessed switch
- Magnetic contact
- 9.52 [0.375 in] Press fit
- 457.20 [18.000 in] #22AWG wire leads
- Closed gap options

PART NUMBER CONFIGURATOR

Series



MR1000

DIM "X"



A - 19.0 [0.75 in]
 B - 25.0 [1.00 in]

Housing Color



W - White

Lead Length



A - 457.20 [18.000 in]

Specifications subject to change without notice 11.7.2018



E-SWITCH®



www.e-switch.com

800.867.2717

1

MR1000 SERIES DETECTOR SWITCH

BODY DIMENSIONS

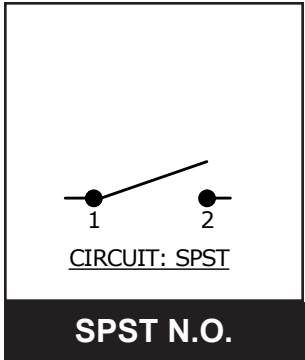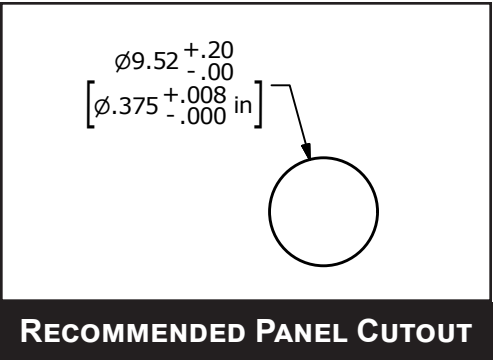

	DIM "X"±1.0 [0.39]	DIM "X"±1.0 [0.39]
CLOSED GAP	A = 19.0 [0.75 in]	B = 25.0 [1.00 in]
DEPARTURE GAP	A = 22.0 [0.87 in]	B = 28.0 [1.10 in]

