

# SERIES RP3508 SWITCHES

## PUSHBUTTON SWITCHES - ILLUMINATED



### FEATURES & BENEFITS

- Panel mount
- Illuminated
- Standard green, red and yellow LED options

### APPLICATIONS/MARKETS

- Telecommunications
- Networking
- Computers/servers
- Performance audio
- Instrumentation
- Low power on/off designs
- External hard drives and modems

### SPECIFICATIONS

Contact Rating: 3A@125 VAC  
1.5A@250 VAC

Life Expectancy (Mechanical):  $\geq 20,000$  cycles

Life Expectancy (Electrical):  $\geq 6,000$  cycles

Insulation Resistance:  $> 1,000M\ \Omega$

Dielectric Strength:  $> 1,500$  volts 1 minute


Operating Temperature: 0°C to +65°C

Storage Temperature: -25°C to +85°C

### MATERIALS

Switch Housing: UL94-HB  
Terminals: Solder lug, silver-plated

### ► ► ► HOW TO ORDER

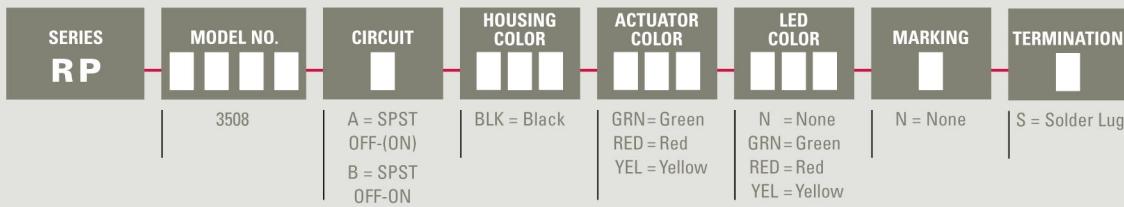

### ► ► ► Example Ordering Number

RP-3508-A-BLK-RED-GRN-N-S

Specifications subject to change without notice.

### RP 3508

