

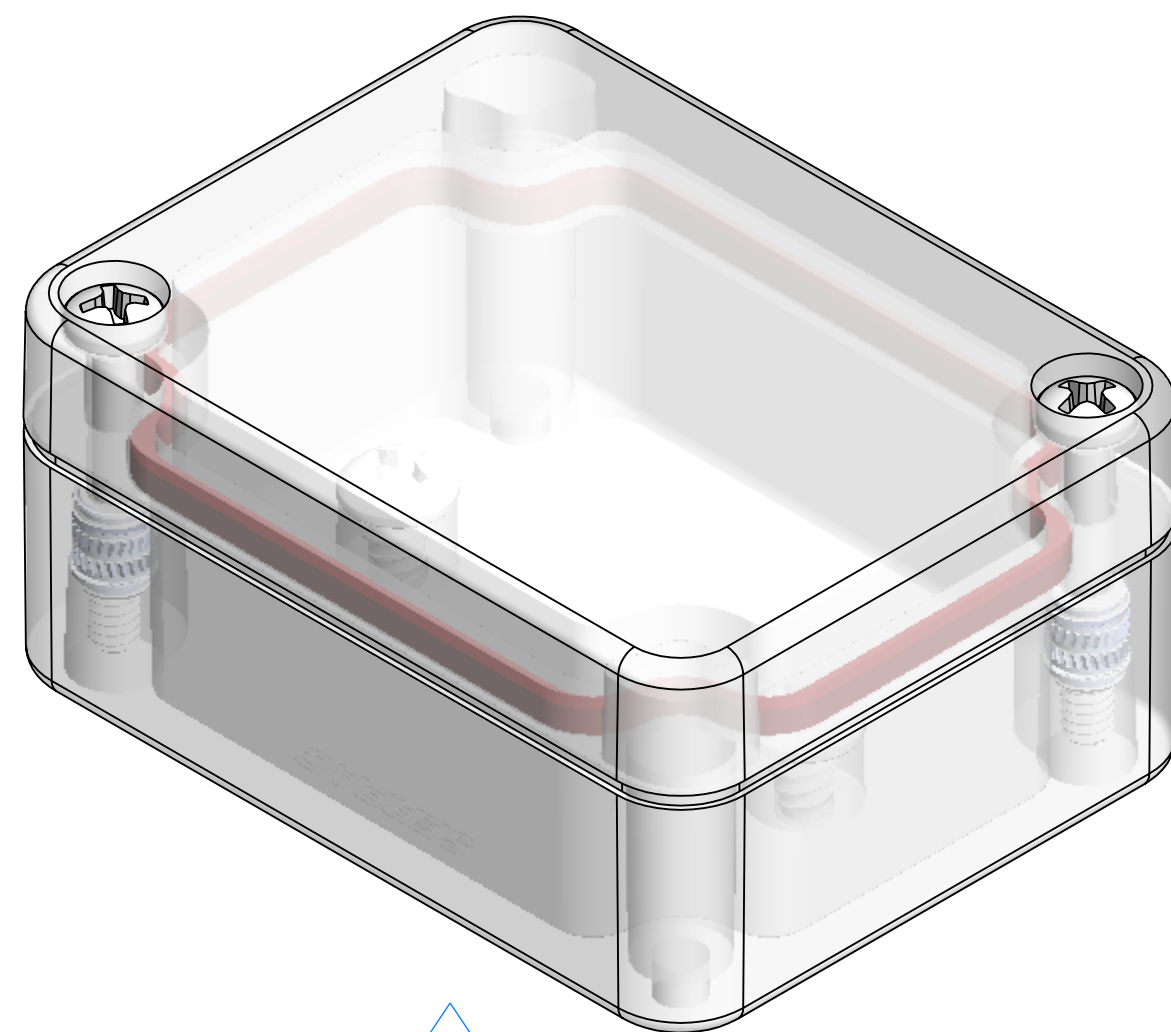
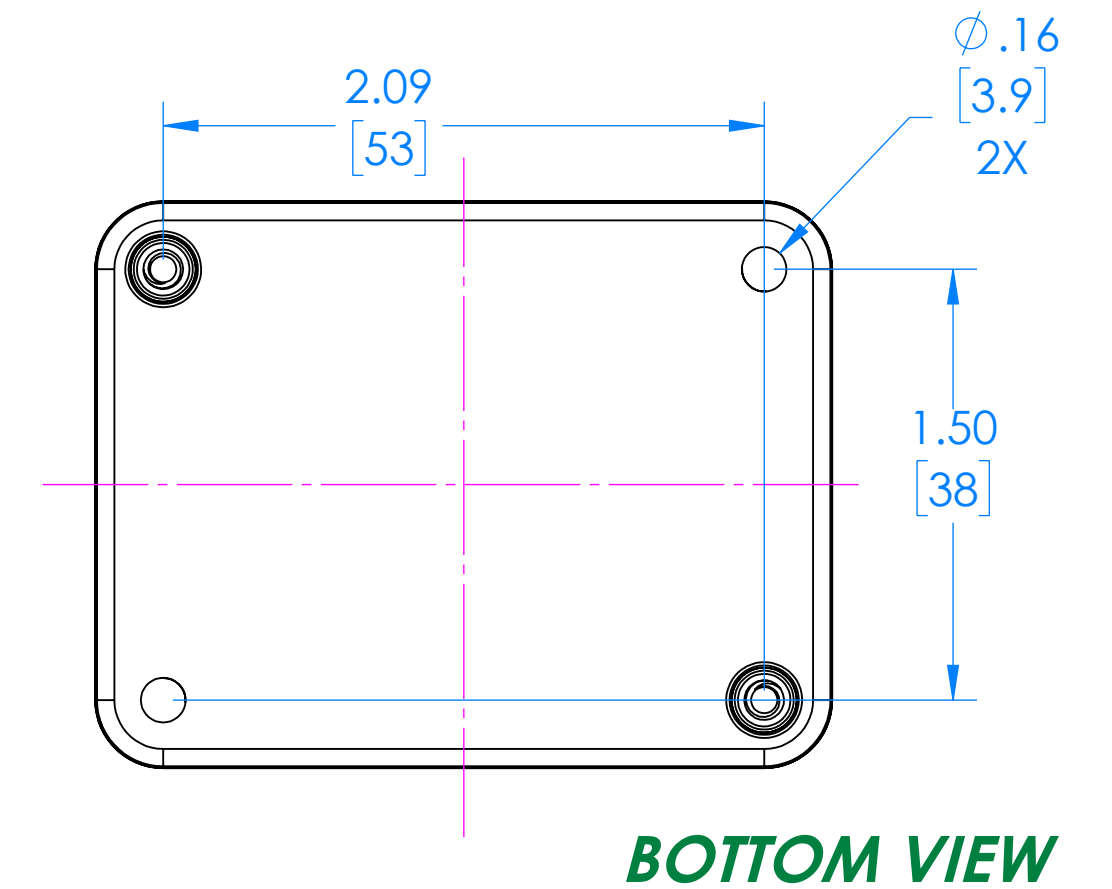
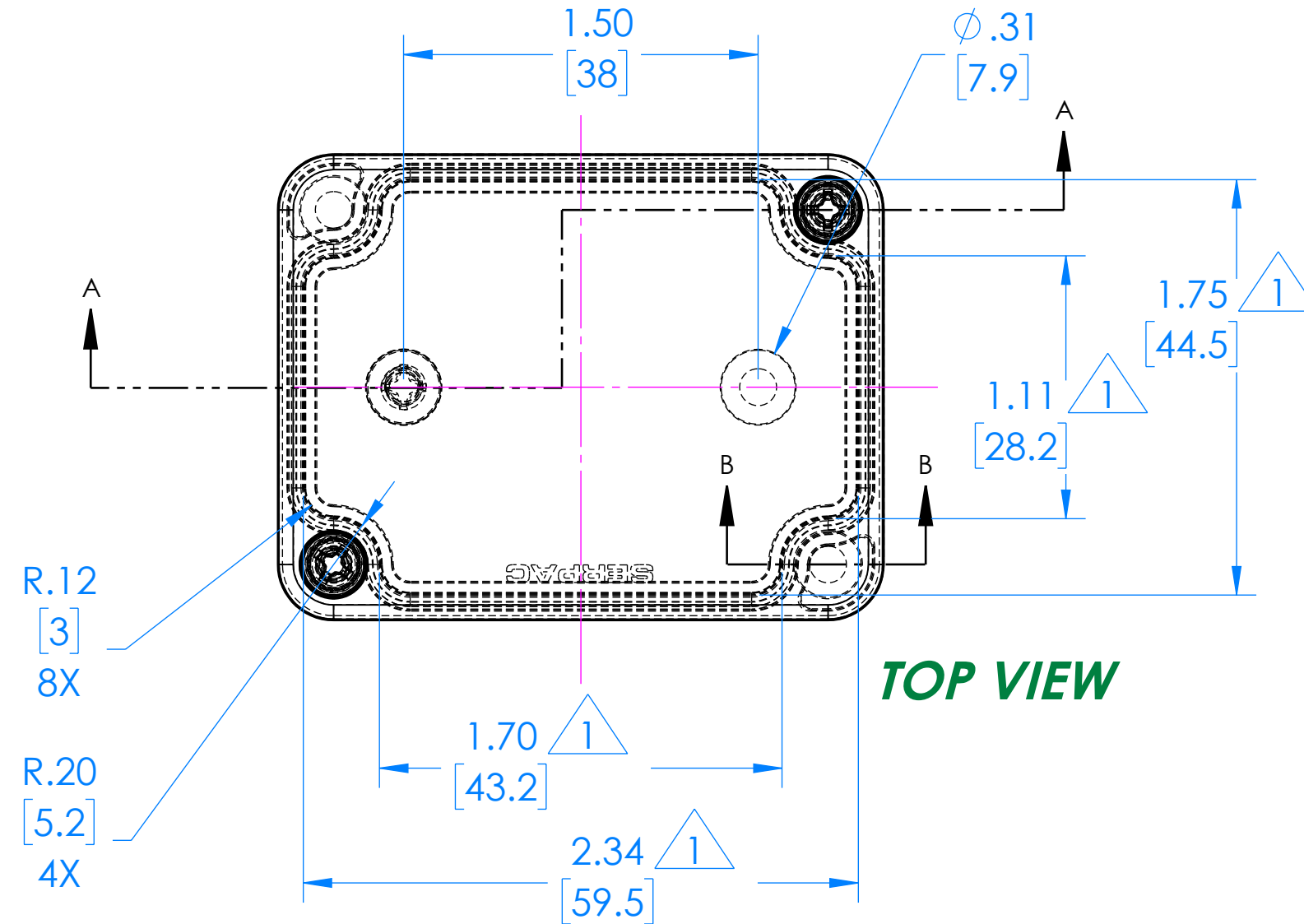


SERPAC RB32X04Y08Y 2


Electronic Enclosures

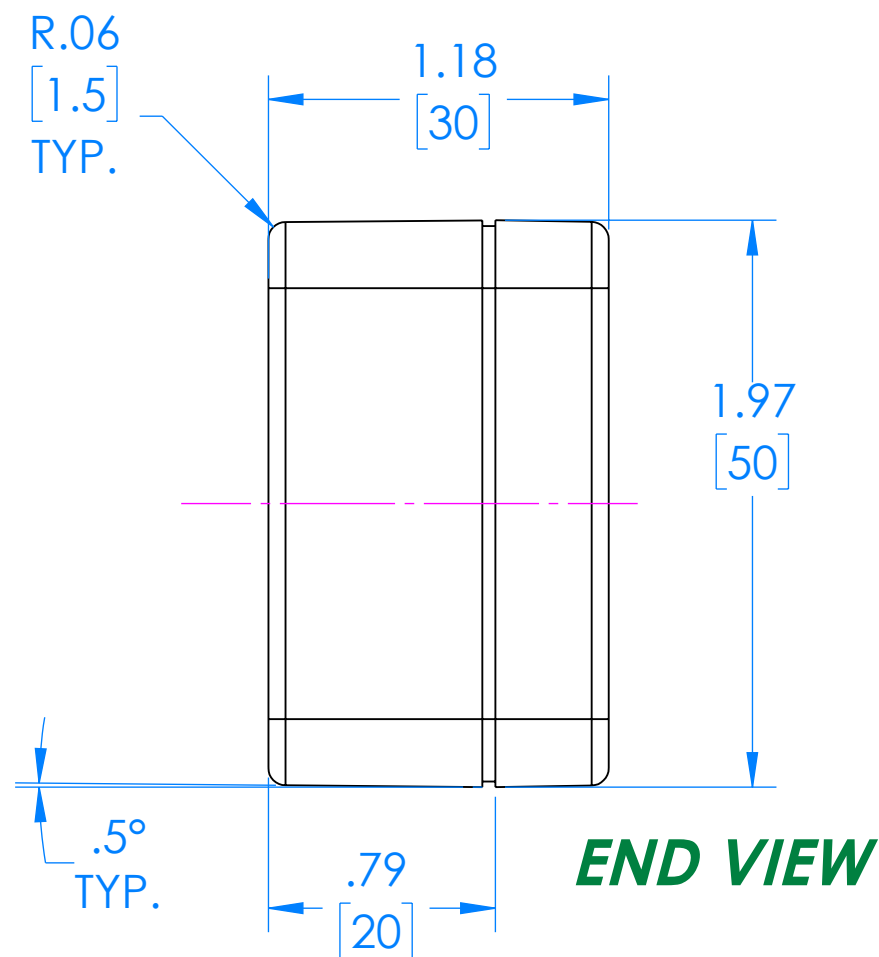


RB32X04C08C 2
(Part shown, no material (X) specified)

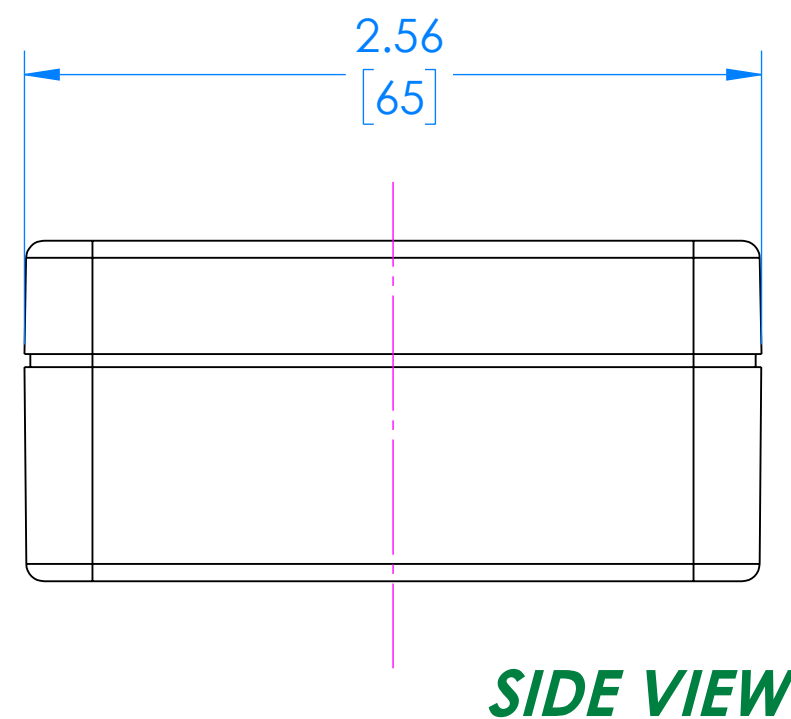

SECTION B-B

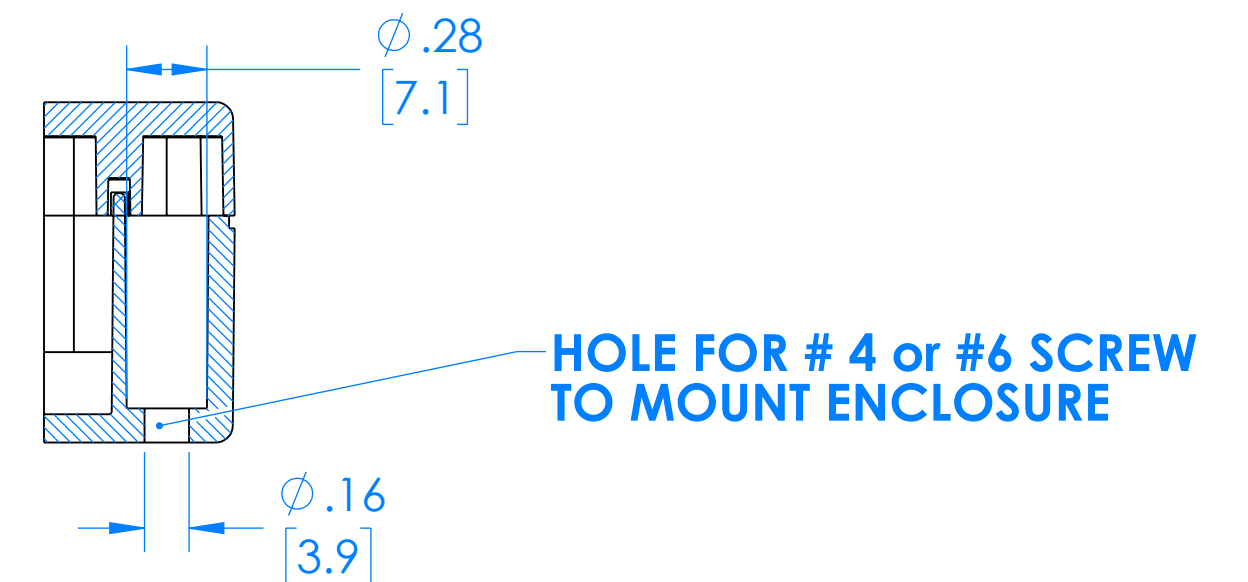

PN-8032 O-Ring

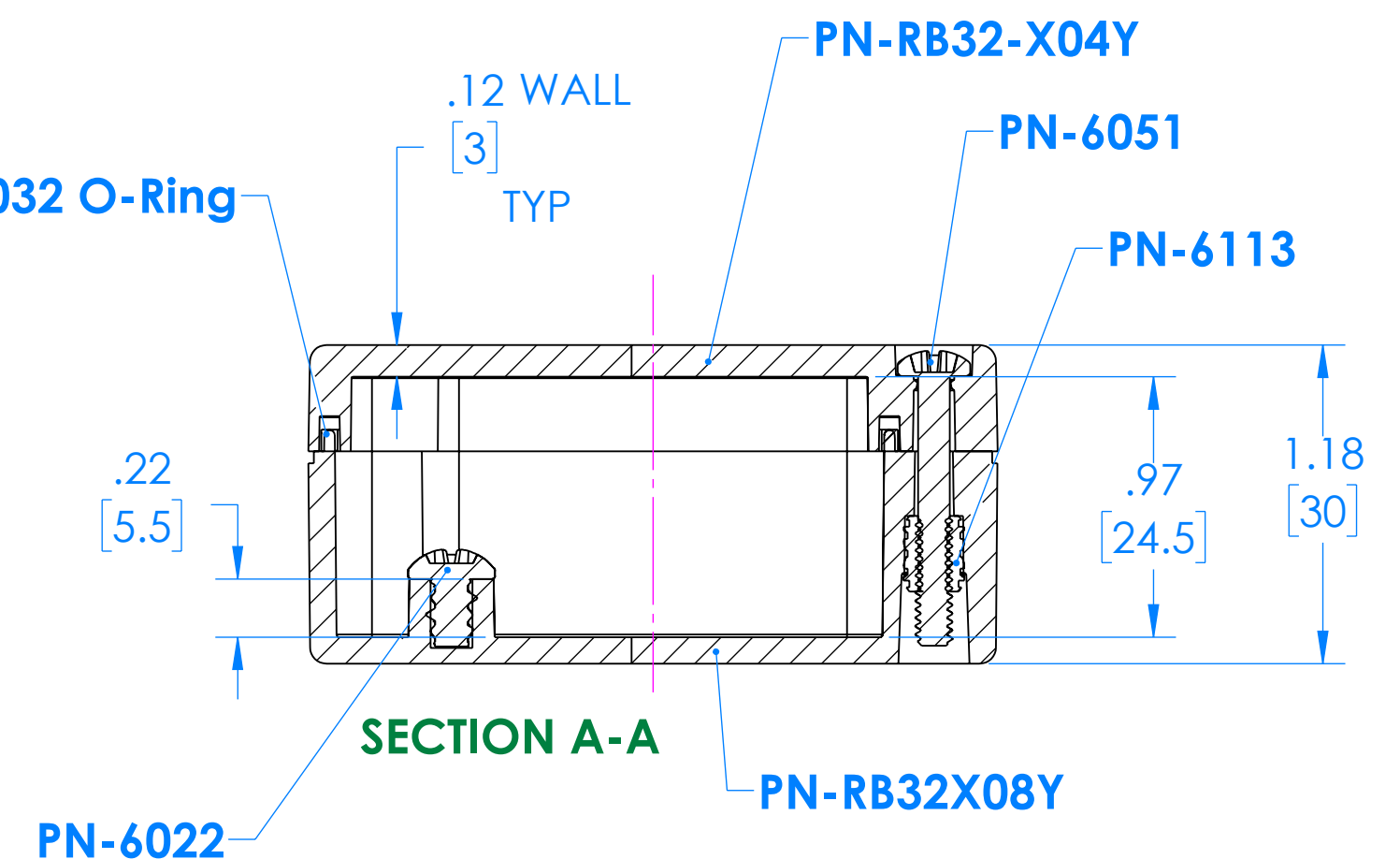

PN	Description
RB32-X04Y	(1) RB32-X04Y, Top
RB32X08Y	(1) RB32X08Y, Bottom
8032	(1) RB32 O-Ring
6051	(2) #6-32 Captive PH Hd Screw
6022	(2) #10 High/Low Pan Hd x 1/4"
6113	(2) #6-32 Threaded Insert

- 1 =INTERIOR DIMENSIONS (@ BOTTOM)
- 2 =STANDARD COLORS (Y) ARE: BLACK (B), CLEAR (C) AND GRAY (G)
TOPS AND BOTTOMS ALL POSSIBLE COMBINATIONS AVAILABLE
STANDARD MATERIALS (X) IS: POLYCARBONATE (P)


-Watertight enclosure meets or exceed Nema 4 and or IP67.

DIMENSIONS in Inch
[mm]

ALL DIMENSIONS ARE $\pm .010"$
2009 Wright Ave, La Verne, Ca. 91750
Ph. (626) 331-0517 Fx. (626) 331-8584 serpac.com

5/5/2023

RB32 Circuit Board (Fits all Parts starting with RB32)

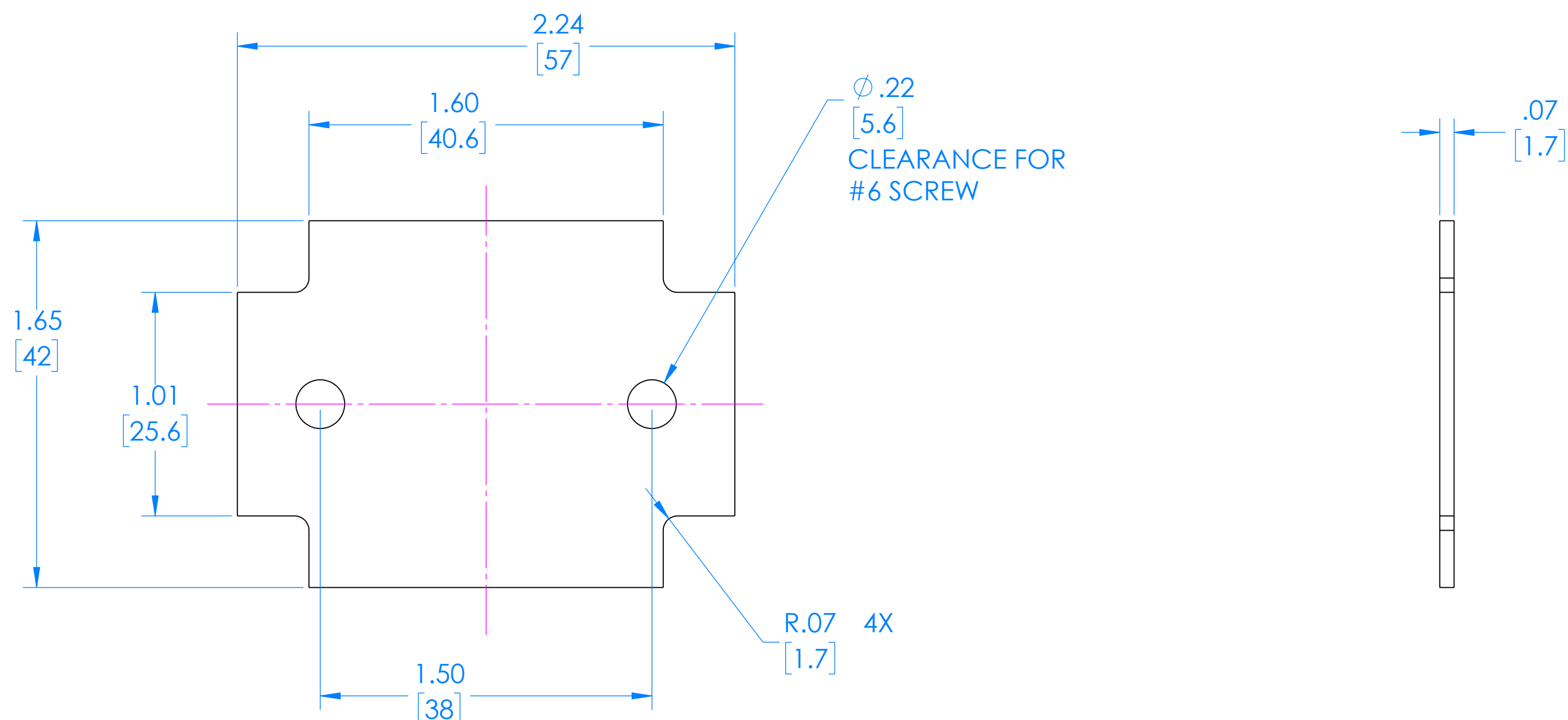

(REFERENCE ONLY)