
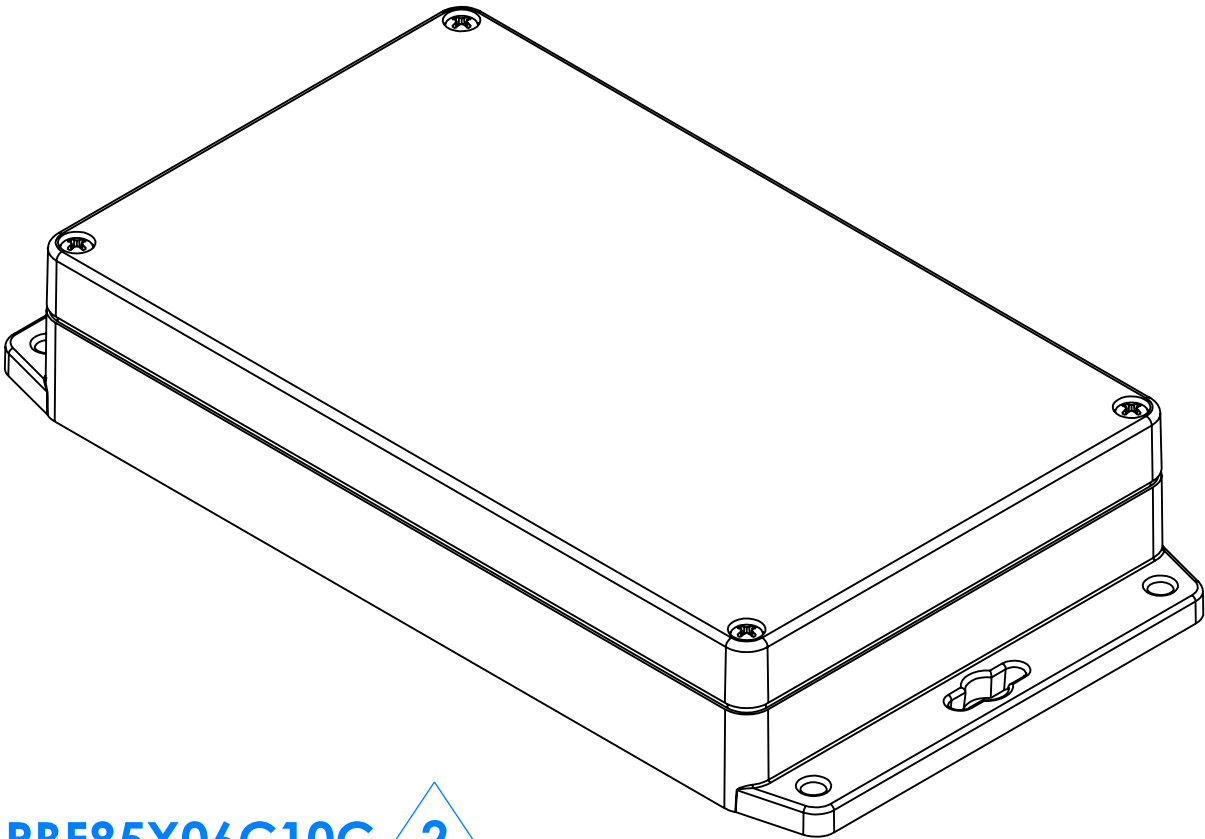




SERPAC RBF85X06Y10Y

Electronic Enclosures

2

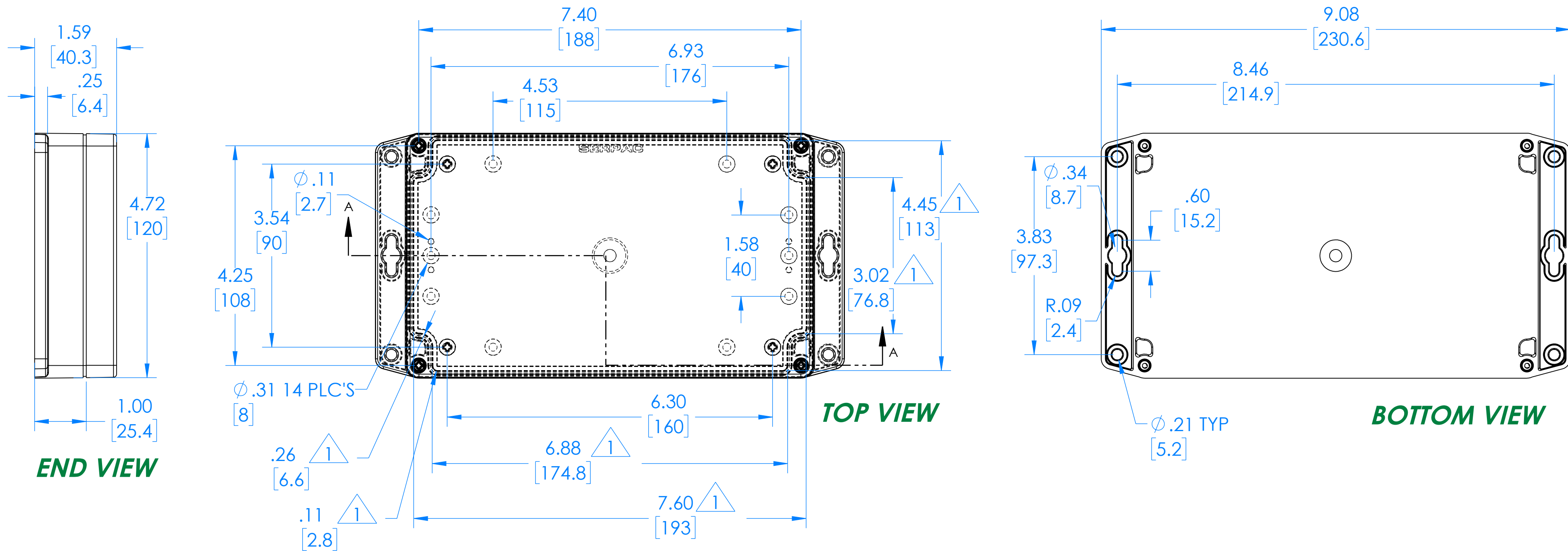

RBF85X06C10C 2
(Part shown, no material (X) specified)

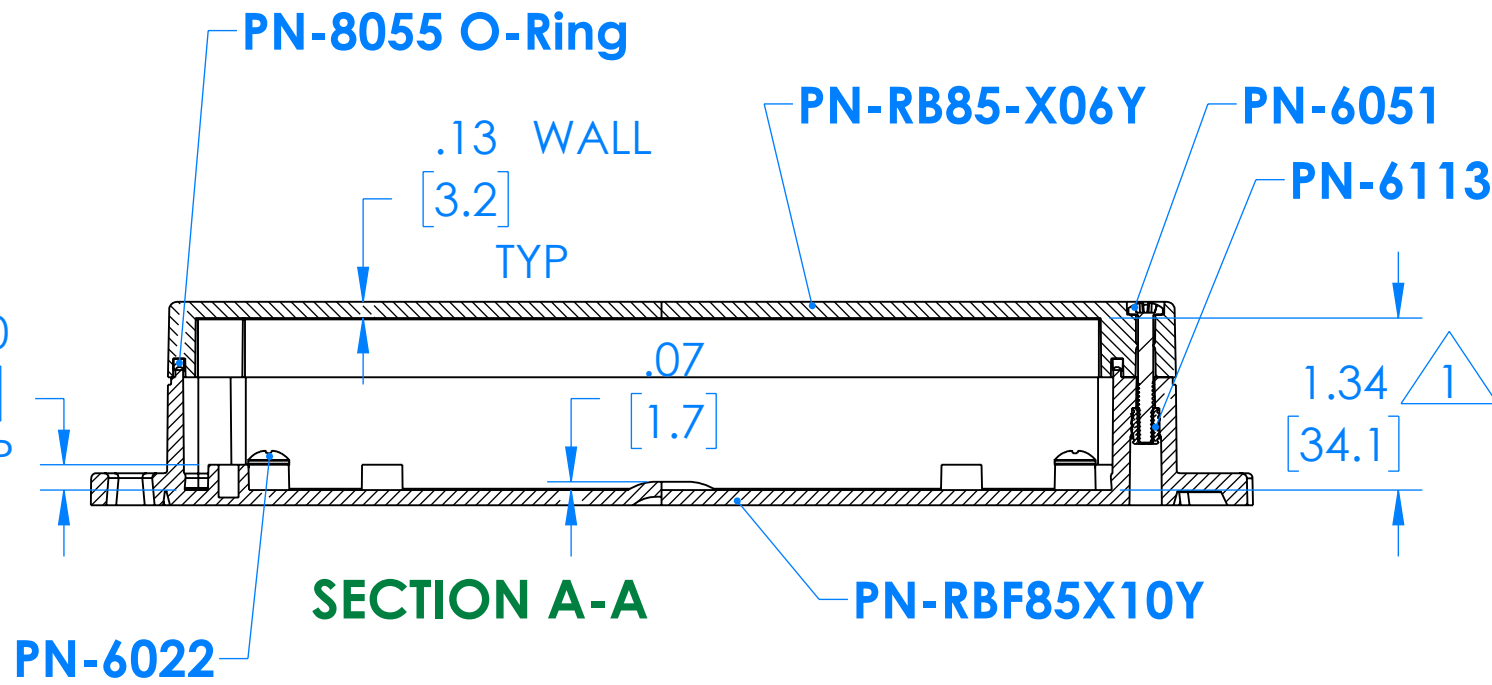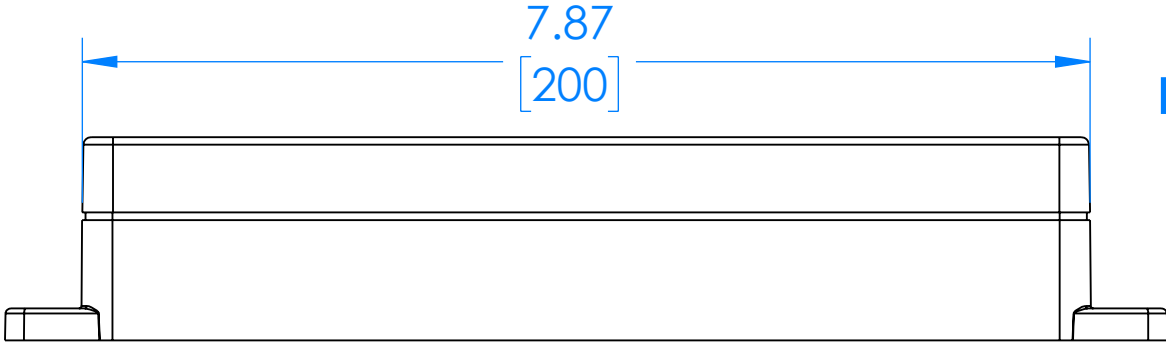

PN	Description
RB85-X06Y	(1) RB85-X06Y, Top
RBF85X10Y	(1) RBF85X10Y, Bottom
8085	(1) RB85 O-Ring
6051	(4) #6-32 X 1" Captive Ph Pan Hd Screw
6022	(4) #10 High/Low Pan Hd x 1/4"
6113	(4) #6-32 Threaded Insert

- 1 =INTERIOR DIMENSIONS (@ BOTTOM)
- 2 =STANDARD COLORS (Y) ARE: BLACK (B), CLEAR (C) AND GRAY (G)
TOPS AND BOTTOMS ALL POSSIBLE COMBINATIONS AVAILABLE
STANDARD MATERIALS (X) IS: POLYCARBONATE (P)


-Watertight enclosure meets or exceed Nema 4 and or IP67.

DIMENSIONS in Inch [mm]

ALL DIMENSIONS ARE ± .010" 5/10/2023
2009 Wright Ave., La Verne, CA. 91750
Ph. (626) 331-0517 Fx. (626) 331-8584 serpac.com

SERPAC
Electronic Enclosures

RBF85 Circuit Board (Fits all Parts starting with RBF85)

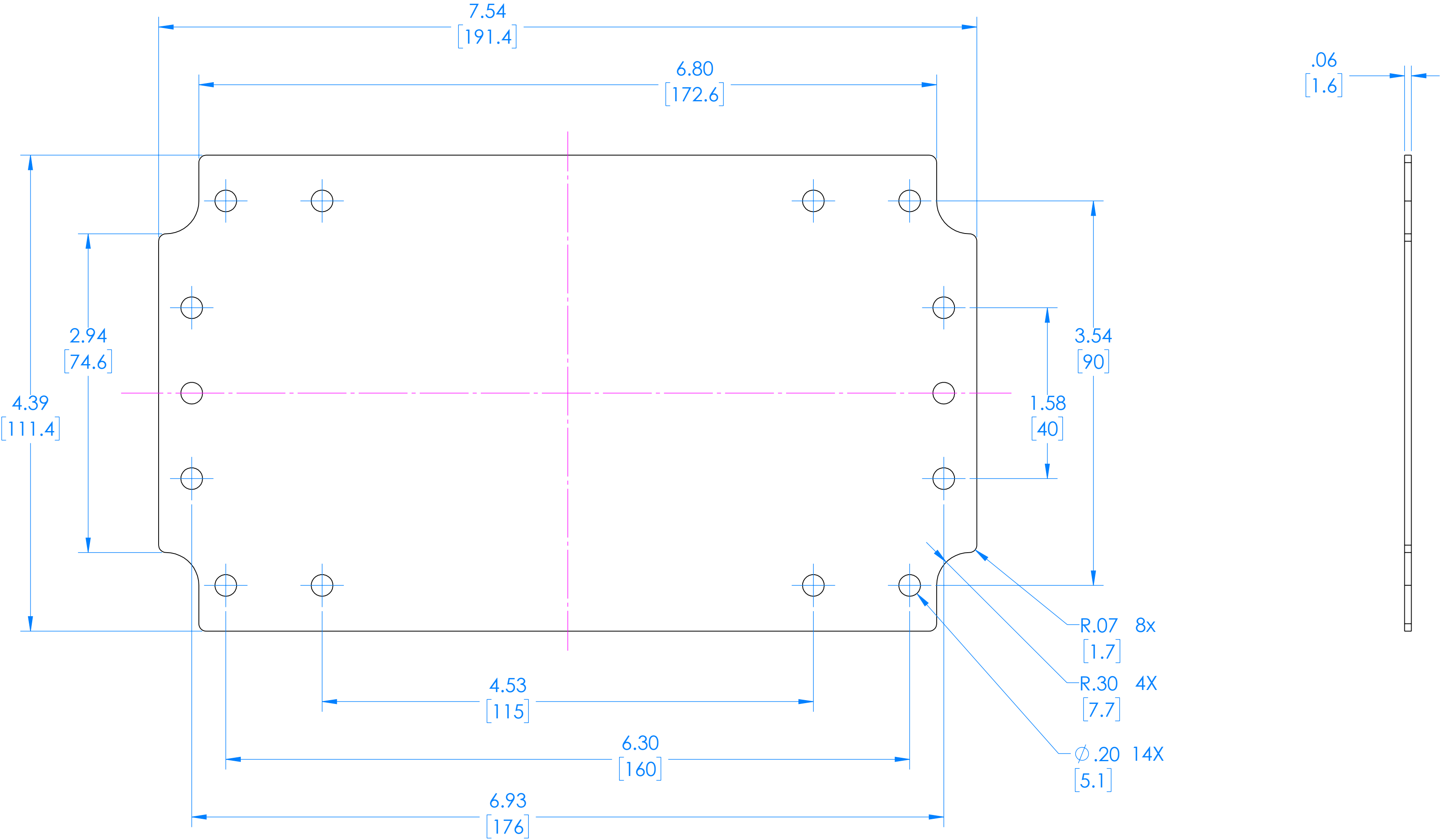

(REFERENCE ONLY)