


SERPAC

WM011i






ELECTRONIC ENCLOSURES

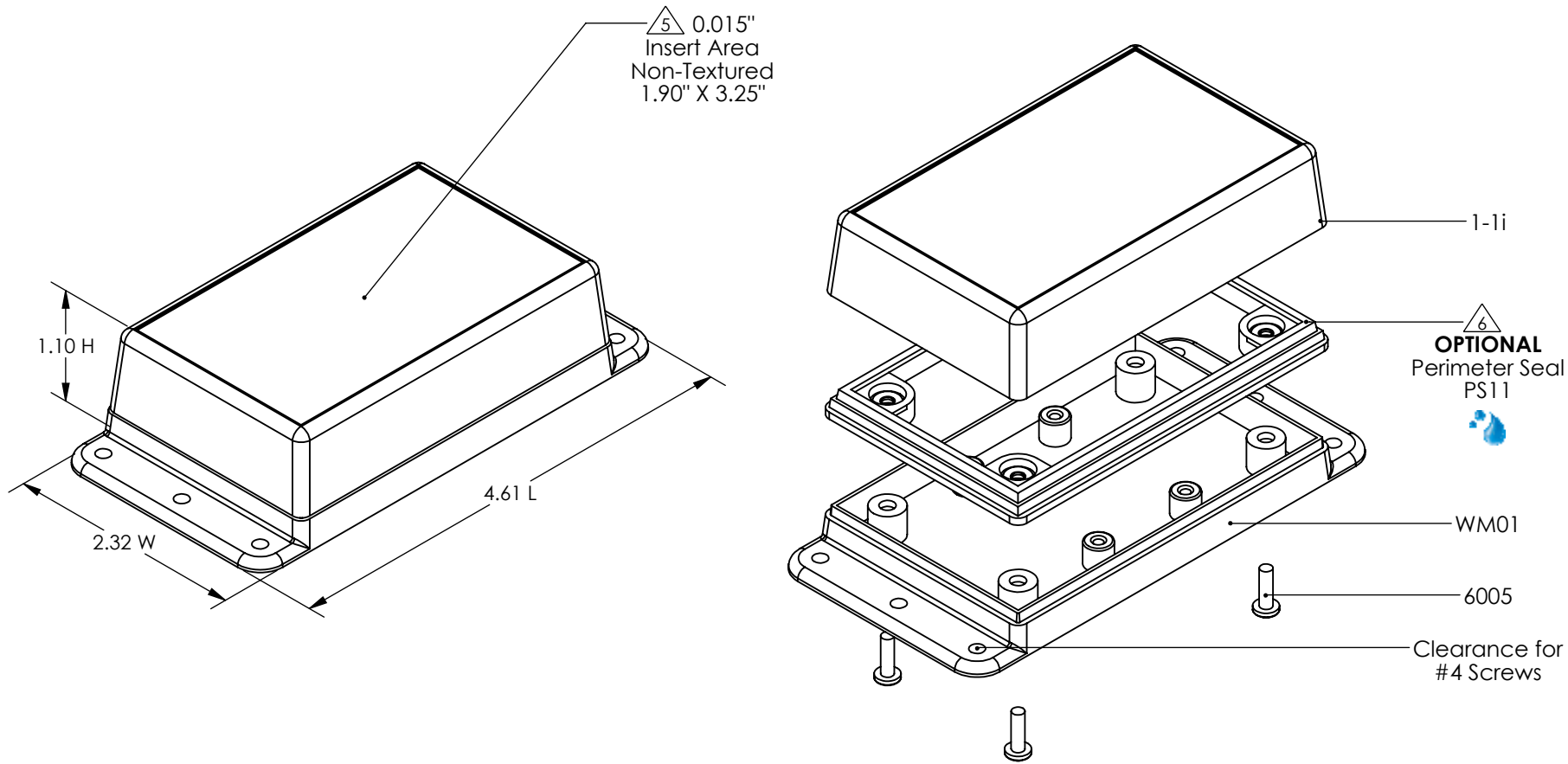

PART NO.	DESCRIPTION (Included)	ACCESSORIES (Optional)
1-1i	Top	PART NO. DESCRIPTION
WM01	Wall Mounted Bottom	60 Standoff Hole
6005	#4X3/8" Self-Tapping Screw (4)	61 Standoff Post
		PS11 Waterproof Perimeter Seal

Notes: Enclosure weight .12 lb / 56 g
1) Enclosure meets or exceeds IP40 and NEMA 1
2) Circuit Board drawings see sheet 3.
3) All components are RoHS Compliant.
4) Material: Top and Bottom ABS.
5) Customizable molding areas. $\triangle 5$
6) When used with PS11 the enclosure meets or exceeds IP 67 and NEMA 4X, 12 and 13 MIL-STD-810G 506.5 (.01 lb / 7g) $\triangle 6$

SERPAC WM011i
ELECTRONIC ENCLOSURES

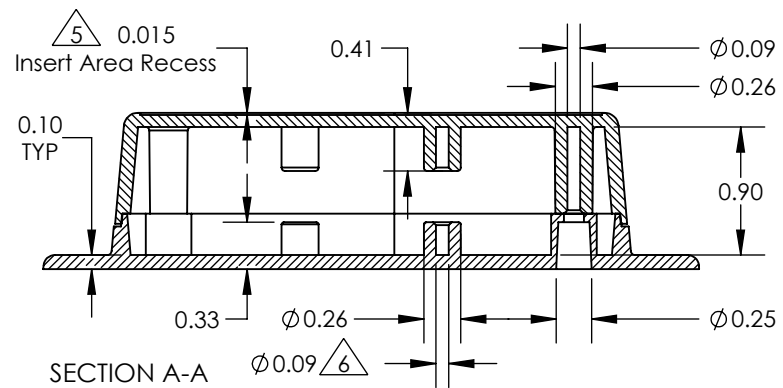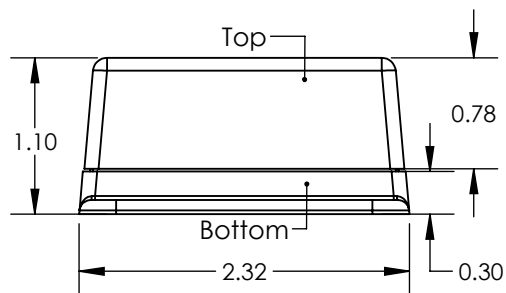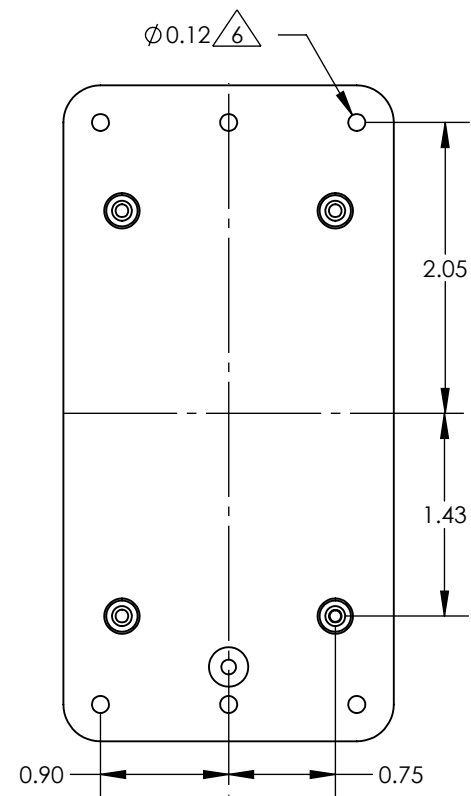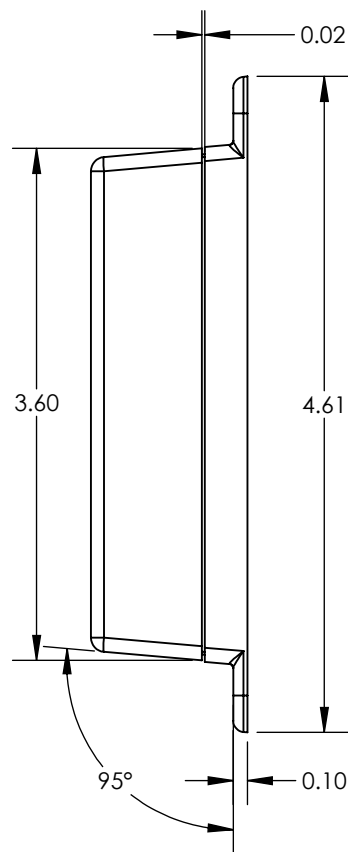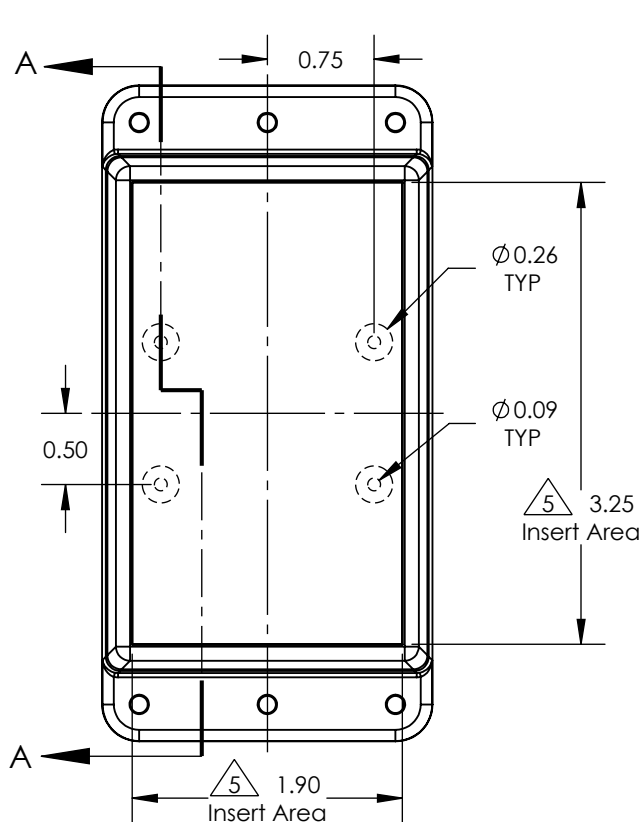

Notes:

Enclosure weight .12 lb / 56 g

1) Enclosure meets or exceeds IP40 and NEMA 1

2) Circuit Board drawings see sheet 3.

3) All components are RoHS Compliant.

4) Material: Top and Bottom ABS.

5) Customizable molding areas. 

6) Accepts #4 self tapping screw. 

7) When used with PS11 the enclosure meets or exceeds IP 67 and NEMA 4X, 12 and 13 MIL-STD-810G 506.5 (.01 lb / 7g)

SERPAC WM011i CIRCUIT BOARD

ELECTRONIC ENCLOSURES

Top & Bottom Option

