

Full stainless steel variant successfully passes
96-hour salt spray testing per ASTM B117

SPECIFICATIONS:

MATERIALS:

HOUSING:

PBT, UL94 V-0, BLACK

CONTACTS:

GOLD PLATED BRASS

(SEE P/N KEY BELOW)

SHELL:

(SEE P/N KEY BELOW)

NUT:

(SEE P/N KEY BELOW)

ORING:

EPDM, BLACK

ELECTRICAL:

RATED CURRENT:

4A

RATED VOLTAGE:

250V

INSULATION RESISTANCE:

100 MOhms MIN.

CONTACT RESISTANCE:

10 mOhms MAX.

ENVIRONMENT:

OPERATING TEMPERATURE: -40°C TO +85°C


IP67

861-004-113R00Y

3 = BRASS/NICKEL SHELL & NUT
5 = STAINLESS STEEL SHELL & NUT

1 = GOLD FLASH

4 = 10μ" GOLD

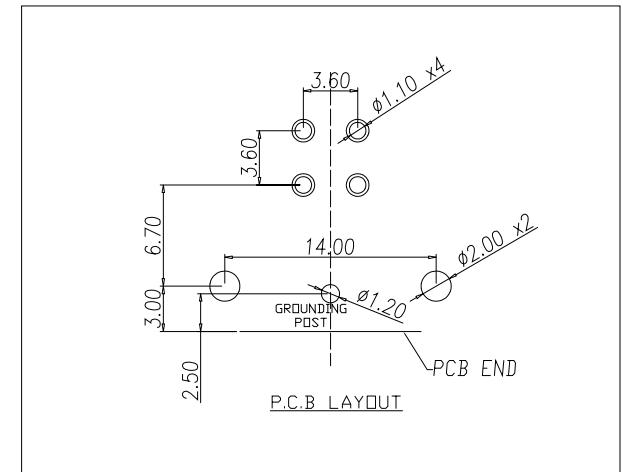

RoHS COMPLIANT



THESE DRAWINGS AND SPECIFICATIONS ARE
THE PROPERTY OF NorComp AND SHALL NOT
BE REPRODUCED, COPIED OR USED AS THE
BASIS FOR THE MANUFACTURE OR SALE OF
APPARATUS WITHOUT WRITTEN PERMISSION.

DRAWN:

M. SIGMON

DATE:

03/07/2016

TOLERANCE

.x ±0.20
.xx ±0.10
.xxx ±0.05
.xxxx ±0.03
ANGULAR ±1°

UNITS = mm

NorComp

SCALE:	1	OF	REV
NTS	1	1	5
DWG NO.			861-004-113R00Y

DO NOT SCALE FROM DRAWING