

DESCRIPTION: 25P MALE / 25P FEMALE GENDER CHANGER

SPECIFICATIONS:

MATERIALS:

HOUSING:

PBT, UL94 V-0

CONTACTS:

GOLD FLASH PLATED BRASS

SHELL:

TIN PLATED STEEL

ELECTRICAL:

RATED CURRENT:

5A

WORKING VOLTAGE:

250V

INSULATION RESISTANCE:






1000 MOhms MIN.

CONTACT RESISTANCE:

15 mOhms MAX.

ENVIRONMENT:

OPERATING TEMPERATURE: -55°C TO +105°C

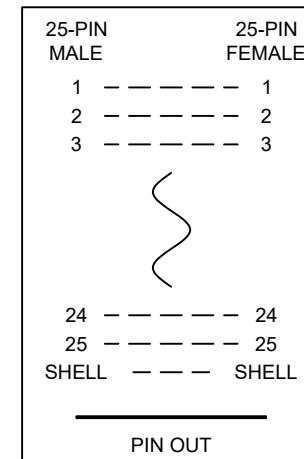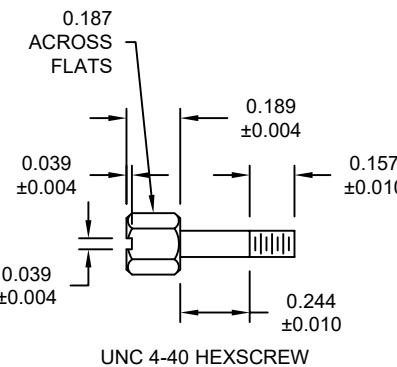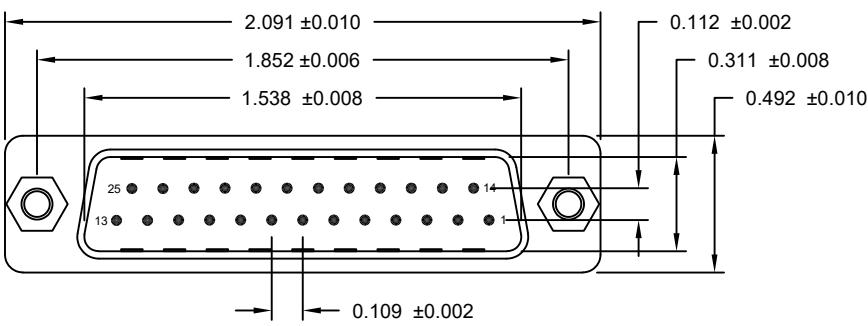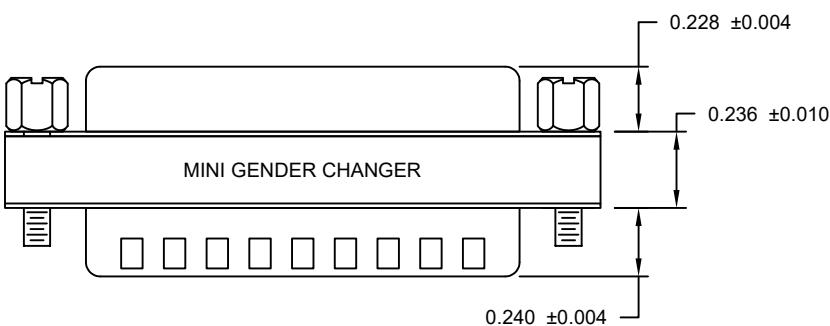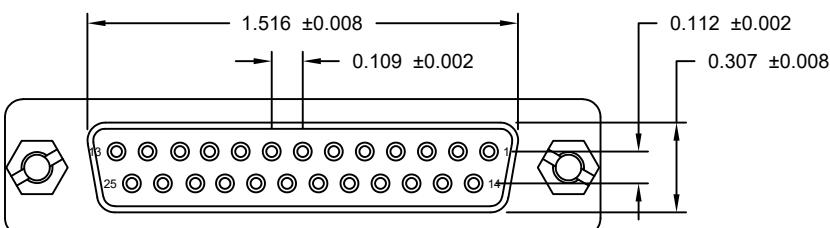

RoHS COMPLIANT



THESE DRAWINGS AND SPECIFICATIONS ARE THE PROPERTY OF NorComp AND SHALL NOT BE REPRODUCED, COPIED OR USED AS THE BASIS FOR THE MANUFACTURE OR SALE OF APPARATUS WITHOUT WRITTEN PERMISSION.

DRAWN:
C. SMITH
DATE:
10/12/2007

UNITS = inch [mm]

DO NOT SCALE FROM DRAWING

NorComp

SCALE: NTS	SHEET 1 OF 1	REV 3
DWG NO. GCLP25M25F		