
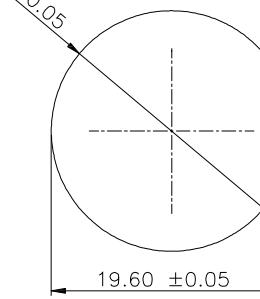


Nut - Torque Spec (0.56 Nm)

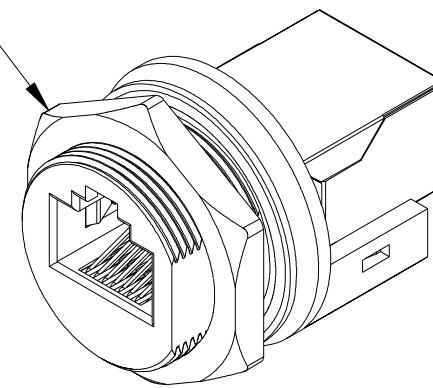

Panel Cut-Out  
Panel Thick: 1.5~2.0mm

#### Materials:

Plastic Housing: Engineering Thermoplastic Flammability Rating UL 94V-0

Gasket: Silicone

Contacts: Phosphor Bronze, Gold Flash over Nickel Plating

Nut: Engineering Thermoplastic Flammability Rating UL 94V-0

Type: Cat5e

#### Mechanical:

IP Rating: IP67 in mated position

Operating Temperature: 0°C TO +85°C

RoHS COMPLIANT



THESE DRAWINGS AND SPECIFICATIONS ARE  
THE PROPERTY OF NorComp AND SHALL NOT  
BE REPRODUCED, COPIED OR USED AS THE  
BASIS FOR THE MANUFACTURE OR SALE OF  
APPARATUS WITHOUT WRITTEN PERMISSION.

DRAWN:  
M. SIGMON  
DATE:  
05/10/2013

UNITS = mm

DO NOT SCALE FROM DRAWING

NorComp

SCALE: NTS	SHEET 1	OF 1	REV 4
DWG NO. IPRJCONN-P			