
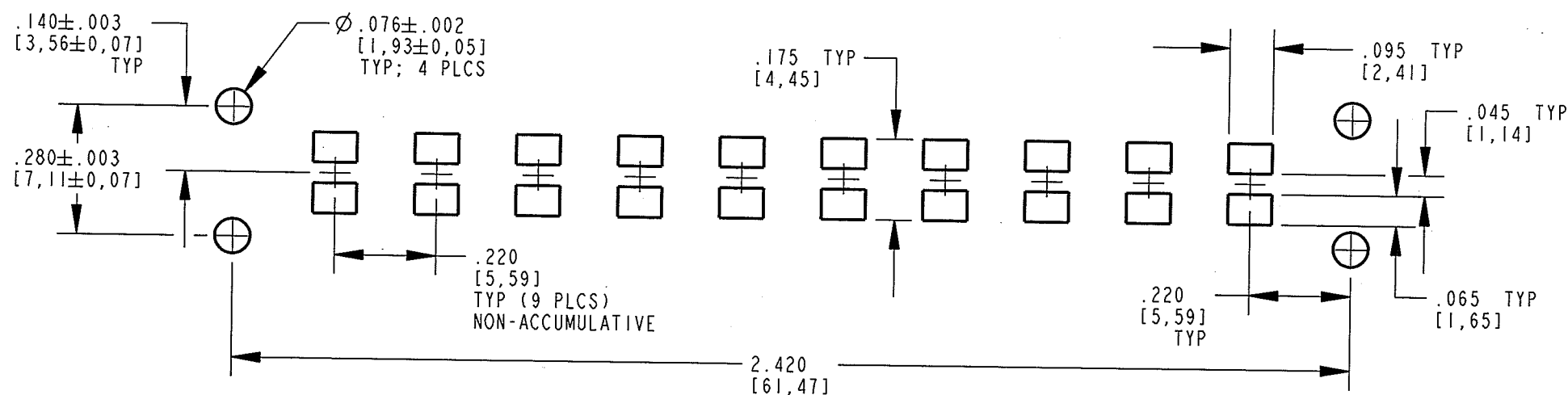


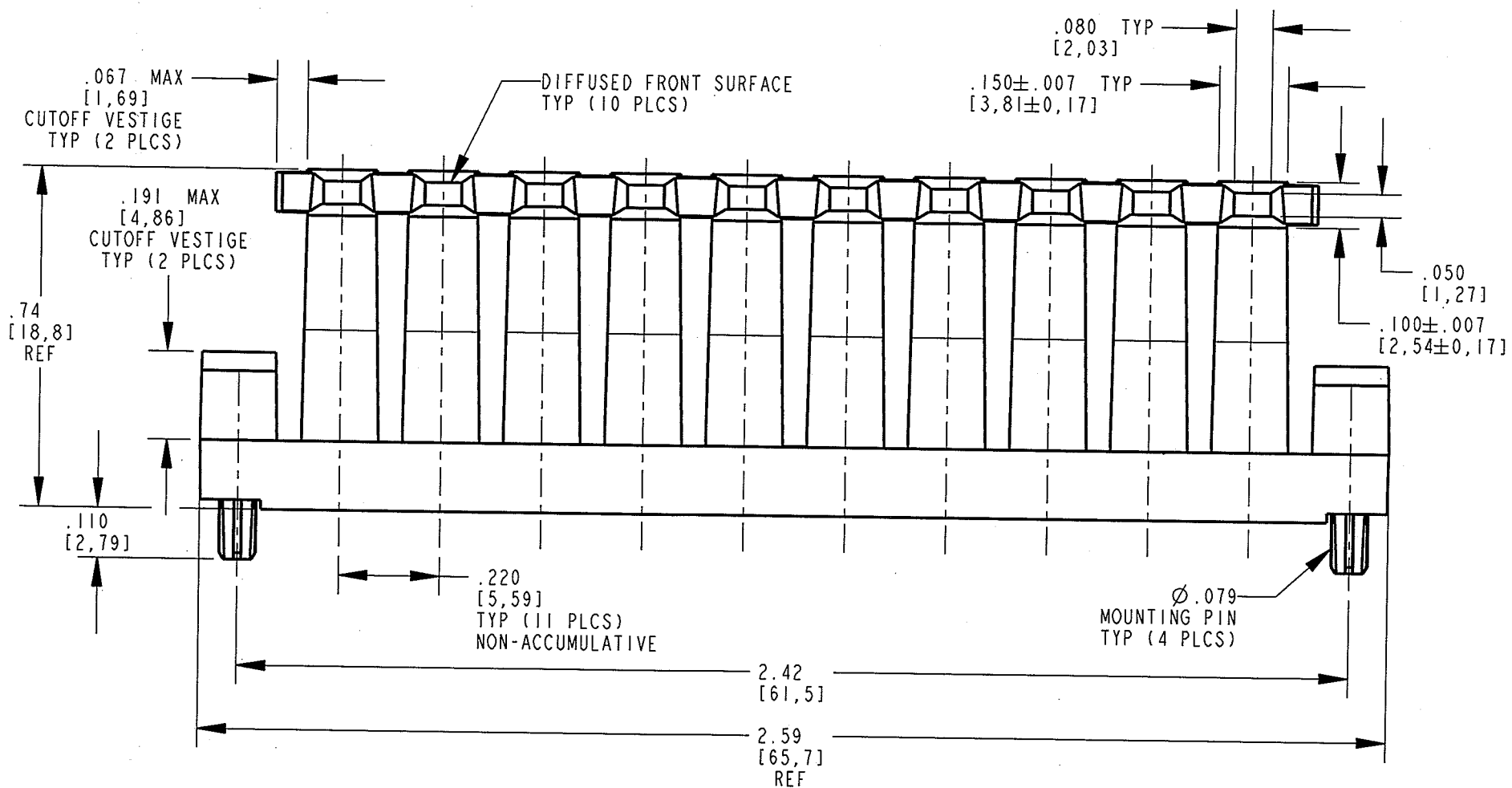

RECOMMENDED HOLE / SOLDER PAD LAYOUT (USING RECOMMENDED DIALIGHT SMT LEDs - P/N'S 597-3XXX-207F)



NOTES:

- COMPONENTS MOLDED IN A CLEAR TRANSMISSIVE POLYCARBONATE (UL 94V-0 FLAMMABILITY).
- COMPONENTS DESIGNED TO BE PRESSED INTO PC BOARD.
- RECOMMENDED DIALIGHT SMT LEDs: 597-3XXX-207F, 597-77XX-207F
- STORAGE AND OPERATING TEMPERATURE: -30°C TO 100°C
- DIALIGHT PART NUMBER: 515-1093-801F

RoHS COMPLIANT 515-1093-801F

Part Numbers with the "F" suffix ending are RoHS Compliant. Packaging is marked with "RoHS Compliant" label or equivalent markings.

REV	ECN NO	REVISIONS	DRN	CKD	APP	DATE
A		NEW RELEASE	KLJ	7.0	46	12-10-08

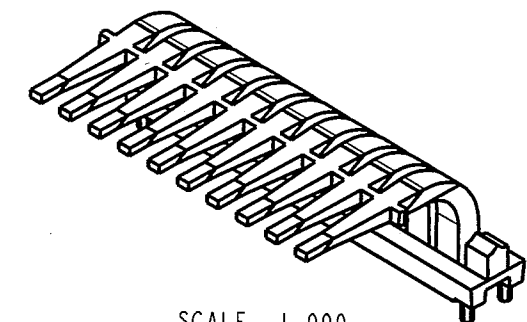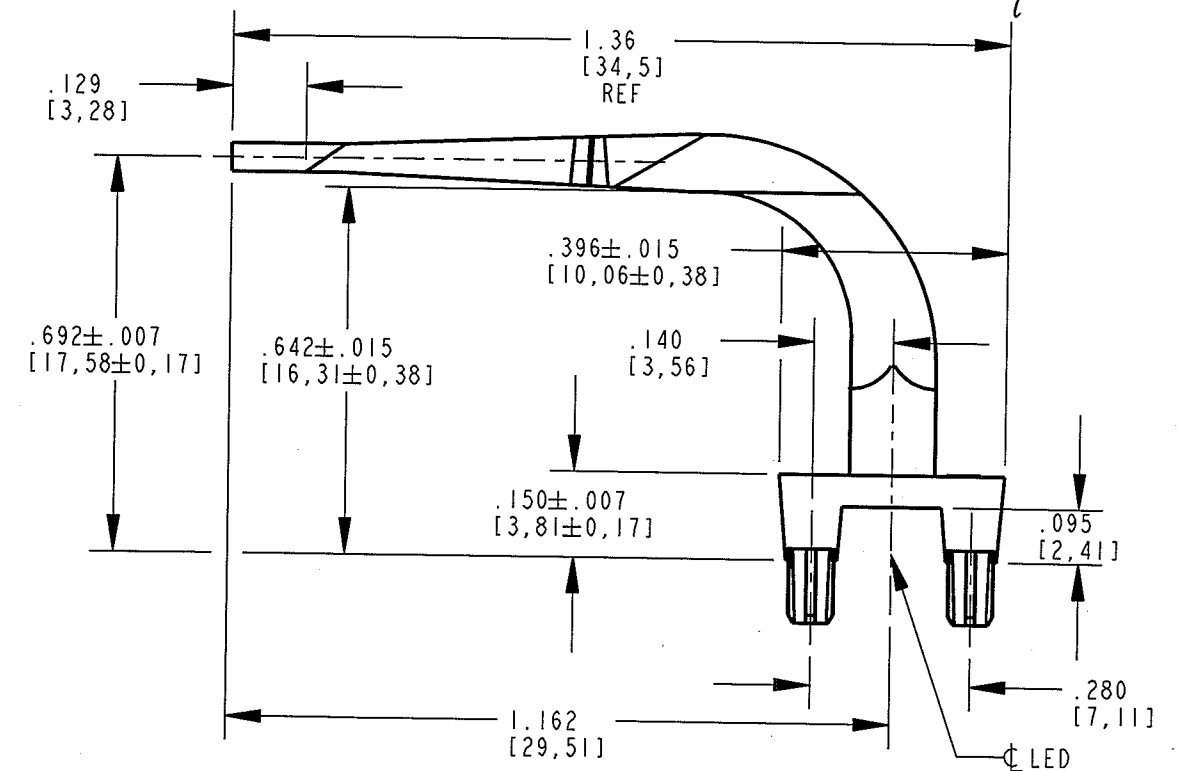

SCALE 1.000

THIS DRAWING AND THE CONTENTS HEREIN ARE CONFIDENTIAL AND THE SOLE PROPERTY OF DIALIGHT. REPRODUCTION OF THIS DRAWING OR CONSTRUCTION OF ANY PARTS WITHIN THIS DRAWING ARE FORBIDDEN WITHOUT THE WRITTEN CONSENT OF DIALIGHT.					
SCALE: 3.000		DRAWING NUMBER		REV	
ALL DIM'S IN: INCHES (MM)		C-17689		A	
TOLERANCES: UNLESS OTHERWISE SPECIFIED					
FRACTIONS: $\pm 1/64$		TITLE 10 ELEMENT LIGHT PIPE			
DECIMALS (.XX): $\pm .01$					
DECIMALS (.XXX): $\pm .005$		MATERIAL SEE NOTES			
ANGLES: $\pm 3^\circ$					
FINISH:				1501 ROUTE 34 SOUTH FARMINGDALE, NJ 07727	
FSCM 83330					
		SHEET 1 OF 1 FAMILY TABLE			