

# 1. SPECIFICATION

AC-7E3D




ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	3	 Standard state, standard drive circuit. Square wave 1/2 duty.
02	Operating Voltage	V	2 ~ 4	
03	Consumption Current	mA Max.	150	
04	Sound pressure level (Distance at 10cm )	dB(A) Min.	70	Rated voltage, rated frequency.
05	Direct Current Resistance	$\Omega$	$8 \pm 1$	
06	Rated Frequency	Hz	3100	

REV NO.

REVISION NOTE

APPROVAL

DATE

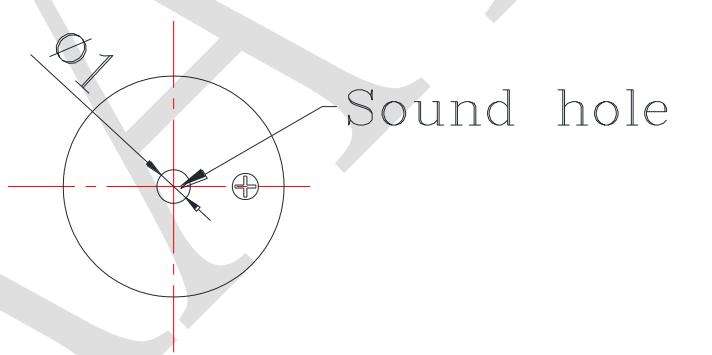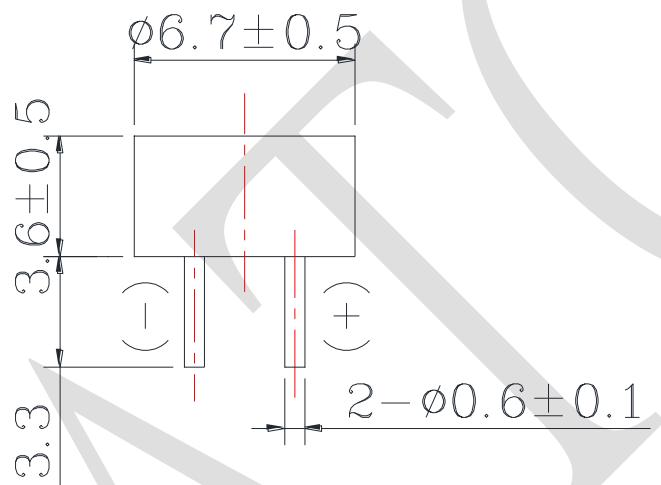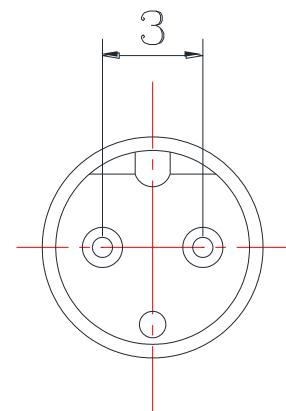

RoHS

TITLE: ELECTRO MAGNETIC BUZZER

PART NO. AC-7E3D

DWG NO. \*\*\*\*-\*\*\*\*\*

DRAWN: Zadk

2020/04/16

SCALE: 4:1 SHEET: 1 of 1

DESIGNED: R&amp;D OF AAT

UNITS: mm

CHECKED:

TOLERANCE ± 0.5

APPROVAL:

FIRST ANGLE PROJECTION

REV

MATERIAL: NORYL



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

