
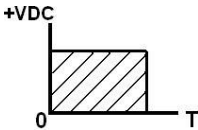
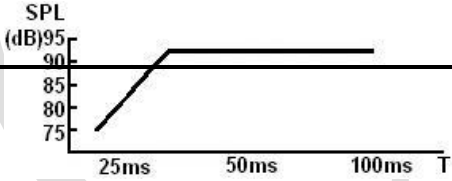


1. SPECIFICATION

AD-1005-BM-1


ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	5	
02	Operating Voltage	V	3 ~ 8	
03	Rated Current	mA (Max)	30	Rated Voltage
04	Sound pressure level	dB(A) (Min)	80	Distance at 10cm
05	Resonant Frequency	Hz	2700± 300	

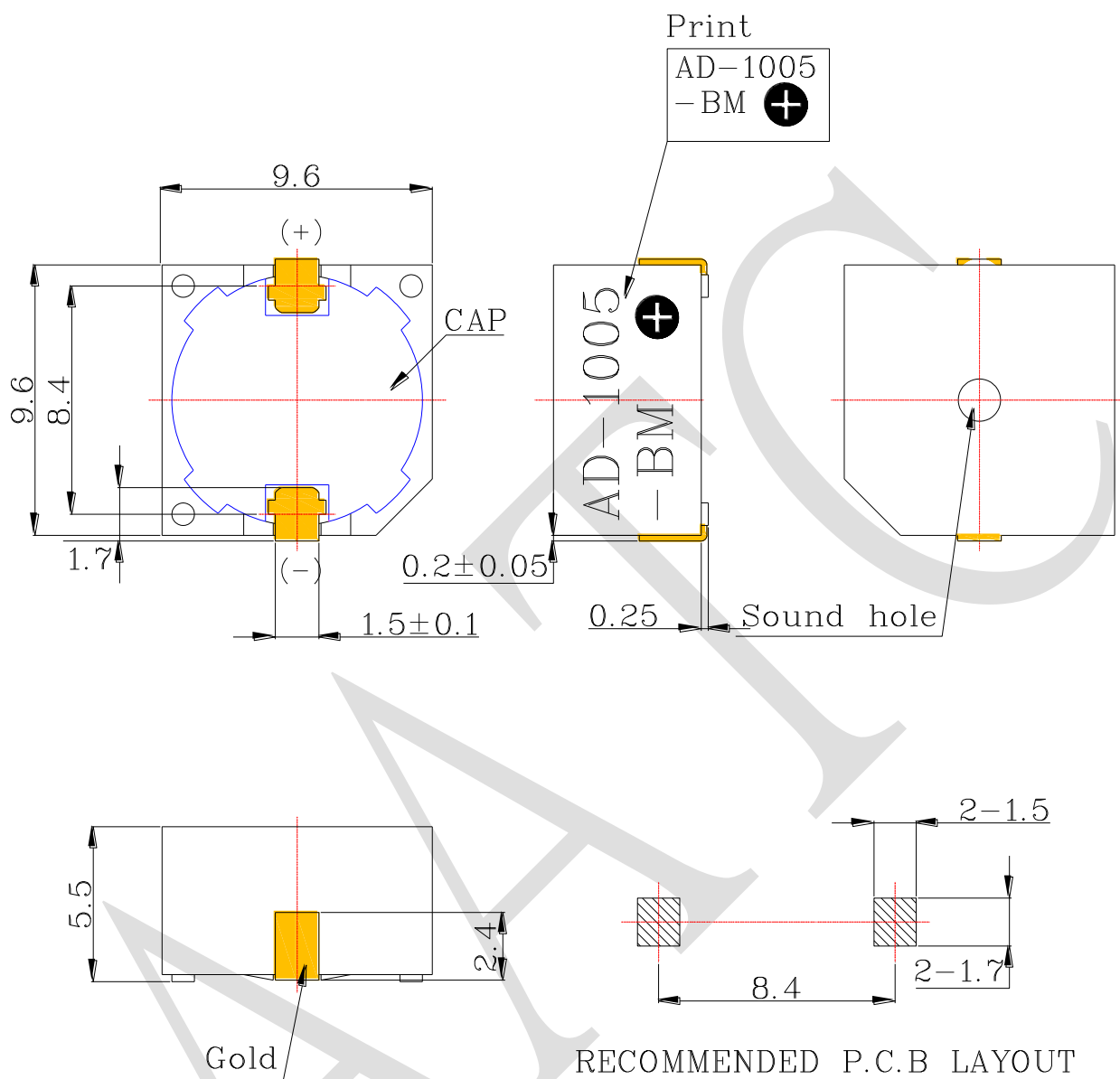

EU RoHS 2 Annex III Exemption list

7(a)

Lead in high melting temperature type solders (i.e. lead-based alloys containing 85 % by weight or more lead).

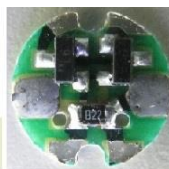

RoHS

TITLE: SOUND TRANSDUCER (SMD)

DRAWN: Zack

2015/01/08

SCALE: 1:1

SHEET: 1 : 1

PART NO. AD-1005-BM-1

DESIGNED: R & D OF AAT

UNITS: mm

CHECKED:

TOLERANCE ± 0.5

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

DWG NO. SMD-096055F-05027DJ-1

REV

MATERIAL: PPS

ONE PLACE DECIMAL $\pm$ ***TWO PLACE DECIMAL $\pm$ ***THREE PLACE DECIMAL $\pm$ ***

ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC