 


1. SPECIFICATION

AD-1305-GU2-LF(RoHS)


ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	5	
02	Operating Voltage	V	4 ~ 7	
03	Consumption Current	mA (Max)	Mean : 50	Applying rated voltage, rated frequency Square wave, 1/2 duty subject to standard state.
			Peak : 150	
04	Direct Current Resistance	Ω	45±5	
05	Sound Output (Distance at 10cm)	dBA (Min)	85	Applying rated voltage, rated frequency Square wave, 1/2 duty subject to standard state.
06	Rated Frequency	Hz	2400	

REV NO.

REVISION NOTE

APPROVAL

DATE

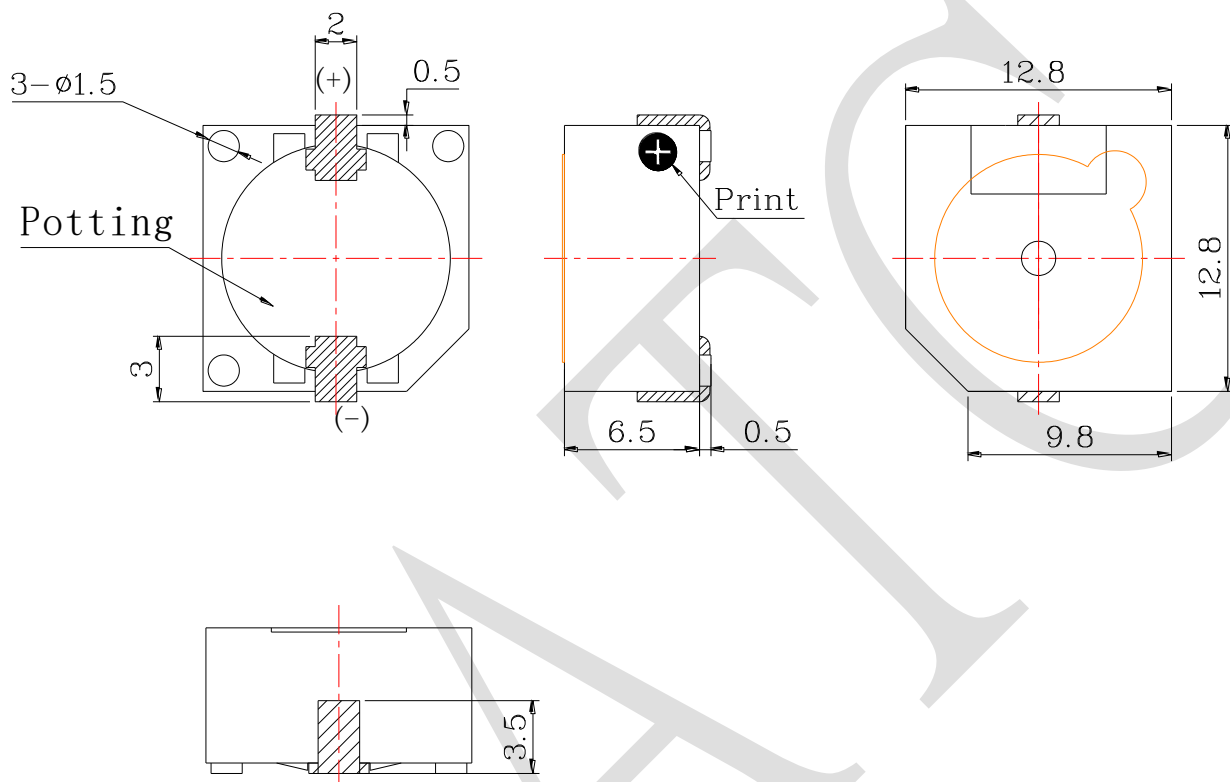

EU RoHS 2 Annex III Exemption list

7(a)

Lead in high melting temperature type solders (i.e. lead-based alloys containing 85 % by weight or more lead).



RoHS

TITLE: SOUND TRANSDUCER (SMD)

DRAWN: Zack

2015/08/06

SCALE: 1:1

SHEET: 1 : 1

PART NO. AD-1305-GU2-LF

DESIGNED: R & D OF AAT

UNITS: mm

DWG NO.

FDM-1026 SMD-128065F-05024C-1_A10_2_1_

2

CHECKED:

TOLERANCE ± 0.5

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

ONE PLACE DECIMAL ± ***

TWO PLACE DECIMAL ± ***

THREE PLACE DECIMAL ± ***

REV

MATERIAL: PPS



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC