
 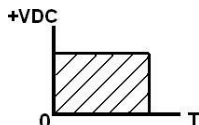

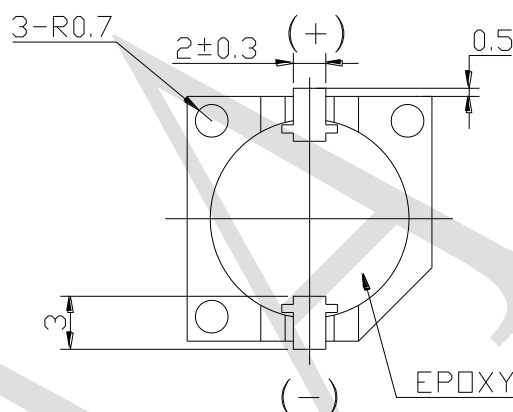
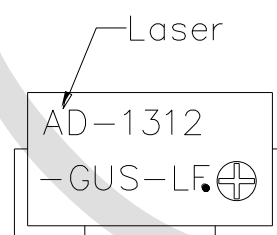
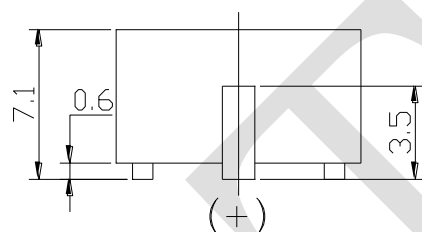


1. SPECIFICATION

AD-1312-GUS-LF

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	12	
02	Operating Voltage	V	8 ~ 15	
03	Consumption Current	mA (Max)	30	Rated Voltage
04	Resonant Frequency	Hz	2400± 200	Rated Voltage
05	Response times	ms	≥ 100	
06	Sound pressure level	dB(A) Min.	85	Distance at 10cm Rated Voltage / Resonant Frequency


REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

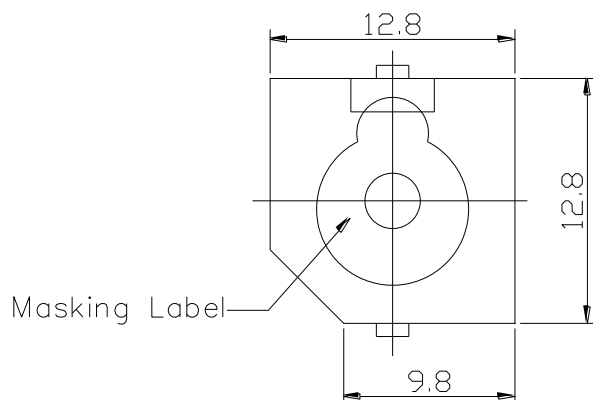

EU RoHS 2 Annex III Exemption list

7(a)

Lead in high melting temperature type solders (i.e. lead-based alloys containing 85 % by weight or more lead).

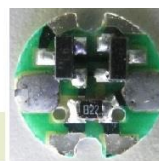

RoHS

TITLE: SOUND TRANSDUCER (SMD)		DRAWN: Zack	2019/08/01	SCALE: 1:1	SHEET: 1 : 1
PART NO. AD-1312-GUS-LF	4	DESIGNED: R & D OF AAT		UNITS: mm	
DWG NO. UCT12XIC		CHECKED:		TOLERANCE ± 0.5	
		APPROVAL:		UNLESS OTHERWISE SPECIFIED:	
	REV	MATERIAL: PPS		ONE PLACE DECIMAL ± ***	
				TWO PLACE DECIMAL ± ***	
				THREE PLACE DECIMAL ± ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC