


1. SPECIFICATION

AK-343408FF-2

ITEM		SPECIFICATIONS	
01	Type	Dynamic Speaker	
02	Dimension	External diameter 34 x 34 mm	
03	Rated Input Power	2.0 W	
04	Max. Input Power	3.0 W for 1 minute	
05	Impedance	8Ω ± 15% at 2KHz 1V	
06	Resonance Frequency (Fo)	300 Hz ± 20% at Fo, 1V	
07	Sound pressure level	78 dB(1.0W/0.5M) ± 3 dB	at AVE 1.0KHz.
		93 dB(1.0W/0.1M) ± 3 dB	
08	Frequency Range	Fo – 20 K Hz	
09	Total Harmonics Distortion	Max 10 % at 1 KHz, 1.5V.	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

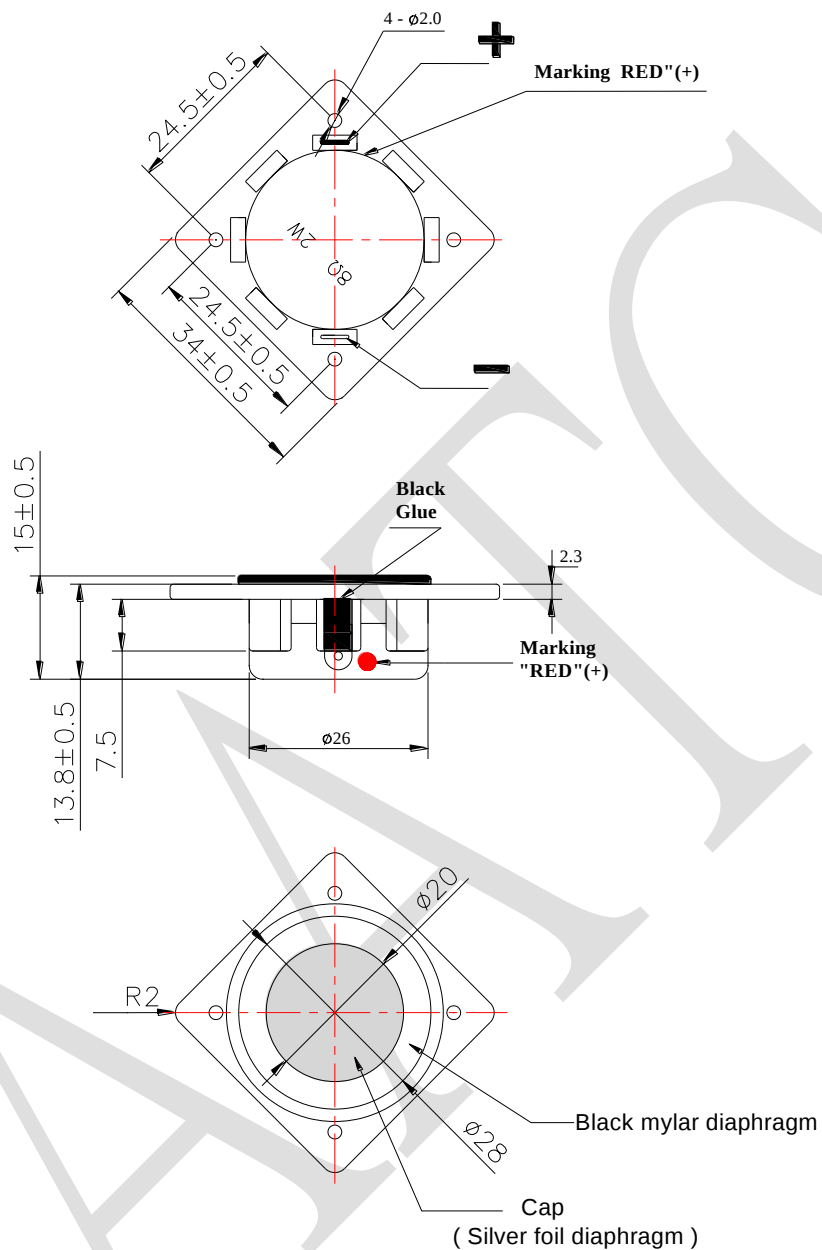

RoHS

TITLE: DYNAMIC SPEAKER		DRAWN: Jerry	2014/05/07	SCALE: 1:1	SHEET: 1 : 1
PART NO. AK-343408FF-2	2	DESIGNED: R & D OF AAT		UNITS: mm	
DWG NO. YD34-1A-8N18PU-EC		CHECKED:		TOLERANCE ± 0.5	
		APPROVAL:		UNLESS OTHERWISE SPECIFIED:	
	REV	MATERIAL: *****		ONE PLACE DECIMAL ± ***	
				TWO PLACE DECIMAL ± ***	
				THREE PLACE DECIMAL ± ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC