

1. SPECIFICATIONS

AMF-O60C40-NWH-LF

01	Electret's Type	Foil type
02	Sensitivity	-40±3dB (0dB=1V/Pa,1KHz)
03	Standard Operation Voltage	2.0 V
04	Output Impedance	2.2 KΩ
05	Directivity	Omni directional
06	Frequency Range	70 - 20K Hz
07	Max. Operation Voltage	10V
08	Current Consumption	Max.0.5mA
09	Sensitivity Reduction	Within -3dB 0dB=1V/Pa,1KHz Vs=2.0to 1.5V
10	S/N Ratio	≥58dB


REV NO.

REVISION NOTE

APPROVAL

DATE




FILTER

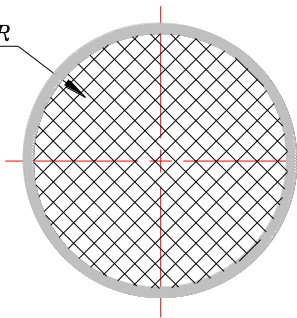

Wires: UL1571,30AWG#

Connector : Equivalent to Molex 51021-0200

Holder:DD-EQ-JTC79-01

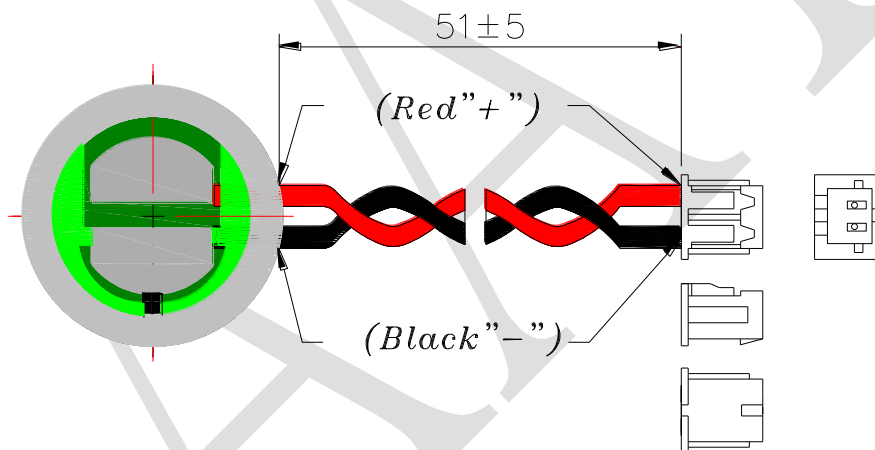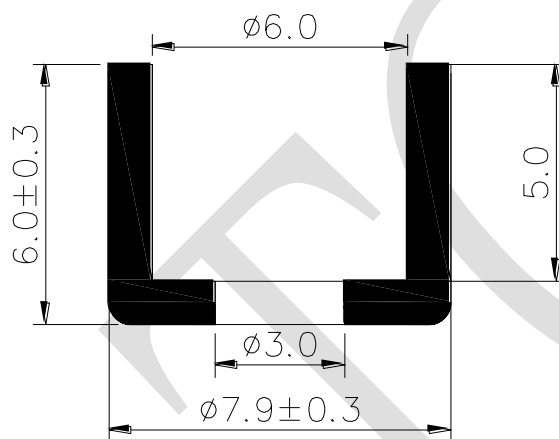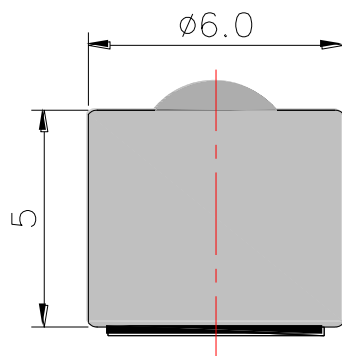

RoHS

TITLE: MICROPHONE		DRAWN: <i>Moose</i> 2016/03/11	SCALE: 5:1	SHEET: 1 of 1
PART NO. AMF-060C40-NWH-LF	2	DESIGNED: R & D OF AAT	UNITS: mm	
DWG NO. F6050AL-SBN-D54-M -11436		CHECKED:	TOLERANCE ± 0.3	
		APPROVAL:	UNLESS OTHERWISE SPECIFIED:	
	REV	MATERIAL: AL	ONE PLACE DECIMAL ± ***	
			TWO PLACE DECIMAL ± ***	
			THREE PLACE DECIMAL ± ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC