

1. SPECIFICATIONS

AMF-O60F42-NWH5


01	Electret Type	FOIL type
02	Sensitivity	-42±3dB (0dB=1V/Pa,1KHz)
03	Output Impedance (Max)	2.2KΩ
04	Directivity	Omnidirectional
05	Frequency Range	70-20,000Hz
06	Max. Operation Voltage	10V
07	Standard Operation Voltage	2.0V
08	Current Consumption	Max.0.5mA
09	Sensitivity Reduction	Within -3dB 0dB=1V/Pa,1KHz Vs=2.0 to 1.5V
10	S/N Ratio	> 58dB

REV NO.

REVISION NOTE


APPROVAL

DATE

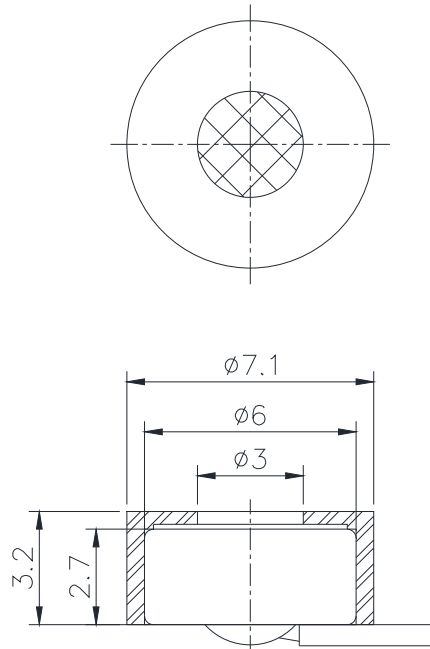

HOLDER : R-0603-B

WIRE : UL 1571 , 30 AWG.

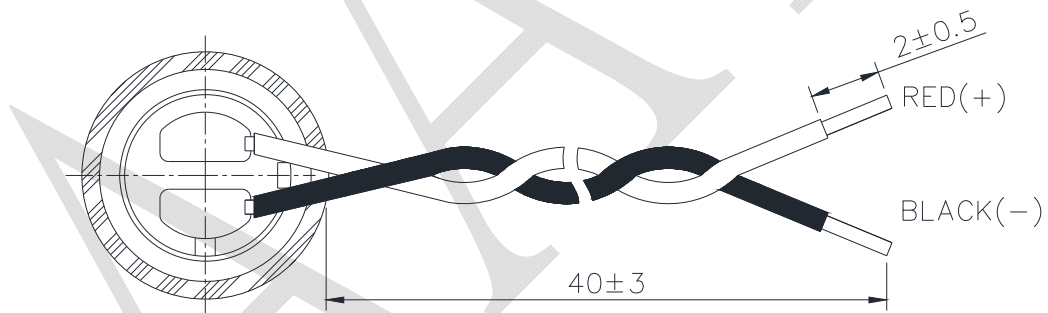MIC. : $\varnothing$ * 2.7mm

TITLE: MICROPHONE		DRAWN: JCHEN 08/25/2005	SCALE: 5:1	SHEET: 1 of 1
PART NO. AMF-060F42-NWH5	1	DESIGNED: R & D OF AAT	UNITS: mm	
DWG NO. DTM-1269		CHECKED:	TOLERANCE $\pm$ 0.2	
		APPROVAL:	UNLESS OTHERWISE SPECIFIED:	
	REV	MATERIAL: *****	ONE PLACE DECIMAL $\pm$ ***	
			TWO PLACE DECIMAL $\pm$ ***	
			THREE PLACE DECIMAL $\pm$ ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC