 



1. SPECIFICATION

APD-1405-KX2(RoHS)

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	5	 <p>V_{p-p}</p> <p>0V</p> <p>Square wave 1/2 duty.</p>
02	Operating Voltage	V	1 ~25	
03	Consumption Current	mA (Max)	3	
04	Sound pressure level (Distance at 10cm)	dB(A) (Min)	75	Rated voltage, rated frequency.
05	Capacitance	pF	12000±30%	At 1000Hz
06	Rated Frequency	Hz	4000± 500	

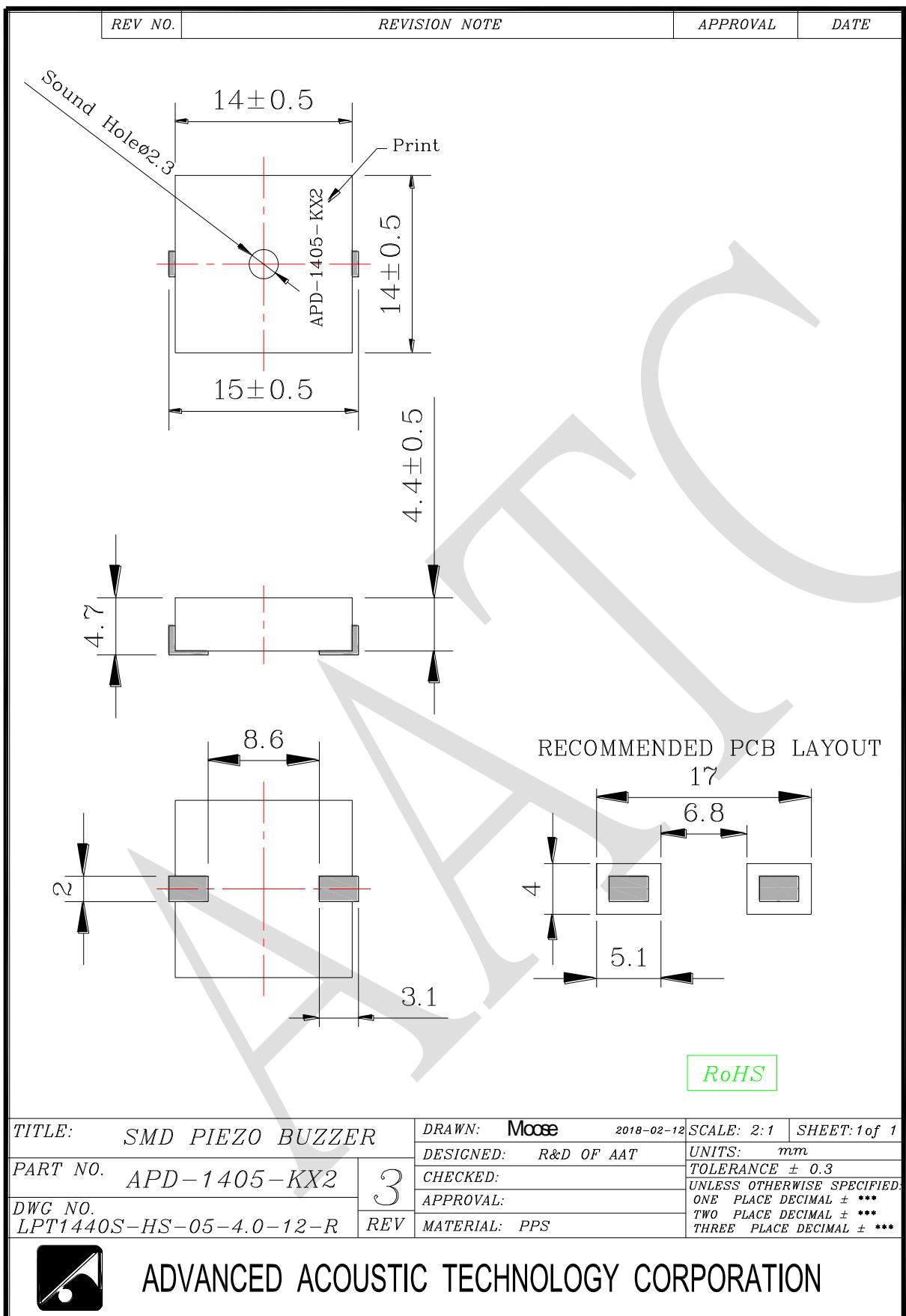

ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

