
 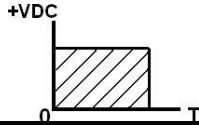



1. SPECIFICATION

AX-1205-BH-1P

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	5	
02	Operating Voltage	V	3 ~ 7	
03	Consumption Current	mA (Max)	15	Rated Voltage
04	Resonant Frequency	Hz	2300± 300	Rated Voltage
05	Response times	ms	≥ 100	
06	Sound pressure level	dB(A) Min.	85	Distance at 10cm Rated Voltage

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

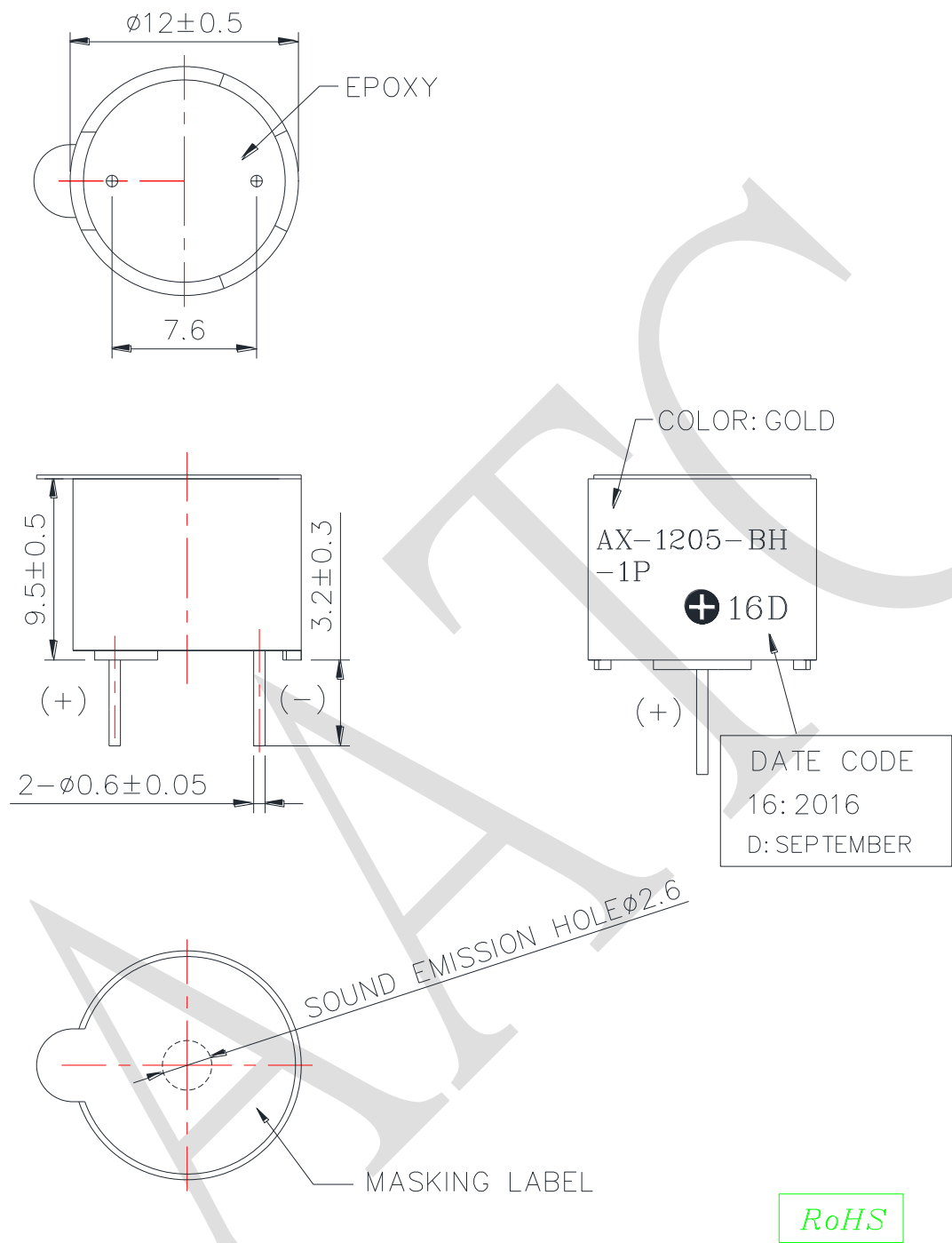

RoHS

TITLE: ELECTRO MAGNETIC INDICATOR		DRAWN: Hank	2022/01/17	SCALE: 4:1	SHEET: 1 of 1
PART NO. AX-1205-BH-1P	2	DESIGNED: R&D OF AAT		UNITS: mm	
DWG NO. JM12955CC-1P		CHECKED:		TOLERANCE ± 0.5	
		APPROVAL:		FIRST ANGLE PROJECTION	
	REV	MATERIAL: PBT			



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC