

1. SPECIFICATION

AZ-1240E-1P


ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	9	 Square wave 1/2 duty.
02	Operating Voltage	V	1 ~ 20	
03	Consumption Current	mA (Max)	9	
04	Sound pressure level (Distance at 10cm)	dB(A) (Min)	83	Rated voltage, rated frequency.
05	Capacitance	pF	12000±30%	At 120Hz
06	Rated Frequency	Hz	4000± 300	

REV NO.

REVISION NOTE

APPROVAL

DATE

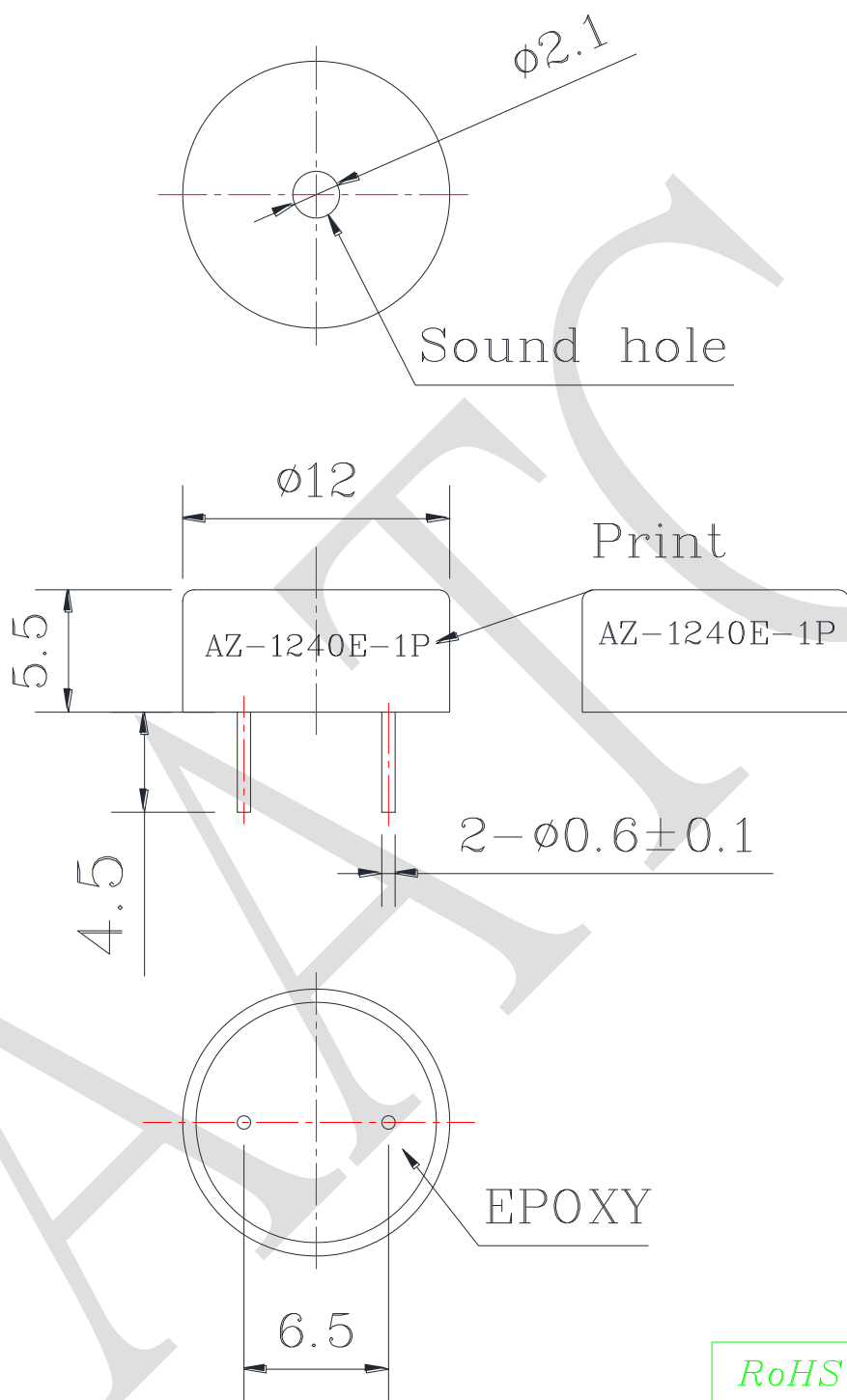

TITLE: PIEZO BUZZER

DRAWN: Zack

2020/02/18

SCALE: 2:1

SHEET: 1:1

PART NO. AZ-1240E-1P

3

DESIGNED: R&D OF AAT

CHECKED:

APPROVAL:

DWG NO. LPT1255-T0-09-4.0-12-6.5-R

REV

MATERIAL: PPO

UNITS: mm

TOLERANCE ± 0.5

UNLESS OTHERWISE SPECIFIED:

ONE PLACE DECIMAL $\pm$ ***TWO PLACE DECIMAL $\pm$ ***THREE PLACE DECIMAL $\pm$ ***

ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC