

1. SPECIFICATION

AZ-1440S-P3



ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	12	VDC
02	Operating Voltage	V	3 ~ 16	
03	Rated Current	mA(Max)	7	Rated Voltage Rated Frequency
04	Sound pressure level (Distance at 10cm)	dBA(Min)	80	
05	Rated Frequency	Hz	4000	Rated Voltage
06	Resonant Frequency	Hz	4000± 500	

REV NO.

REVISION NOTE

APPROVAL

DATE

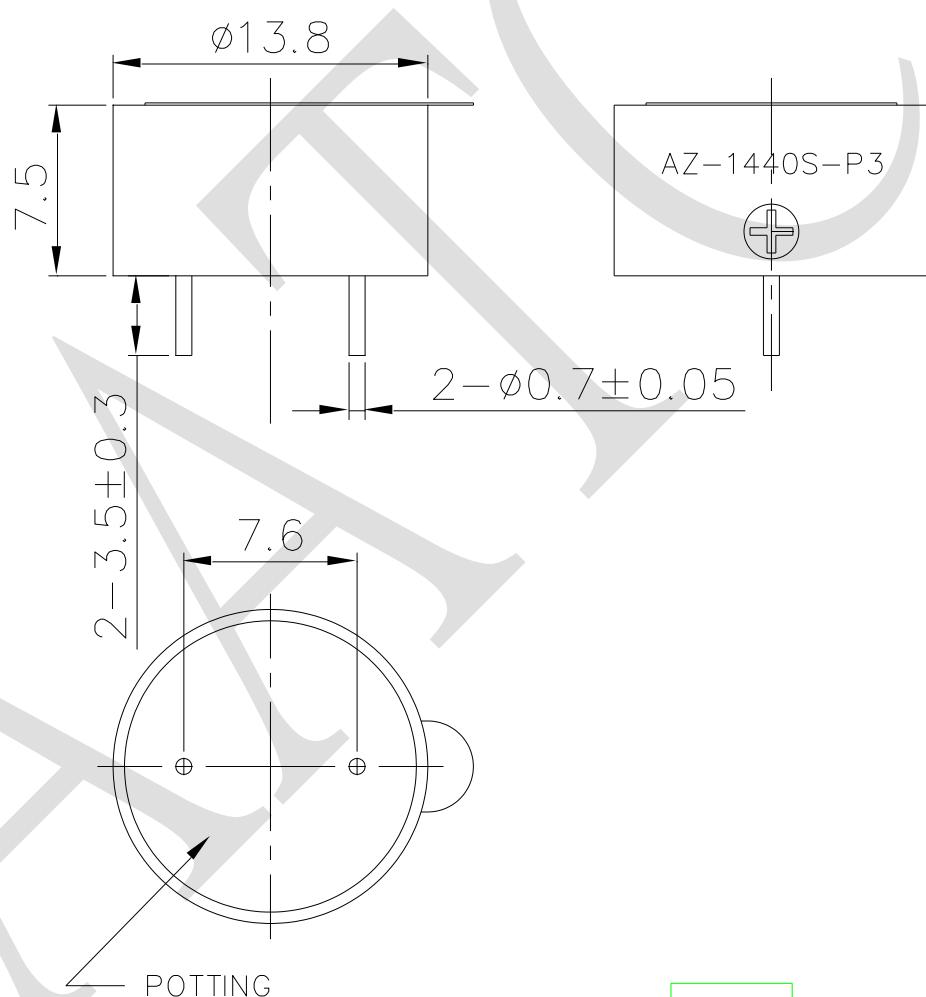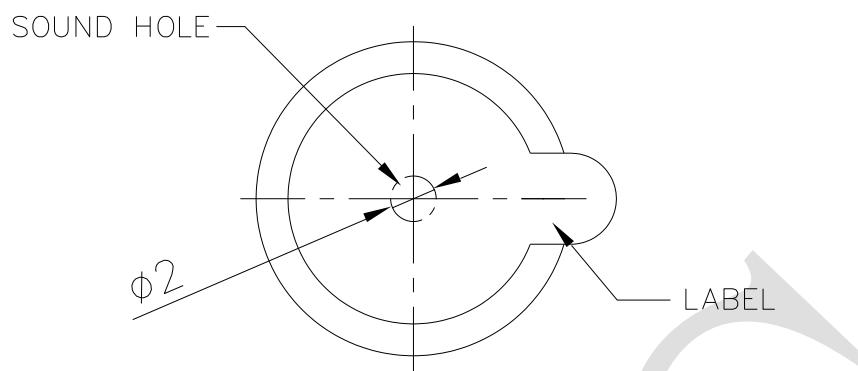

TITLE:	PIEZO BUZZER	DRAWN:	Zack	2012/07/26	SCALE: 2:1	SHEET: 1 of 1
PART NO.	AZ-1440S-P3	DESIGNED:	R & D OF AAT		UNITS: mm	
DWG NO.	DTP-1001	2	CHECKED:		TOLERANCE ± 0.5	
		REV	APPROVAL:		UNLESS OTHERWISE SPECIFIED: ONE PLACE DECIMAL $\pm ***$ TWO PLACE DECIMAL $\pm ***$ THREE PLACE DECIMAL $\pm ***$	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

