

1. SPECIFICATION

AZ-1640E-WV9

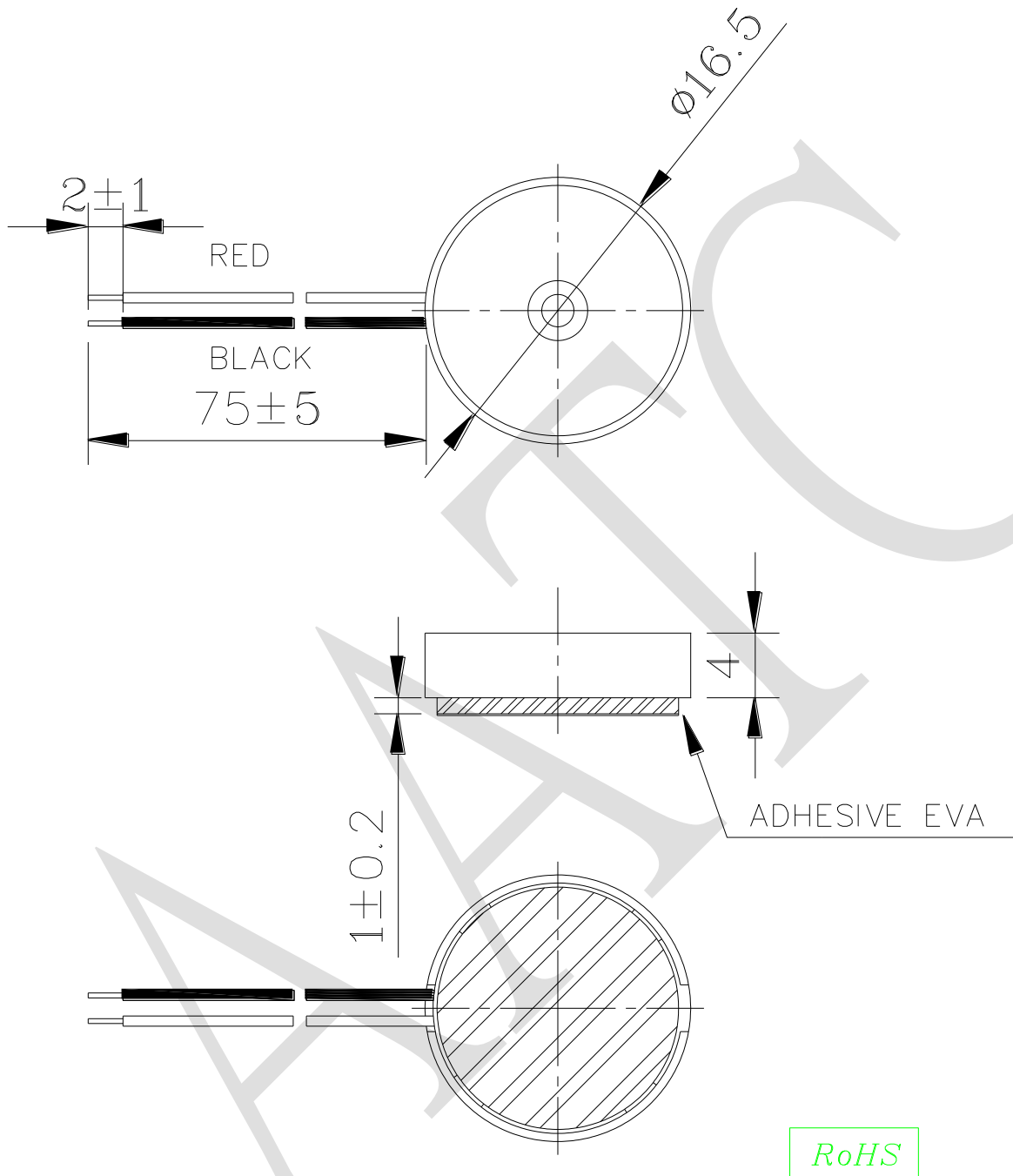
ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	9	Vp-p (Square Wave) 1/2 duty
02	Operating Voltage	V	3~ 30	
03	Rated Current	mA(Max)	7	Rated Voltage
04	Sound pressure level (Distance at 10cm)	dBA(Min)	80	Rated Voltage Rated Frequency
05	Resonant Frequency	Hz	4000 ± 300	Rated Voltage
06	Capacitance	pF	15000±30%	At 1K Hz

REV NO.

REVISION NOTE

APPROVAL

DATE

TITLE: *PIEZO BUZZER*DRAWN: **Zack**

2013/03/21

SCALE: 2:1

SHEET: 1:1

PART NO. *AZ-1640E-WV9*DESIGNED: *R&D OF AAT*UNITS: *mm*DWG NO. *UGPA17A4009W75T*

2

CHECKED:

TOLERANCE ± 0.3

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

ONE PLACE DECIMAL $\pm$ ***TWO PLACE DECIMAL $\pm$ ***THREE PLACE DECIMAL $\pm$ ***

REV

MATERIAL: *ABS***ADVANCED ACOUSTIC TECHNOLOGY CORPORATION**

For more information, please contact AATC.

AATC