




Diagonal Cutting Pliers, Bell System, Skinning Holes, 6-Inch

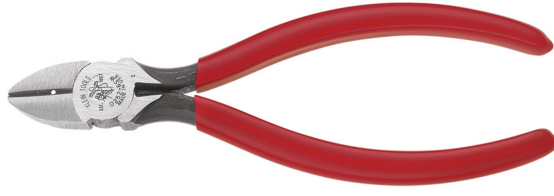

These Klein Tools Diagonal-Cutting Pliers Bell System have a heavier design for all purpose use. The pliers' bell system type has a skinning hole for 24 AWG and W notches slit insulation cleanly. They are made of US-made steel with induction hardened cutting knives for durability. The hot-riveted joint ensures smooth action and no handle wobble.

Specifications

Type:	Diagonal Cutting Bell System Pliers	Special Features:	Skinning Hole and "W" Notches
Overall Length (Inch):	6.15	Overall Length (cm):	15.6
Material:	Steel	Nose Type:	Tapered
Jaw Length (Inch):	0.696	Jaw Length (cm):	1.8
Jaw Width (Inch):	0.75	Jaw Width (cm):	1.9
Jaw Thickness (Inch):	0.813	Jaw Thickness (cm):	2.1
Jaw Capacity (Inch):	0.5	Jaw Capacity (cm):	1.3
Cutting Knives:	Standard	Knife Length (Inch):	0.594
Knife Length (cm):	1.5	Cut Style:	Standard
Joint Type:	Hot Riveted	Handle Color:	Red
Handle Finish:	Plastic-Dipped	Handle Length (Inch):	3.81
Handle Length (cm):	9.7	Insulated:	No
Tether Capable:	No	Standard:	No
Weight (oz):	5.3	Weight (g):	150