
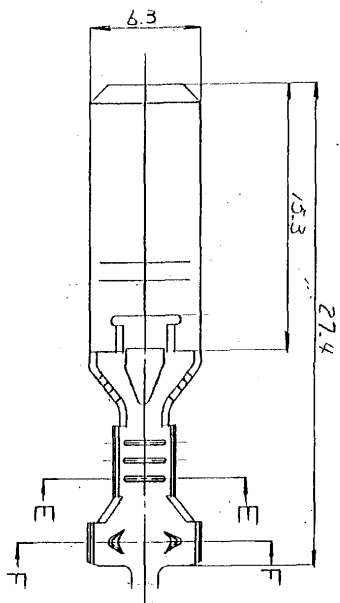


五回

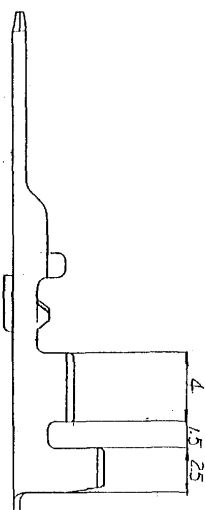

試品番	A	B	C	D	適用標準
7114-2875	2.7	4.5	2.5	4.5	AV 0.3-0.5
7114-2876	3.7	5.5	3.5	5.5	AV 0.05-2
7114-2877	4.7	6.5	4.2	6.2	AV 3

[illegible] $YBM \approx -kNo$

完