




Wiremold  
880MPFC Series Fire Classified Nonmetallic Rectangular Floor Box  
Part No. 880MPFC

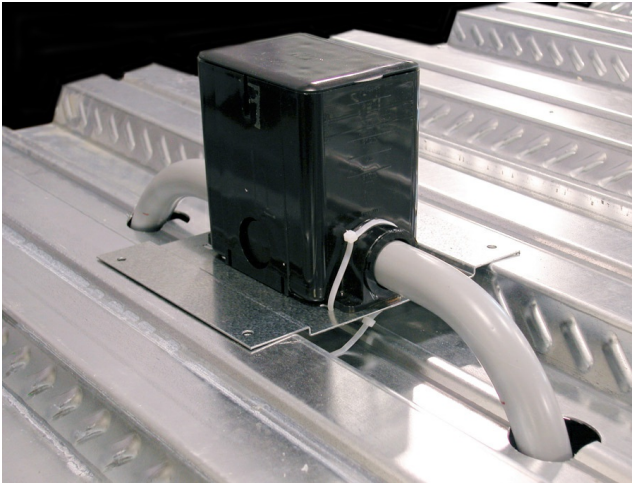

Fire Classified Nonmetallic Rectangular Floor Box. Box comes complete with reusable mudcap, insert spacer, conduit plugs and reducers. Reducers provided for reduction to 1", 3/4", and 1/2" (25mm, 19.1mm, and 12.7mm) conduit. Minimum concrete depth is 3 1/2" (89mm) and maximum concrete depth is 6" (152mm). Minimum capacity is 50 cu. in. (819ml) and maximum capacity is 100 cu. in. (1639ml). Box dimensions are 4 1/8" W x 5 1/2" L x 6" (105mm x 140mm x 152mm). NOTE: Insert spacer should not be removed until after concrete pour. This is a single-gang offering. Cannot gang boxes together and maintain Fire Classification. Floor box spacing 2' on center, no more than 1 per 65 s.f. span. Maximum Copper Cross Section per Insert: Four (4) #12 AWG Type THHN Power Conductor or 48 #23 AWG (6 Cat. 6) Tele Data conductors. Box preserves the 2-hour fire rating of the floor in which it has been installed.

## Features & Benefits

Fire Classified Nonmetallic Rectangular Floor Box. Box comes complete with reusable mudcap, insert spacer, conduit plugs and reducers. Reducers provided for reduction to 1", 3/4", and 1/2" (25mm, 19.1mm, and 12.7mm) conduit.

NOTE: Insert spacer should not be removed until after concrete pour. This is a single-gang offering. Cannot gang boxes together and maintain Fire Classification.

Box preserves the 2-hour fire rating of the floor in which it has been installed.

Minimum concrete depth is 3 1/2" (89mm) and maximum concrete depth is 6" (152mm). Minimum capacity is 50 cu. in. (819ml) and maximum capacity is 100 cu. in. (1639ml). Box dimensions are 4 1/8" W x 5 1/2" L x 6" (105mm x 140mm x 152mm).

Floor box spacing 2' on center, no more than 1 per 65 s.f. span. Maximum Copper Cross Section per Insert: Four (4) #12 AWG Type THHN Power Conductor or 48 #23 AWG (6 Cat. 6) Tele Data conductors.

## Specifications

### General Info

Product Line	Wiremold	UPC Number	786564072119
Country Of Origin	United States	Material	PVC
Construction	Assembled	Number of Knockouts	2

---

Application Sector	Commercial	Standard	cULus Listed Metallic Outlet Boxes: File E2961 Guide QCIT Meets Article 314.27(C) of NEC.
--------------------	------------	----------	---

---

Warranty Type	1-Year from Installation or 2-Years from Day of Sale	Type	Floor Box
---------------	---	------	-----------

---

#### Dimensions

---

Product Weight US	5.1 lb	Cubic Capacity	50 in <sup>3</sup>
Knockout Size	1/2 in, 1-1/2 in		

---

#### Listing Agencies / 3rd Party Agencies

---

cULus ListingNumber	E110748	cULus Listed	Yes
---------------------	---------	--------------	-----

---

#### Additional Information

---

RoHS Compliant	Yes		
----------------	-----	--	--

---

#### Technical Information

---

Floor Type	Carpet, Concrete, Tile	Service Capacity	Single
Minimum Floor Depth	3.5 in	Fire Rating	2 hr
Box Capacity	1 Gang	Cable Entry	Conduit
Box Type	Fire Classified	Depth Behind Device Plates	1.75 in

---