




Wiremold
WMFB2DRKS4N Series Dual-Gang Floor Box Assembly
Part No. WMFB2DRKS4N

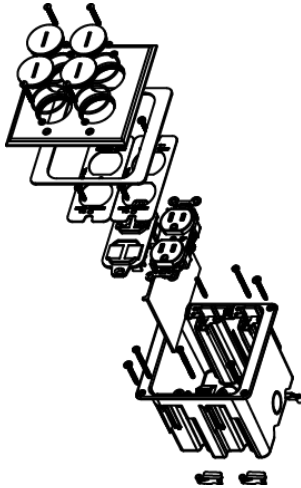

Includes dual-gang box, one 15A tamper-resistant duplex receptacle, 106 adapter with four openings for communication devices, and nickel cover with four screw plugs. For hole cut dimensions, see installation instructions sheet. Box Dimensions: 3 1/4" W x 3 3/4" L x 3 7/8" D [83mm W x 95mm L x 98mm D] Device Plate: 4 7/8" W x 5 1/16" L [124mm W x 129mm L].

Features & Benefits

Includes dual-gang box, one 15A tamper-resistant duplex receptacle, Box Dimensions: 3 1/4" W x 3 3/4" L x 3 7/8" D [83mm W x 95mm L x 98mm D] Device Plate: 4 7/8" W x 5 1/16" L [124mm W x 129mm L].
106 adapter with four openings for communication devices, and nickel cover with four screw plugs.

For hole cut dimensions, see installation instructions sheet.

Specifications

General Info

| | | | |
|-------------------|---|--------------------|--|
| Product Line | Wiremold | UPC Number | 786564054030 |
| Country Of Origin | Mexico | Material | PVC |
| Construction | Not Assembled | Cover Style | Surface |
| Cover Material | Nickel | Application Sector | Commercial, Residential |
| Standard | cULus Listed Nonmetallic Outlet Boxes: File E143222 Guide QCMZ. Meets Article 314.27(C) of NEC. | Warranty Type | 1-Year from Installation or 2-Years from Day of Sale |
| Type | Floor Box | | |

Dimensions

| | | | |
|------------------|---------|-------------------|---------|
| Product Width US | 3.25 in | Product Weight US | 1.76 lb |
|------------------|---------|-------------------|---------|

| | | | |
|------------------|----------|---------------|----------------|
| Product Depth US | 3.875 in | Knockout Size | 1/2 in, 3/4 in |
|------------------|----------|---------------|----------------|

Listing Agencies / 3rd Party Agencies

| | |
|--------------|-----|
| cULus Listed | Yes |
|--------------|-----|

Additional Information

| | |
|----------------|-----|
| RoHS Compliant | Yes |
|----------------|-----|

Technical Information

| | | | |
|------------|------|------------------|------|
| Floor Type | Wood | Service Capacity | Dual |
|------------|------|------------------|------|

| | | | |
|---------------------|------|--------------|---------|
| Minimum Floor Depth | 5 in | Box Capacity | 2 Gangs |
|---------------------|------|--------------|---------|

| | | | |
|-------------|---------------|----------|----------|
| Cable Entry | Through Floor | Box Type | Recessed |
|-------------|---------------|----------|----------|

| | | | |
|-------------------|---|----------------------------|---------|
| Number of Outlets | 2 | Depth Behind Device Plates | 3.87 in |
|-------------------|---|----------------------------|---------|
