

Series 39 EMI+Environmental Backshells

for AS50151 Crimp, M26482 Series II, M83723 Series III, AS95234


390A*053 EMI+Environmental Backshell, Spin Coupling



Adapter Code **A**

AS50151 crimp, AS95234, MIL-DTL-26482
Ser. II, MIL-DTL-83723 Ser. III

PROFILE SELECTION GUIDE

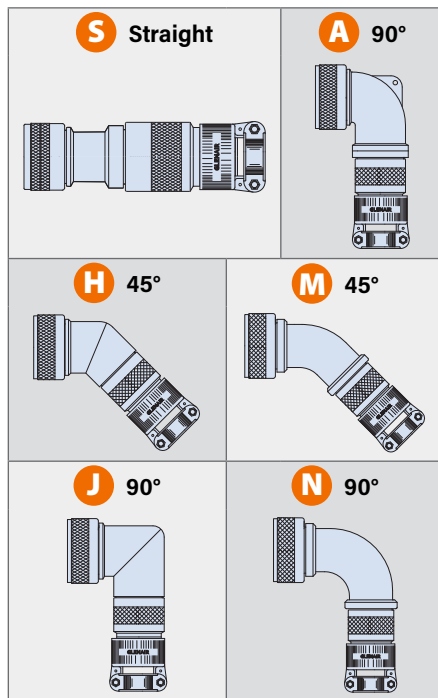

Shielded. Environmental. 390A*053 backshell fits AS50151 crimp (MS3450), AS95234, MIL-DTL-26482 Series II, MIL-DTL-83723 Series III connectors. Spin coupling. Two ground rings for terminating individual and overall braid shields. Type H heavy duty saddle clamp has stainless steel telescoping fillister head screws and lockwashers. Available in aluminum or stainless steel. Silicone O-ring and cable grommet.

PART NUMBER

PART NUMBER			390AS053	NF	18	10	H	3
Base P/N	Base Part No.	Profile	Shell Size					
	390AS053	S Straight	08-28					
	390AA053	A 90° Low Profile	08-28					
	390AH053	H 45° Cut/Weld	08-24					
	390AJ053	J 90° Cut/Weld	08-24					
	390AM053	M 45° Full Radius	08-28					
	390AN053	N 90° Full Radius	08-28					
Material/Finish	M	Alum/ Electroless Nickel						
	MT	Alum/ Nickel-PTFE						
	NF	Alum/ Olive Drab Cadmium						
	ZR	Alum/ Black Zinc-Nickel						
	TZ	Alum/ Tin-Zinc						
	ZI	SST/ Passivated (Profiles H, J, M, N, S only)						
Shell Size		08 10 12 14 16 18 20 22 24 28						
Entry Size	Entry Size	Max. Cable Dia.	Shell Size*	Entry Size	Max. Cable Dia.	Shell Size*		
	03	.250 (7.9)	08-28	16	.937 (23.8)	22-28		
	04	.312 (7.9)	10-28	20	1.250 (31.8)	28		
	06	.437 (11.1)	12-28	24	1.375 (34.9)	28		
	08	.562 (14.3)	14-28	28	1.625 (41.3)	-		
	10	.625 (15.9)	16-28	32	1.875 (47.6)	-		
	12	.750 (19.1)	18-28					
* If selected entry size exceeds shell size range, a Style 2 transition adapter will be included. See Maximum Entry Size for details.								
Strain Relief	H	Saddle Clamp						
	D	Nut		Saddle Clamp		Nut		
Length	3	1.5 inches	Applies to Profile S only. If Entry Size is greater than "Maximum Entry Size" (see next page), then 2 inch minimum applies.					
	4	2.0 inches						
	6	3.0 inches						
	8	4.0 inches						

Shell Size	A Thread Class 2B	øB Max in	mm
08	0.500-20 UNF	.65	16.5
10	0.625-24 UNEF	.77	19.6
12	0.750-20 UNEF	.94	23.9
14	0.875-20 UNEF	1.07	27.2
16	1.000-20 UNEF	1.21	30.7
18	1.0625-18 UNEF	1.23	31.2
20	1.1875-18 UNEF	1.36	34.5
22	1.3125-18 UNEF	1.48	37.6
24	1.4375-18 UNEF	1.73	43.9
28	1.750-18 UNS	1.97	50.0

