

Han Fast-Lock 1,5-2,5qmm ang.silverplate

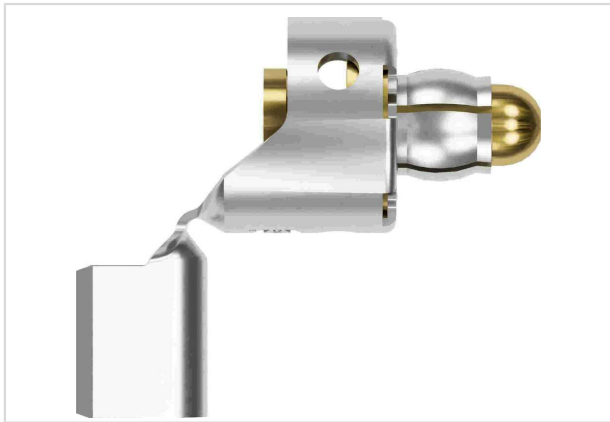


Image is for illustration purposes only. Please refer to product description.

Part number	09 08 000 7222
Specification	Han Fast-Lock 1,5-2,5qmm ang.silverplate
HARTING eCatalogue	https://harting.com/09080007222

Identification

Category	Contacts
Series	Han-Fast [®] Lock
Type of contact	PCB contact
Description of the contact	With pin Angled

Version

Pack contents	Single contact
---------------	----------------

Technical characteristics

Conductor cross-section	1.5 ... 2.5 mm ²
Rated current	≤60 A
Contact resistance	≤2 mΩ
Stripping length	7.5 mm

Material properties

Material (contacts)	Copper alloy
Surface (contacts)	Silver plated
Material (locking)	Copper alloy
Surface (locking)	Passivated
RoHS	compliant with exemption
RoHS exemptions	6(c): Copper alloy containing up to 4 % lead by weight
ELV status	compliant with exemption



Pushing Performance
Since 1945

Material properties

China RoHS	50
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Yes
REACH SVHC substances	Lead
ECHA SCIP number	b51e5b97-eeb5-438b-8538-f1771d43c17d
California Proposition 65 substances	Yes
California Proposition 65 substances	Lead Nickel

Commercial data

Packaging size	100
Net weight	2.292 g
Country of origin	Germany
European customs tariff number	85366990
GTIN	5713140188617
eCl@ss	27460201 PCB connector (board connector)
ETIM	EC002637
UNSPSC 24.0	39121415