

## Han 4HC-Halterung

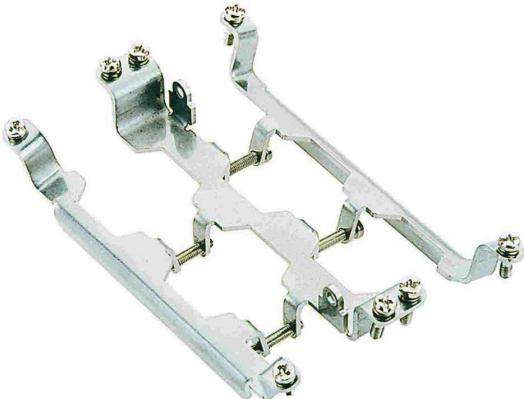


Image is for illustration purposes only. Please refer to product description.

### Identification

Category	Accessories
Series of hoods/housings	Han® M
Type of accessory	Frame
Description of the accessory	for male inserts for female inserts 4x HC 350 contacts + 2x Han® Q 5/0 in a hood

### Version

Size	48 B
------	------

### Technical characteristics

Tightening torque	0.5 Nm Fixing screws M3 0.25 Nm Fixing screws Han® Q 5/0 1.5 Nm Cross-tying screws
-------------------	--

### Material properties

Material (accessories)	Metal
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Yes

## Material properties

California Proposition 65 substances	Nickel
--------------------------------------	--------

## Commercial data

Packaging size	1
Net weight	77.1 g
Country of origin	Germany
European customs tariff number	85389099
GTIN	5713140015739
eCl@ss	27440210 Fixing element for industrial connectors
ETIM	EC002310
UNSPSC 24.0	39121466