

## RJ45 Plug Stewart

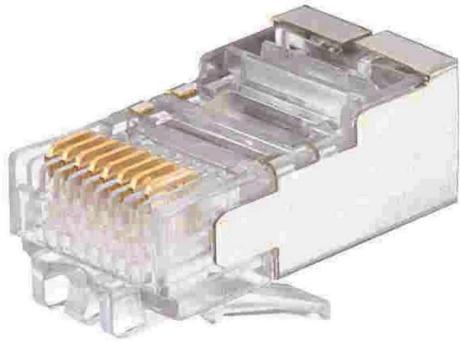


Image is for illustration purposes only. Please refer to product description.

Part number	09 12 000 9957
Specification	RJ45 Plug Stewart
HARTING eCatalogue	<a href="https://harting.com/09120009957">https://harting.com/09120009957</a>

### Identification

Category	Inserts
Element	Data connectors
Specification	for Han® RJ45 module

### Version

Gender	Male
Number of contacts	8

### Technical characteristics

Conductor cross-section [AWG]	AWG 24 ... AWG 22
Limiting temperature	-40 ... +85 °C
Mating cycles	≥500

### Material properties

Material (insert)	Polycarbonate (PC)
Colour (insert)	RAL 7032 (pebble grey)
Material flammability class acc. to UL 94	V-0
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained

## Material properties

REACH SVHC substances	Not contained
-----------------------	---------------

## Specifications and approvals

Specifications	IEC 60664-1 IEC 61984
Approvals	DNV GL

## Commercial data

Packaging size	10
Net weight	3 g
Country of origin	Germany
European customs tariff number	85389099
GTIN	5713140016385
eCl@ss	27440218 Module for industrial connectors (data)
ETIM	EC000438
UNSPSC 24.0	39121552