

## RJ45 Plug

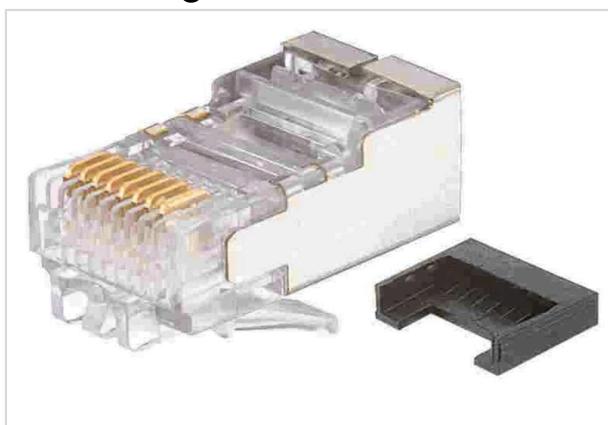


Image is for illustration purposes only. Please refer to product description.

Part number	09 12 000 9958
Specification	RJ45 Plug
HARTING eCatalogue	<a href="https://harting.com/09120009958">https://harting.com/09120009958</a>

### Identification

Category	Inserts
Series	RJ45
Element	Data connectors
Specification	for Han® RJ45 module

### Version

Gender	Male
Number of contacts	8

### Technical characteristics

Transmission characteristics	Cat. 5 Class D up to 100 MHz
	10 Mbit/s
Data rate	100 Mbit/s
	1 Gbit/s
	2.5 Gbit/s
Limiting temperature	-40 ... +70 °C
Mating cycles	≥500

### Material properties

Material (insert)	Polycarbonate (PC)
Colour (insert)	RAL 7032 (pebble grey)
Material flammability class acc. to UL 94	V-0
RoHS	compliant
ELV status	compliant

## Material properties

China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Yes
REACH SVHC substances	Potassium 1,1,2,2,3,3,4,4,4-nonafluorobutane-1-sulphonate
ECHA SCIP number	60b1a572-bb3f-476f-9307-b7d1688bd90c
California Proposition 65 substances	Yes
California Proposition 65 substances	Lead Nickel

## Specifications and approvals

Specifications	IEC 60664-1 IEC 61984
Approvals	DNV GL

## Commercial data

Packaging size	10
Net weight	2.42 g
Country of origin	Germany
European customs tariff number	85389099
GTIN	5713140016392
eCl@ss	27440218 Module for industrial connectors (data)
ETIM	EC000438
UNSPSC 24.0	39121552